


ESTC SQL RW 3500 (769 352)

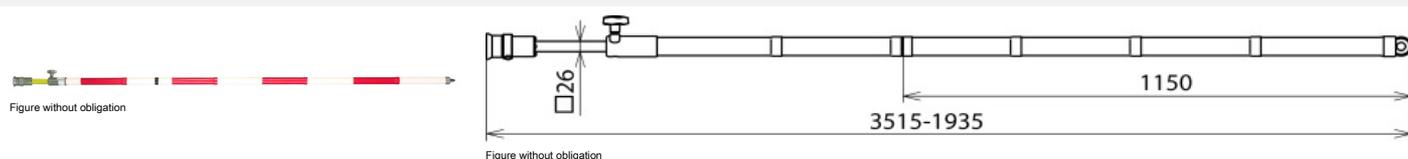

Type	ESTC SQL RW 3500
Part No.	769 352
Total length ($l_{G \max}$ / $l_{G \min}$)	3515 / 1935 mm
Handle length (l_H)	1150 mm
Max. load on the operating head ($l_{G \max}$ / $l_{G \min}$)	10 / 20 kg
DB drawing No.	3 Ebgw 01.58
DB material No.	157 534
Material (insulating tube)	Glass-fibre reinforced polyester tube
Material (star knob)	Aluminium alloy
End fitting	Aluminium / rubber eye
Standard	EN/IEC 61230 (DIN VDE 0683-100)
Temperature range	-25 °C ... +55 °C
Weight	3,7 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364007345
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.