


PHE3S60 110S CSN7774 (769 712)

- Transport case included

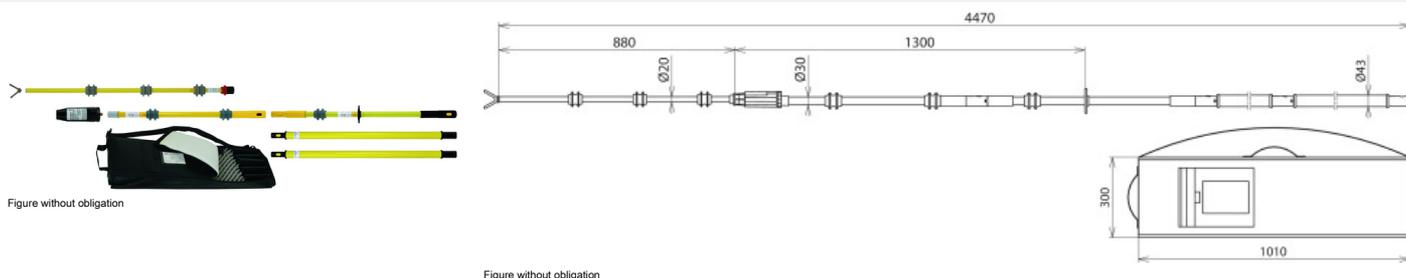

Type	PHE3S60 110S CSN7774
Part No.	769 712
Nominal voltage (U_N)	60 ... 110 kV
Type of voltage	a.c.
Frequency	50 Hz
Category	S
Total length ($l_{G \max} / l_{G \min}$)	4470 / 2840 mm
Insertion depth (l_o)	880 mm
Standard	EN/IEC 61243-1 (DIN VDE 0682-411)
Temperature range	-25 °C ... +55 °C, climatic category N
Design	complete
For use at	
For	indoor and outdoor installations
Application	switchgear installations and overhead lines
Design	single-pole
Indication	acoustic and visual
Self-testing element	yes
Material (test electrode)	copper alloy/gal Sn
Material (test prod)	glass-fibre reinforced epoxy resin tube
Material (indicator)	plastic, fully insulated
Material (insulating stick)	glass-fibre reinforced polyester tube
Weight	5,23 kg
Customs tariff number (Comb. Nomenclature EU)	90303370
GTIN	4013364242517
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.