

PSK 10 32 SQL (784 032)

- Earthing and short-circuiting devices can be configured online via the EaS configurator
- For connecting the phase cables of single-pole and three-pole earthing and short-circuiting devices to the overhead line
- With long threaded T pin shaft



Figure without obligation

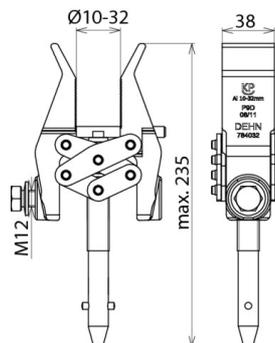


Figure without obligation

| Type | PSK 10 32 SQL |
|---|---|
| Part No. | 784 032 |
| Clamping range Ø | 10 ... 32 mm |
| Anti-rotation protection | PK2 |
| For cable cross-section Cu | 16 ... 95 mm ² |
| Max. short-circuit current I _k 0.5 s | 18.7 kA |
| Max. short-circuit current I _k 1 s | 18.7 kA |
| Standard | EN/IEC 61230 (DIN VDE 0683-100), threaded T pin shaft DIN 48087 |
| Temperature range | -25 °C ... +55 °C |
| Material (pressure plate) | Aluminium alloy |
| Material (clamp body) | Aluminium alloy |
| Material (shaft) | StSt |
| Weight | 843 g |
| Customs tariff number (Comb. Nomenclature EU) | 85359000 |
| GTIN | 4013364018679 |
| PU | 1 pc(s) |

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.

The clamps must be designed for the same maximum short-circuit current as the earthing and short-circuiting cables!