

FEK 4 15 TS FSQL (784 755)

- Earth clamp for overhead contact lines with contact electrode and flexible threaded T pin shaft according to DIN 48087
- For AC 80 to AC 120 overhead contact lines



Figure without obligation

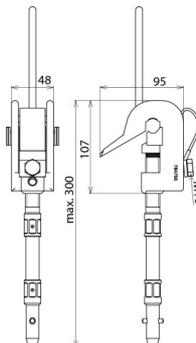


Figure without obligation

Type	FEK 4 15 TS FSQL
Part No.	784 755
Clamping range Ø	4 ... 15 mm
Anti-rotation cable lug	PK2 (Ø10.5 mm)
For cable material	Cu
For cable cross-section	50 mm ²
Max. short-circuit current I _k 0.06 s	34.0 kA
DB drawing No.	3 Ebgw 01.54
DB material No.	157 536
Material (pressure plate)	Cu alloy
Material (clamp body)	Cu alloy
Material (shaft)	StSt
Weight	1,54 kg
Customs tariff number (Comb. Nomenclature EU)	85359000
GTIN	4013364054202
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.