

TRS MS (785 100)

- Transparent intake tubes ensure enhanced safety
- Plug-in coupling system allows fast replacement of operating heads
- Delivered in a suitable transport case



Figure without obligation

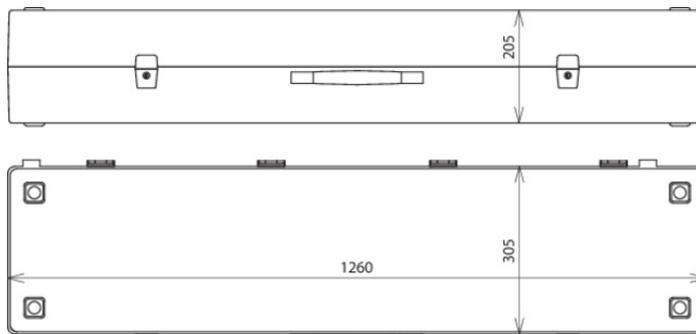


Figure without obligation

Type	TRS MS
Part No.	785 100
Nominal voltage (U_N)	Up to 36 kV
Frequency range	15 ... 60 Hz
Dimensions	1260 x 305 x 205 mm
Total length ($l_{G \max} / l_{G \min}$)	3580 / 1180 mm
Extension ($l_{G \max} / l_{G \min}$)	2515 / 115 mm
Standard	DIN VDE 0682-621
For use at	*
Weight	18 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364087606
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.