


HOEL 36 20 1100 (785 399)

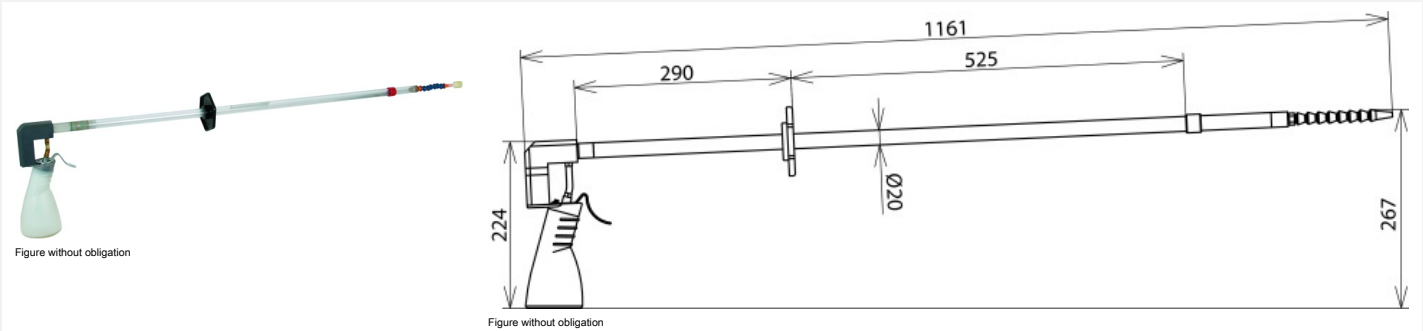

Type	HOEL 36 20 1100
Part No.	785 399
Nominal voltage (U _N)	Up to 36 kV
Total length (l _Σ)	1160 mm
Insertion depth (l _o)	280 mm
Length (handle) (l _H)	290 mm
Diameter	20 mm
Volume (oil container)	200 ml
Temperature range	+5 °C ... +50 °C
Standard	Based on DIN VDE 0681-1 and DIN VDE 0682-621
For use at	☼
Accessory	Extension (500 mm) (Part No. 785 398)
Weight	757 g
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364146525
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.