

TRS NS (785 502)

- For dry cleaning of cable distribution cabinets, open indoor installations and control cabinets
- Plug-in coupling system allows fast replacement of operating heads
- Delivered in a suitable transport case



Figure without obligation

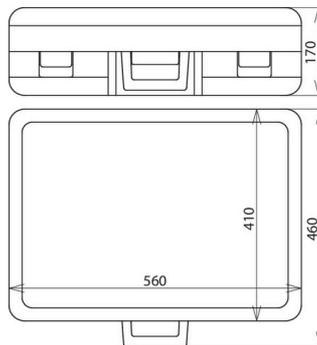


Figure without obligation

Type	TRS NS
Part No.	785 502
Nominal voltage (U_N)	Up to 1000 V
Frequency range	15 ... 60 Hz
Dimensions	560 x 410 x 170 mm
Total length ($l_{G \max}$ / $l_{G \min}$)	1350 / 560 mm
Standard	Based on DIN VDE 0680-3
For use at	*
Weight	7,2 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364087347
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.