

SE E14 (785 639)

- For indoor installations
- Protection against reconnection
- With "Nicht schalten" symbol [Do not close the circuit] acc. to national regulations (VBG 125)
- Insulating plug for screw inserts



Figure without obligation

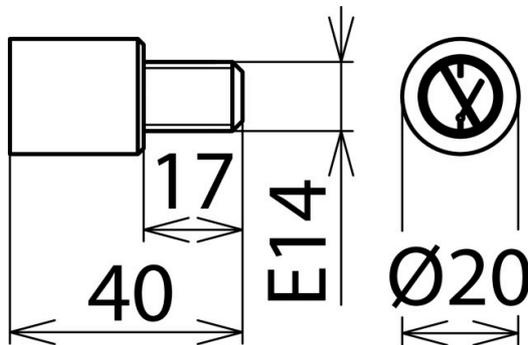


Figure without obligation

Type	SE E14
Part No.	785 639
Nominal voltage (U _N)	Up to 1000 V
Size	E14
Diameter	20 mm
Dimensions	Ø20 x 40 mm
Standard	VBG 125 and DIN 40008
Use	For indoor installations
Weight	15 g
Customs tariff number (Comb. Nomenclature EU)	85369095
GTIN	4013364087019
PU	10 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.