

FRS ZK MS (785 940)

- Damp cleaning equipment for use under live conditions with special cleaning liquid
- Universal gear coupling for replacing and adjusting the angle of operating heads
- Delivered in a suitable transport case



Figure without obligation

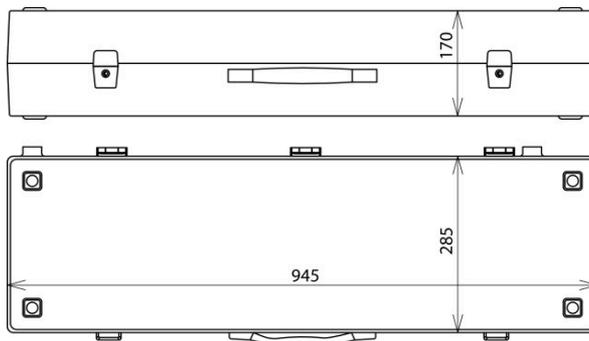


Figure without obligation

Type	FRS ZK MS
Part No.	785 940
Nominal voltage (U_N)	Up to 36 kV
Frequency range	15 ... 60 Hz
Dimensions	945 x 285 x 170 mm
Total length ($l_{G \max} / l_{G \min}$)	3250 / 1450 mm
Extension ($l_{G \max} / l_{G \min}$)	2100 / 350 mm
Standard	Based on DIN VDE 0681-1 and DIN VDE 0682-621
Standard (universal gear coupling)	EN/IEC 60832 (DIN VDE 0682-211)
For use at	*
Weight	10,85 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364106253
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.