

## Single Point Coaxial Drop Elbow

### Application

- For single point vapor recovery only


### Features

- 3" male vapor outlet (top)
- Comes assembled with 4" male inlet
- Bolt-on inlets/outlets for easy, fast replacement
- Replacement parts are available; please contact Dixon®
- 6400 co-axial inlets do not fit our other elbow series

### Materials

- Arms: solid bronze
- Sight glass: acrylic
- Seals: nitrile rubber

| Inlet           | Outlet            | Aluminum Part # |
|-----------------|-------------------|-----------------|
| 3" adapter fuel | 3" male vapor     | 6430            |
| 3" coupler fuel |                   | 6430F           |
| 4" adapter fuel |                   | 6400            |
| 4" coupler fuel |                   | 6400F           |
| 4" coupler fuel | 3" male NPT vapor | 6400FNPT        |
| 3" adapter fuel | 3" male vapor     | 6430X           |
| 3" coupler fuel |                   | 6430XF          |
| 4" adapter fuel |                   | 6400X           |
| 4" coupler fuel |                   | 6400XF          |
| 4" coupler fuel | 3" male NPT vapor | 6400XFNPT       |

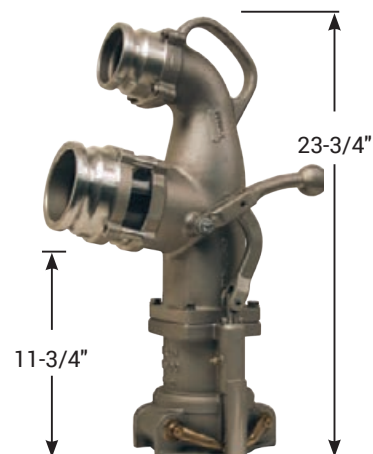

## Coaxial Elbow Fuel Inlets

### Adapters

### Application

- For use with 6400-series coaxial elbows only

### Feature

- Rated for petroleum service, Ethanol to E100, and biodiesel to B20

| Size | Aluminum Part # |
|------|-----------------|
| 3"   | 6000-16C        |
| 4"   | 6000-17C        |



### Couplers

### Application

- For use with 6400-series coaxial elbows only

### Feature

- Rated for petroleum service, Ethanol to E100, and biodiesel to B20

| Size | Aluminum Part # |
|------|-----------------|
| 3"   | 6000-15C        |
| 4"   | 6000-14C        |



S

### Vapor Outlets

| Size | Aluminum Part # |
|------|-----------------|
| 3"   | 6000-4          |
| 3"   | 6000-26C        |

