


**CLASS
D**

WELDED STORAGE CABINETS

Commercial Grade




CATALOG PAGE 143

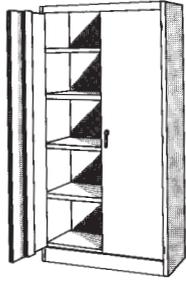

STORAGE

COUNTER HEIGHT

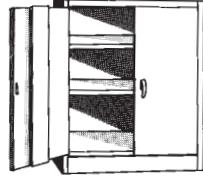

Product Number	Size W" x D" x H"	Color	List Each	Shpg. Wt.
WELDED STORAGE CABINETS				
WC183642GY	36" x 18" x 42"	Gray	394.83	85
WC183642PU	36" x 18" x 42"	Putty	394.83	85
WC183672GY	36" x 18" x 72"	Gray	489.96	138
WC183672PU	36" x 18" x 72"	Putty	489.96	138
WC243672GY	36" x 24" x 72"	Gray	603.72	181
WC243672PU	36" x 24" x 72"	Putty	603.72	181

Product Number	Size W" x D" x H"	Color	List Each	Shpg. Wt.
SHELVES ONLY				
7002GY	36" x 18"	Gray	26.58	7
7002PU	36" x 18"	Putty	26.58	7
7006GY	36" x 24"	Gray	34.47	9
7006PU	36" x 24"	Putty	34.47	9


**CLASS
D**

WELDED STORAGE CABINETS


Industrial Grade



CATALOG PAGE 143

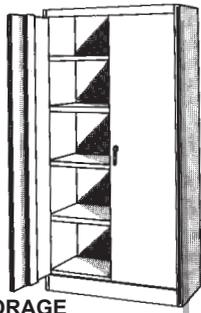

STORAGE

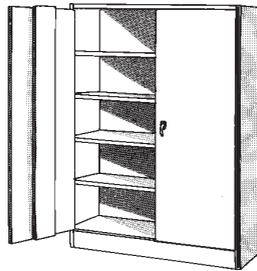

JUMBO STORAGE

WELDED CABINETS

Product Number		Size W" x D" x H"	List Ea.	Shpg. Wt.
Gray	Putty			
WC183678GY	WC183678PU	36"x18"x78"	742.60	186
WC243678GY	WC243678PU	36"x24" x78"	815.89	217
WC184878GY	WC184878PU	48"x18"x78"	962.44	273
WC244878GY	WC244878PU	48"x24"x78"	1,063.06	271

SHELVES ONLY


7810GY	7810PU	36 x 18	31.00	8
7811GY	7811PU	36 x 24	41.24	10
7812GY	7812PU	48 x 18	45.05	10
7813GY	7813PU	48 x 24	54.94	12

**CLASS
D**

VAULT CABINETS



CATALOG PAGE 143

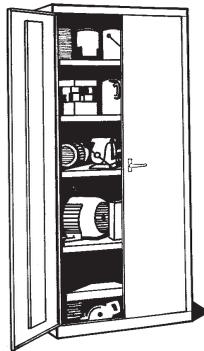

Product Number	Size W" x D" x H"	List Each	Shpg. Wt.
VC1500G	36 x 18 x 48	796.41	198
VC1501G	36 x 18 x 60	955.70	240
VC1502G	36 x 18 x 72	1,116.80	281
VC1503G	36 x 18 x 84	1,199.18	309
VC1504G	36 x 24 x 84	1,290.71	352
VC1505G	48 x 24 x 84	1,662.38	409
VC362448	36 x 24 x 48	737.81	210
VC362472	36 x 24 x 72	922.96	332
VC482472	48 x 24 x 72	1,109.98	370
VAULT CABINET SHELF			
VCEX136G	36 x 18	69.47	18
VCEX236G	36 x 24	85.78	22
VCEX348G	48 x 24	112.60	27

**CLASS
D**

EXTRA HEAVY DUTY CABINETS



CATALOG PAGE 144



Product Number	Size W" x D" x H"	Color	List Each	Shpg. Wt.
EHD4236	36" x 24" x 42"	Gray	945.66	210.0
EHD7836	36" x 24" x 78"	Gray	1,484.90	363.0
EHD7848	48" x 24" x 78"	Gray	1,625.51	445.0
EHD7860	60" x 24" x 78"	Gray	1,765.90	526.0