

Beacons

Steady-On Halogen

125 Class



Edwards 125 Class standard steady-on Halogen beacons are NEMA Type 4X signaling devices, suitable for indoor or outdoor applications where a continuous (steady-on) light source is required. Base material is gray or black, manufactured from a 33% glass filled nylon, providing a high resistance to heat and chemicals. The lens is made of shatter-resistant polycarbonate.

Features and Specifications

- Halogen light source
- Shatter-resistant polycarbonate lens
- Gray or black glass filled nylon base
- Suitable for use in indoor or outdoor applications
- NEMA Type 4X enclosure
- Option for panel or conduit mounting
- Operating temperature range: -31°F to 150°F (-35°C to 66°C)




3.25"



Ordering Information						
Description	Cat. No.	Operating Voltage ¹	Current	Lens Colors	Replacement	
					Lens	Lamp
Steady-on Beacon Halogen - Gray Base	125HALSA24A	24V AC	0.770 A	Amber	125LA	
	125HALSB24A	24V AC	0.770 A	Blue	125LB	50LMP-9WH-D
	125HALSC24A	24V AC	0.770 A	Clear	125LC	or industry trade
	125HALSG24A	24V AC	0.770 A	Green	125LG	no. 1692 ²
	125HALSR24A	24V AC	0.770 A	Red	125LR	
	125HALSA120A	120V AC	0.200 A	Amber	125LA	
	125HALSB120A	120V AC	0.200 A	Blue	125LB	50LMP-12WH-D
	125HALSC120A	120V AC	0.200 A	Clear	125LC	or industry trade
	125HALSG120A	120V AC	0.200 A	Green	125LG	no. 15T7DC ²
	125HALSR120A	120V AC	0.200 A	Red	125LR	
	125HALSA24D	24V DC	0.770 A	Amber	125LA	
	125HALSB24D	24V DC	0.770 A	Blue	125LB	50LMP-9WH-D
	125HALSC24D	24V DC	0.770 A	Clear	125LC	or industry trade
	125HALSG24D	24V DC	0.770 A	Green	125LG	no. 1692 ²
125HALSR24D	24V DC	0.770 A	Red	125LR		
Steady-on Beacon Halogen - Black Base	125HALSA24AB	24V AC	0.770 A	Amber	125LA	
	125HALSB24AB	24V AC	0.770 A	Blue	125LB	50LMP-9WH-D
	125HALSC24AB	24V AC	0.770 A	Clear	125LC	or industry trade
	125HALSG24AB	24V AC	0.770 A	Green	125LG	no. 1692 ²
	125HALSR24AB	24V AC	0.770 A	Red	125LR	
	125HALSA120AB	120V AC	0.200 A	Amber	125LA	
	125HALSB120AB	120V AC	0.200 A	Blue	125LB	50LMP-12WH-D
	125HALSC120AB	120V AC	0.200 A	Clear	125LC	or industry trade
	125HALSG120AB	120V AC	0.200 A	Green	125LG	no. 15T7DC ²
	125HALSR120AB	120V AC	0.200 A	Red	125LR	
	125HALSA24DB	24V DC	0.770 A	Amber	125LA	
	125HALSB24DB	24V DC	0.770 A	Blue	125LB	50LMP-9WH-D
	125HALSC24DB	24V DC	0.770 A	Clear	125LC	or industry trade
	125HALSG24DB	24V DC	0.770 A	Green	125LG	no. 1692 ²
125HALSR24DB	24V DC	0.770 A	Red	125LR		

¹AC voltage frequency is 50/60 Hz
²Incandescent lamps, user supplied

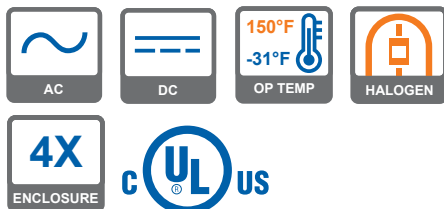

Beacons

Steady-On Halogen

125 Class

Accessories

Description	Cat. No.
Protective Wire Guard	125GRD
Corner Mount Bracket	CBR
Wall Mount Bracket	WBR



125GRD
Protective Wire Guard



CBR
Corner Mount Bracket



WBR
Wall Mount Bracket

Weights and Dimensions

Cat. No.	Approx. Net Weight (lb.)	Approx. Shipping Weight (lb.)
125HALS*24D	0.40	0.50
125HALS*24A	0.40	0.50
125HALS*120A	0.40	0.50
125HALS*24DB	0.40	0.50
125HALS*24AB	0.40	0.50
125HALS*120AB	0.40	0.50
125GRD	0.61	0.77
CBR	4.00	4.20
WBR	2.30	2.50

*Letter in this position designates lens color: A - amber, B - blue, C - clear, G - green or R - red

