

Push Buttons

Low Voltage

250 Series



The 250 is a low voltage, high amperage push button designed for simultaneous operation of two or three devices from one central point.

The 255 is a low voltage, high amperage push button designed for use where the simultaneous breaking of one circuit and the making of another is required.

Features and Specifications


- Fully insulated
- Multiple contacts
- Momentary contacts
- 250 has 3 normally open contacts
- 255 has 1 normally open, 1 normally closed contact

Ordering Information


Description	Cat. No.	Switching Voltage	Current		Finish		Hole Size	Hole Depth
			DC	AC	Rim	Center		
Multiple Contact Push Buttons	250	12V	6.0 A	2.0 A	Polished Nickel	Black	3/4" (19mm)	1 1/16" (27mm)
		24V	4.0 A	1.0 A				
		48V	2.0 A	0.5 A				
	255	12V	6.0 A	2.0 A	Polished Nickel	Black	3/4" (19mm)	1 1/16" (27mm)
		24V	4.0 A	1.0 A				
		48V	2.0 A	0.5 A				

Weights and Dimensions

Cat. No.	Approx. Net Weight (lb.)	Approx. Shipping Weight (lb.)
250	0.04	0.08
255	0.04	0.08

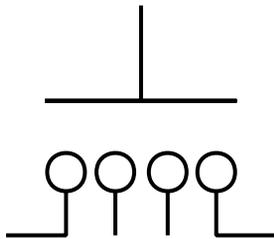

250 Contact Arrangement

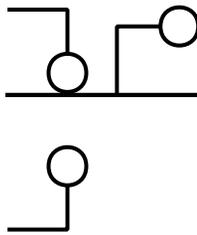

255 Contact Arrangement

