



Cat. No. MC8-16C1



Cat. No. MC8-16C1-1

## LED 8 Line Lobby Message Center

### MC8-16C1 Series

#### FEATURES

- > Stores up to 30 pages of messages
- > 100,000 Hr. Multi-color LED Lamp Technology
- > Upper and lower case characters
- > Timed text features
- > 1 month typical memory retention
- > Built in real-time clock, 12 or 24 hour format
- > Built in serial computer interface- RS232 and RS485
- > Addressable
- > Keypad controller
- > Power cord with 3 prong plug supplied

#### AGENCY APPROVALS

- > ETL Listed to ANSI/UL 1950 Second Edition (US)
- > Can/CSA-22.2 No. 950-M89 (Can)
- > FCC Part 15 Class A

The Edwards MC8-16C1 Message Center is an indoor rated multi-color LED communication center. It may be used as a stand-alone message center or can be networked into a company wide communication system. When networked, one message can be transmitted from the controlling computer software to the serial computer interface on all the message centers within the facility or discrete messages can be sent to specific addresses within the communication network of messages centers.

The unit has a solid oak case and is designed for free standing floor installation but is supplied with wall mounting brackets if that style mounting is required. For use indoors in commercial and industrial environments.


Designed for indoor communication, this Edwards Message Center is designed for installation in company lobbies to greet guests and provide them with information at a glance. Such information may include meeting room assignments, safety goals, changes in employee benefits or other company announcements. May also be used in commercial establishments such as stores and restaurants to assist with internal and external communications.

#### Hand Held Remote Programmer

A 54 key hand held remote control keyboard with easy to understand programming instructions is supplied with each Edwards Message Center — MC-RP (supplied with each unit). Batteries included.

D-04

## TECHNICAL INFORMATION

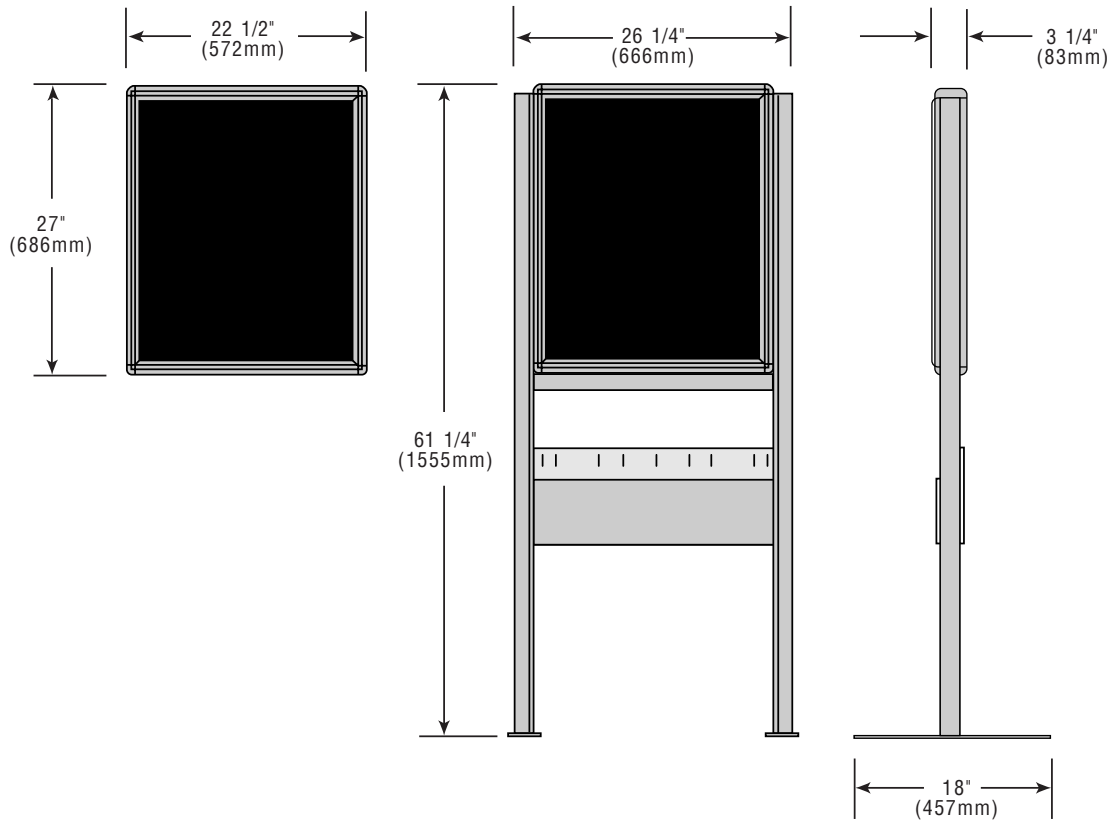

Cat. No.	Power	No. characters	Character size Array	Pixel size diameter x center to center spacing	Pixel Color	Max. viewing distance w/ largest font*	Message capacity	Operating environment	Case dimens/ display dimens
MC8-16C-1	120V AC ± 10% 180 watt max.	8 lines of 16 characters each	1.4"	.2" x .2"	3 colors	70 ft	26 pages of messages	32-95°F 0-95% relative humidity	27" L 61" D
MC8-16C1-1	120V AC ± 10% 180 watt max.	8 lines of 16 characters each	1.2"	.2" x .2"	3 colors	60 ft	30 pages of messages	non-condensing	17 3/4" L 72" H

\*Fonts available: sans serif, upper/lower case, small sans serif    \*\*Reflects floor stand feet

### Accessories

Windows® compatible software for down loading discrete messages — order MCN-1-0.

Infrared message loader with 3 foot cable and 9V battery — order MC-RIRL.

**For Message Center software & Hardware Accessories please see pages 7-18 to 7-25.**

Windows is a registered trademark of Microsoft Corporation