


Conventional and Addressable Accessories

Relays

MR Series



MR101/C

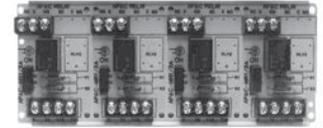

MR104T

The MR Series Multi-Voltage Control Relays offer SPDT or DPDT 10 Amp contacts that may be operated by one of four input control voltages. A single relay may be energized from a voltage source of 24V DC, 24V AC, 115V AC or 230V AC by wiring to appropriate input terminals.

Each relay position contains a red light emitting diode (LED) that indicates the relay coil is energized. Relays may be “snapped apart” from a standard four-module assembly and used independently.

These devices are suitable for applications where local contacts are required for system status and remote contacts for control of electrical loads and general purpose switching, such as HVAC, temperature control, fire alarm, security, energy management and lighting control systems.

Features and Specifications

- May be energized from one of four input voltages
- Contains red LED which illuminates when the coil is energized
- Single, or quad relay modules may be “snapped apart” from a standard four-position master
- SPDT or DPDT relays available
- Available in dustproof metal enclosures with LED viewing port
- Track mounting hardware to facilitate installation in standard cabinets
- Operating temperature range: 32°F to 120°F (0°C to 49°C)

Ordering Information

Description	Cat. No.	Operating Voltage	Current	Contacts	Contact Rating	Mounting
Single-position Relays	MR101/T	24V AC, 24V DC, 115V AC, 230V AC	0.015 A	SPDT	10 A @ 115V AC	Track
	MR101/C	24V AC, 24V DC, 115V AC, 230V AC	0.015 A	SPDT	10 A @ 115V AC	Metal Enclosure
	MR201/T	24V AC, 24V DC, 115V AC, 230V AC	0.035 A	DPDT	10 A @ 115V AC	Track
	MR201/C	24V AC, 24V DC, 115V AC, 230V AC	0.035 A	DPDT	10 A @ 115V AC	Metal Enclosure
Four-position Relays	MR104T	24V AC, 24V DC, 115V AC, 230V AC	0.015 A	SPDT	10 A @ 115V AC	Track
	MR104C	24V AC, 24V DC, 115V AC, 230V AC	0.015 A	SPDT	10 A @ 115V AC	Metal Enclosure
	MR204/T	24V AC, 24V DC, 115V AC, 230V AC	0.035 A	DPDT	10 A @ 115V AC	Track
	MR204/C	24V AC, 24V DC, 115V AC, 230V AC	0.035 A	DPDT	10 A @ 115V AC	Metal Enclosure



Conventional and Addressable Accessories

Relays

MR Series

Weights and Dimensions

Cat. No.	Approx. Shipping Weight (lb.)	Dimensions		
		Height (in.)	Width (in.)	Depth (in.)
MR101/T	0.25	3.0	2.125	1.5
MR101/C	1.00	6.125	3.25	2.5
MR201/T	0.25	3.0	2.125	1.5
MR201/C	1.00	6.125	3.25	2.5
MR104T	1.00	3.0	8.5	1.5
MR104C	4.00	6.125	9.5	2.5
MR204/T	1.00	3.0	8.5	1.5
MR204/C	4.00	6.125	9.5	2.5