

# WHC-Series, Hydraulic Cutterheads

▼ Shown from left to right: WHC-4000, WHC-750




## WHC, WHR, STC Series

Capacity:  
**3 - 20 ton**

Cutting Capacity:  
**∅ 13 - 101 mm**

Maximum Operating Pressure:  
**700 bar**

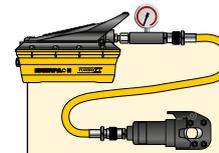


### Tool-Pump Sets

Cutterheads marked with an \* are available as sets (pump, tool, gauge, couplers and hose) for your ordering convenience.

Cutterhead Model Nr.	Pump Model Nr.	Set Model Number
WHC-750	P-392	<b>STC-750H</b>
WHC-750	P-392FP	<b>STC-750FP</b>
WHC-750	PATG-1102N	<b>STC-750A</b>
WHC-1250	P-392	<b>STC-1250H</b>
WHC-1250	P-392FP	<b>STC-1250FP</b>
WHC-1250	PATG-1102N	<b>STC-1250A</b>

- Single-acting, spring return on all models, except WHR-1250
- Guillotine action for smooth cutting operation
- Lifting handles on larger models for easy transport
- Carrying bag included for easy carrying and tool protection
- Ideal for use with most Enerpac pumps featuring 3-way valve or dump valve and 700 bar pressure rating (except WHR-1250, which requires 4-way valve)
- CR-400 coupler and dust cap included on all models.

▼ Steel rope is easily cut with the smooth guillotine action of an Enerpac cutterhead.

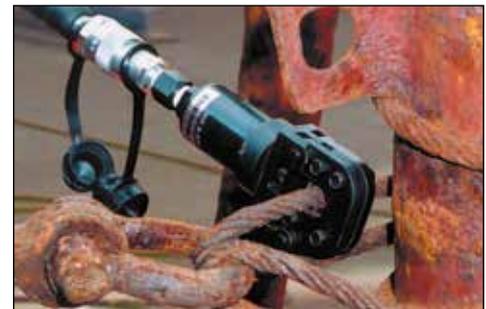

### ▼ Selection Chart Maximum Cutting Capacities (∅ in mm)

Cutter Head Operation	Capacity ton	Model Number	Oil Capacity (cm <sup>3</sup> )	Length (mm)	Steel Wire Rope, Hemp-core or IWRC 6x7 6x12 6x19	Round Bar				Wire Strand				Cable		Replacement Blades (kg)	
						Copper Wire or Bar	Aluminum Wire or Bar	Soft Steel Bolts	Reinforcing Bar	Bare Copper Wire Strands	Bare Aluminum Wire Strands	ACSR	Guy Steel Wire Strands	Telephone Cable CPP	Underground Cable (Power)		
Single-Acting	4	<b>WHC-750*</b>	19,7	127	19	19	19	19	13	19	19	19	16	☆	☆	3,2	<b>WCB-750</b>
	20	<b>WHC-1250*</b>	134,4	279	31	31	31	31	25	31	31	31	22	☆	☆	11,3	<b>WCB-1250</b>
	13	<b>WHC-2000</b>	119,6	381	25	31	31	22	☆	50	50	50	19	☆	☆	10,4	<b>WCB-2000</b>
	3	<b>WHC-3380</b>	65,5	482	☆	☆	☆	☆	☆	76	76	☆	☆	85	85	9,1	<b>WCB-3380</b>
	8	<b>WHC-4000</b>	137,7	609	☆	☆	☆	☆	☆	89	89	☆	☆	101	101	14,5	<b>WCB-4000</b>
Dbl.-Act.	20	<b>WHR-1250</b>	122,9	419	31	31	31	31	25	31	31	31	22	☆	☆	11,8	<b>WCB-1250</b>

\* Available in sets with P-392 Hand Pump, P-392FP Foot Pump or PATG-1102N Turbo Air Pump.

☆ Will not cut designated material