

RVF Series

Exterior Mount Fans



Model	RVF 4	RVF 4XL	RVF 6	RVF 6XL	RVF 8XL	RVF 10	RVF 10L	RVF 10XL
Duct Size	4"	4"	6"	6"	8"	10"	10"	10"
Rated Power	19W	92W	92W	149W	151W	112W	211W	312W
Voltage / Phase	120V / 1							
Max Amps	0.17A	0.84A	0.84A	1.46A	1.42A	0.94A	2.10A	2.61A
Shipping Weight	8 lbs	10 lbs	10 lbs	14 lbs	14 lbs	31 lbs	36 lbs	33 lbs
Shipping Class	1	1	1	1	1	1	1	1




Model	RVF 4XL EC	RVF 6XL EC	RVF 8XL EC	RVF 10 EC
Duct Size	4"	6"	8"	10"
Rated Power	80W	61W	85W	130W
Voltage / Phase	120V / 1	120V / 1	120V / 1	120V / 1
Max Amps	1.51A	1.21A	1.56A	2.22A
Shipping Weight	8 lbs	20 lbs	20 lbs	31 lbs
Shipping Class	1	1	1	1



Size (inches)

Model	A	B	C	D	E
RVF 4	4	10 1/4	13	6	2 3/4
RVF 4XL RVF 4XL EC	4	10 1/4	13	6	2 3/4
RVF 6	6	10 1/4	13	6	2 3/4
RVF 6XL RVF 6XL EC	6	14 1/4	17	6 8	2 3/4 4 7/8
RVF 8XL RVF 8XL EC	8	14 1/4	17	6 8	2 3/4 4 7/8
RVF 10 RVF 10 EC	10	17 7/8	21 1/4	10	5 7/8
RVF 10L	10	17 7/8	21 1/4	10	5 7/8
RVF 10XL	10	17 7/8	21 1/4	10	5 7/8

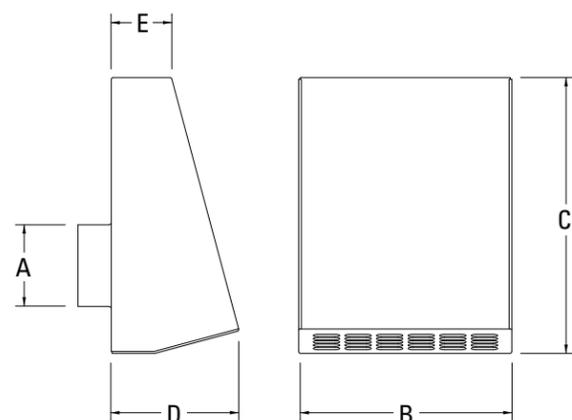

CFM

Model	0.1" P _s	0.2" P _s	0.4" P _s	0.6" P _s	0.8" P _s	1.0" P _s	1.5" P _s
RVF 4	120	112	83	37	-	-	-
RVF 4XL	180	172	154	136	118	91	-
RVF 6	220	204	177	150	123	68	-
RVF 6XL	360	346	315	285	258	213	64
RVF 8XL	410	392	348	312	282	235	102
RVF 10	760	720	630	520	400	270	-
RVF 10L	1020	985	920	850	770	670	269
RVF 10XL	1222	1180	1095	996	900	800	485
RVF 4XL EC	225	220	209	190	170	155	108
RVF 6XL EC	380	362	328	284	244	208	95
RVF 8XL EC	492	470	433	392	348	290	160
RVF 10 EC	862	830	766	698	611	505	100

RE/REC Series


Roof Mount Fans



Model	RE 54/REC 54	RE 6/ REC 6	RE 8XL/ REC 8XL	RE 10XL/REC 10XL	RE 10XLT/REC 10XLT
Duct Size	5"	6"	8"	10"	10"
Rated Power	19W	87W	153W	394W	531W
Voltage / Phase	120V / 1	120V / 1	120V / 1	120V / 1	120V / 1
Max Amps	0.18A	0.80A	1.40A	3.60A	4.86A
RPM (min ⁻¹)	3040	2700	2800	3250	2950
Shipping weight	11 lbs	14 lbs	19 lbs	31 lbs	33 lbs
Shipping class	1	1	1	1	1

Size (inches)

Model	A	B	C	D	E
RE 54 / REC 54	10 15/16	6	5	15 1/2	1 1/2
RE 6 / REC 6	13 15/16	6 1/4	6	15 1/2	1 1/2
RE 8XL / REC 8XL	16 9/16	5 15/16	8	20	1 1/2
RE 10XL / REC 10XL	20 13/16	11 1/2	10	20	1 1/2
RE 10XLT / REC 10XLT	20 13/16	12 11/16	10	20	1 1/2

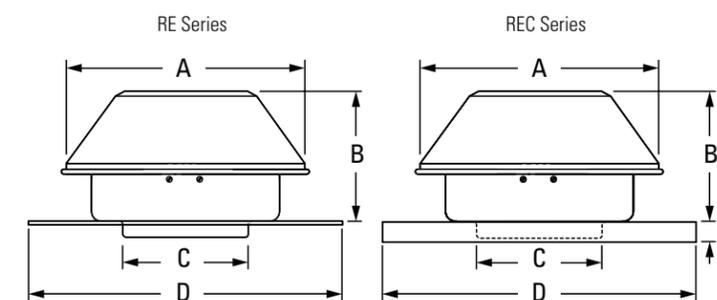

CFM

RPM	0" P _s	.50" P _s	.75" P _s	1.0" P _s	1.5" P _s
RE 54 / REC 54	116	65	36	-	-
RE 6 / REC 6	227	169	134	106	52
RE 8XL / REC 8XL	409	307	259	212	130
RE 10XL / REC 10XL	753	690	656	622	548
RE 10XLT / REC 10XLT	1008	890	831	766	609