


TH & THSS Series Mul-T-Mount Electric Infrared Heater

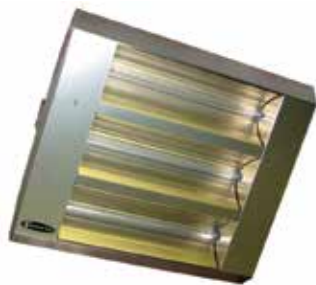

3-Lamp Mul-T-Mount Series - Bankers Bronze Or Stainless Steel Housing With (3) Clear 12mm Quartz Lamps Included



NOTE:

- 600-Volt Models also available, contact factory for more information.
- Asymmetrical pattern units are also available for 30° & 60°
- Made in U.S.A.

BRONZE HOUSING		STAINLESS STEEL HOUSING		KW	BTUs	VOLTS	REFLECTOR PATTERN	12mm DIAMETER REPLACEMENT LAMP	WT. (LBS)	LIST						
MFG CATALOG NUMBER	MFG MODEL NUMBER	MFG CATALOG NUMBER	MFG MODEL NUMBER							Bankers Bronze	Stainless Steel					
04874802	223-30-TH-208V	04436702	223-30-THSS-208V	4.8	16382	208	30° Symmetrical	63016209	25	1139	1283					
04874902	223-30-TH-240V	04436802	223-30-THSS-240V			240		63016249								
04875002	223-30-TH-277V	04436902	223-30-THSS-277V			277		63016279								
04875102	223-30-TH-480V	04815802	223-30-THSS-480V			480		63016489								
04875202	223-60-TH-208V	04432802	223-60-THSS-208V			208	60° Symmetrical	63016209								
04875302	223-60-TH-240V	04437302	223-60-THSS-240V			240		63016249								
04875402	223-60-TH-277V	04437402	223-60-THSS-277V			277		63016279								
04875502	223-60-TH-480V	04815902	223-60-THSS-480V			480		63016489								
04875602	223-90-TH-208V	04437802	223-90-THSS-208V			208	90° Symmetrical	63016209								
04875702	223-90-TH-240V	04437902	223-90-THSS-240V			240		63016249								
04875802	223-90-TH-277V	04438002	223-90-THSS-277V			277		63016279								
04875902	223-90-TH-480V	04816002	223-90-THSS-480V			480		63016489								
04876002	343-30-TH-208V	04812302	343-30-THSS-208V	7.5	25298	208	30° Symmetrical	63025209	33	1378	1636					
04876102	343-30-TH-240V	04812402	343-30-THSS-240V			240		63025249								
04876202	343-30-TH-480V	088114394	343-30-THSS-480V			480		63025489								
04876302	343-60-TH-208V	04812602	343-60-THSS-208V			208		60° Symmetrical				63025209				
04876402	343-60-TH-240V	04812702	343-60-THSS-240V			240	63025249									
04876502	343-60-TH-480V	088116394	343-60-THSS-480V			480	63025489									
04876602	343-90-TH-208V	04812902	343-90-THSS-208V			208	90° Symmetrical					63025209				
04876702	343-90-TH-240V	04813002	343-90-THSS-240V			240		63025249								
04876802	343-90-TH-480V	088118394	343-90-THSS-480V			480		63025489								
04876902	463-30-TH-480V	088105394	463-30-THSS-480V			10.95		37372				480	30° Sym.	63036489	41	1655
04877002	463-60-TH-480V	088107394	463-60-THSS-480V				60° Sym.					63036489				
04877102	463-90-TH-480V	088109394	463-90-THSS-480V				90° Sym.					63036489				

TH & THSS Series Product Accessories

MFG CATALOG NUMBER	MFG MODEL NUMBER	DESCRIPTION	FOR USE WITH	WT.(LBS)	LIST
08811239	VMB-41-SS	Wall Mounting Brackets (2)	All Mul-T-Mount Models	12	233
08511500	CHWG-222	Stainless Steel Wire Guards	222 Series	2	63
08511400	CHWG-342		342 Series		83
08516200	CHWG-462		462 Series		114
08543600	CHWG-223		223 Series		78
08543500	CHWG-343		343 Series		101
08543400	CHWG-463		463 Series		118
			Recessed Mounting Frames (UL)		
		Ceiling Cutout (in.)	Frame Size (in.)		
04419902	RMF-222-SS-A	27 x 17 7/8	29 1/8 x 20	6	258
04494402	RMF-222-A	27 x 17 7/8	29 1/8 x 20		188
04420702	RMF-342-SS-A	36 x 17 7/8	38 1/8 x 20	9	318
04418702	RMF-342-A	36 x 17 7/8	38 1/8 x 20		190
04421002	RMF-462-SS-A	49 x 17 7/8	51 1/8 x 20	11	388
04494502	RMF-462-A	49 x 17 7/8	51 1/8 x 20		240
08811002	RMF-223-SS	32 x 29 3/8	34 1/8 x 31 1/2	15	390
08811302	RMF-343-SS	41 x 29 3/8	43 1/8 x 31 1/2	18	457
08811102	RMF-463-SS	54 x 29 3/8	56 1/8 x 31 1/2	20	557
04877202	RMF-223	32 x 29 3/8	34 1/8 x 31 1/2	15	312
04877302	RMF-343	41 x 29 3/8	43 1/8 x 31 1/2	18	329
04877402	RMF-463	54 x 29 3/8	56 1/8 x 31 1/2	20	409
04407802	31939009	Red Vycor Sleeves	All 1600W Qtz. Lamp	2	96
04407302	31940009	Reduces 12mm Clear Quartz Lamp	All 2500W Qtz. Lamp		126
04407402	31941009	Brightness by 90%	All 3650W Qtz. Lamp		155
04461502	632-1620	Red Quartz Lamps; 1.6kw, 208v	222, 223 & RPH Series	2	162
04461602	632-1624	Red Quartz Lamps; 1.6kw, 240v			162
04462202	632-2548	Red Quartz Lamps; 2.5kw, 480v			342 & 343 Series