



Post Office Box 97  
Benton Harbor, Michigan  
Ph: 269/926-6171  
Fax: 269/925-8268

PART NUMBER:

STD122C

REVISION:

A

Product Specifications









Model Number	MAX. PRESS.		MAX. SPEED	HP	kW	Net Wt.	
	bar.	PSI				lbs.	kg
4AM-NRV-22BLL	5.6	80	2,000 RPM	1.05	.77	7	3.2
4AM-NRV-54ALL	5.5	80	2,000 RPM	1.05	.77	7	3.2

SOUND LEVEL 87 dB(A) MAX.  
 NORMAL AMBIENT +1°C. - 120°C.  
 RELATIVE HUMIDITY 0% - 100%  
 ENVIRONMENT HAZARDOUS AMBIENT COMBUSTIBLE  
GAS AND DUST +1° TO +40°C

CONFORMS TO EUROPEAN STANDARD EN13463-1  
 NON-ELECTRICAL EQUIPMENT FOR EXPLOSIVE  
 ATMOSPHERES GROUP II CAT 2 (GAS & DUST),  
 PROTECTED BY CONSTRUCTION (SURFACE TEMP. RATED 135°C).

NOTES:

1. CORROSION RESISTANT ROTOR ASSEMBLY.
2. UNIVERSAL VANE MATERIAL FOR OPERATING WITH OR WITHOUT LUBRICATION.
3. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE

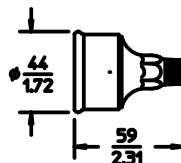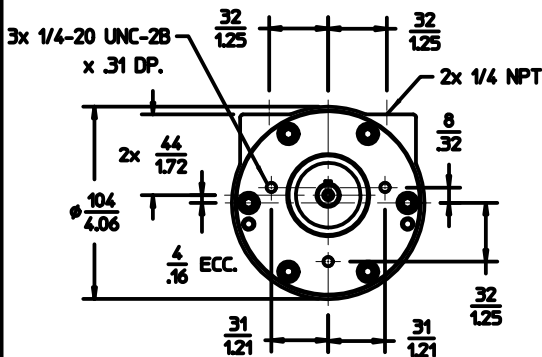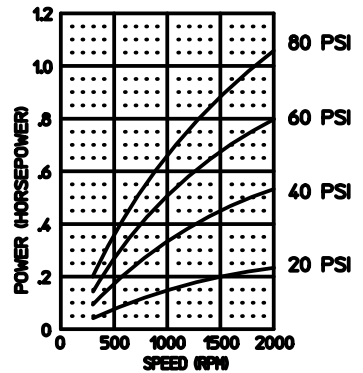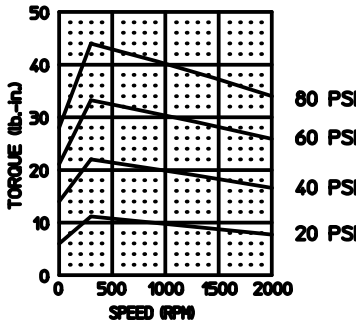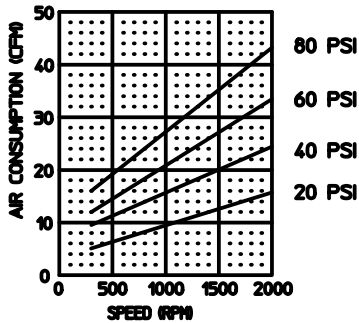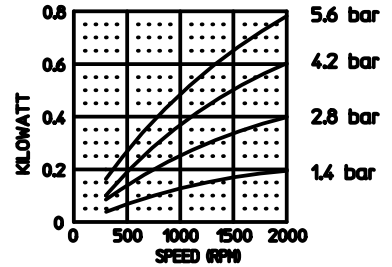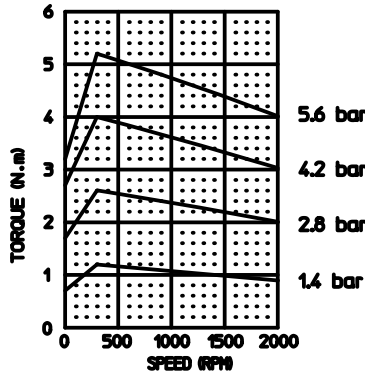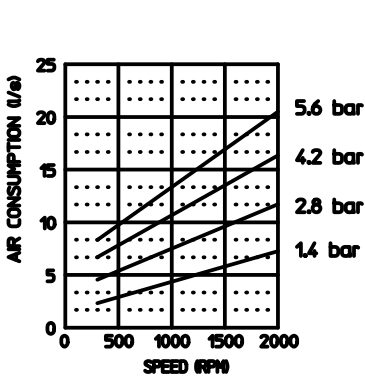

MUFFLER ASM.  
(SHIPPED UNATTACHED)

