

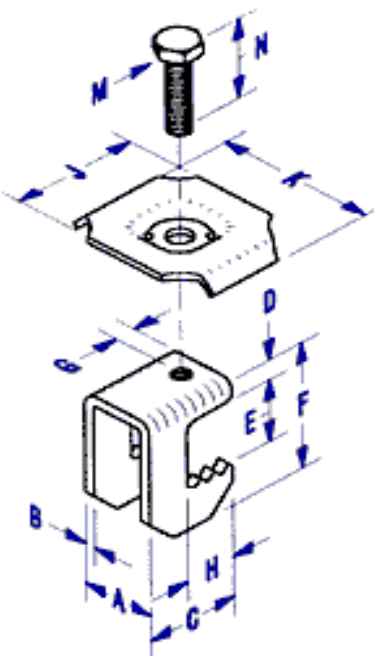
Grating Fasteners

P. O. Box 610
Harvey, LA 70059



Home of "G-Clips"...the best grating fastener

XSSG-Clip Dimensions

		<u>Letter to part descriptions:</u> A: Grip jaw Width B: Grip jaw Steel Thickness C: Grip jaw Length D: Grip jaw Flange Height E: Grip jaw Opening F: Overall Grip jaw Height G: Hole Center to Edge H: Grip jaw Depth I: Top Plate Thickness J: Top Plate Length K: Top Plate Width L: Top Plate Depression Depth M: Hex Head Cap Screw N: Screw Length	
<u>XSSGG-1 Dims:</u> A: 3/4" B: 13 gauge C: 1-1/8" D: 1/8" E: 13/16" F: 1-3/4" G: 1/4" H: 5/8" I: 16 gauge J: 1-1/2" K: 1-3/8" L: 1/8" M: 1/4"-20 N: varies	<u>XSSGG-2 Dims:</u> A: 3/4" B: 13 gauge C: 1-1/8" D: 1/8" E: 1-9/32" F: 2-1/8" G: 1/4" H: 5/8" I: 16 gauge J: 1-1/2" K: 1-3/8" L: 1/8" M: 1/4"-20 N: varies	<u>XSSGG-3 Dims:</u> A: 3/4" B: 13 gauge C: 1-1/8" D: 1/8" E: 1-7/8" F: 2-3/4" G: 1/4" H: 5/8" I: 16 gauge J: 1-1/2" K: 1-3/8" L: 1/8" M: 1/4"-20 N: varies	<u>XSSGG-4 Dims:</u> A: 3/4" B: 13 gauge C: 1-1/8" D: 1/8" E: 2-3/8" F: 3-1/4" G: 1/4" H: 5/8" I: 16 gauge J: 1-1/2" K: 1-3/8" L: 1/8" M: 1/4"-20 N: varies