


NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount

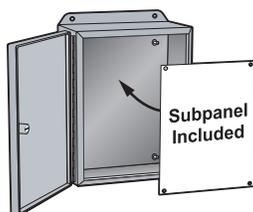

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a problem.

Construction

- Formed from 0.08in [2 mm] Type 5052 H-32 aluminum.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Welded brackets provide for enclosure mounting.
- Cover is secured with easily operated aluminum clamps.
- Seamless poured-in-place gasket.
- All models larger than 4 x 4 in [102 x 102 mm] include a removable 14-gauge subpanel.
- Tapped studs are provided for mounting inner panels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

Finish

- Cover and enclosure are natural unfinished aluminum.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 4, 4X, 12, and 13 [UL File E63524]
- CSA Type 4, 4X, 12, and 13 [CSA File RL21001]
- Complies with
 - NEMA Type 4, 4X, 12, and 13
 - IEC 60529, IP66



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount

Part Number	Price	Enclosure Size HxWxD	Painted Subpanel (included)	Subpanel HxW	Optional Subpanels			Drawing Link
					Aluminum	Galvanized	Stainless	
1414N4ALA	\$163.00	4.31 x 4.31 x 3.21 [109 x 109 x 82]	—	—	—	—	—	PDF
1414N4ALC	\$188.00	6.31 x 4.31 x 3.21 [160 x 109 x 82]	14R0503	4.88 x 2.88 [124 x 73]	14A0503	14G0503	14R0503SS	PDF
1414N4ALE	\$210.00	6.31 x 6.31 x 4.21 [160 x 160 x 107]	14R0505	4.88 x 4.88 [124 x 124]	14A0505	14G0505	14R0505SS	PDF
1414N4ALG	\$221.00	8.31 x 6.31 x 3.71 [211 x 160 x 94]	14R0705	6.75 x 4.88 [171 x 124]	14A0705	14G0705	14R0705SS	PDF
1414N4ALI	\$259.00	10.31 x 8.31 x 4.21 [262 x 211 x 107]	14R0907	8.75 x 6.88 [222 x 175]	14A0907	14G0907	14R0907SS	PDF
1414N4ALK	\$318.00	12.31 x 10.31 x 5.21 [313 x 262 x 132]	14R1109	10.75 x 8.88 [273 x 226]	14A1109	14G1109	14R1109SS	PDF
1414N4ALM6	\$386.00	14.31 x 12.31 x 6.21 [363 x 313 x 158]	14R1311	12.75 x 10.88 [324 x 276]	14A1311	14G1311	14R1311SS	PDF
1414N4ALM8	\$438.00	14.31 x 12.31 x 8.21 [363 x 313 x 209]	14R1311	12.75 x 10.88 [324 x 276]	14A1311	14G1311	14R1311SS	PDF
1414N4ALO6	\$446.00	16.31 x 14.31 x 6.21 [414 x 363 x 158]	14R1513	14.75 x 12.88 [375 x 327]	14A1513	14G1513	14R1513SS	PDF
1414N4ALO10	\$582.00	16.31 x 14.31 x 10.21 [414 x 363 x 259]	14R1513	14.75 x 12.88 [375 x 327]	14A1513	14G1513	14R1513SS	PDF

Notes: Dimensions in inches [millimeters].

*Subpanel NOT included.

NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount



Dimensions

