
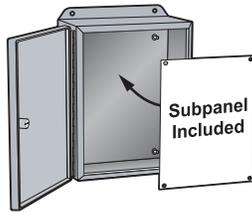


NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

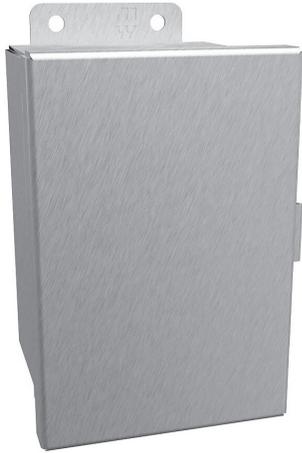

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion may be a problem.

Construction

- Formed from 14-gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Continuous stainless steel hinged cover is secured with stainless steel clamps and screws.
- Seamless poured-in-place gasket.
- All models include a removable 14-gauge subpanel.
- Tapped studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 3R, 4, 4X, 12, and 13 [UL File E65324]
- CSA Type 3R, 4, 4X, 12, and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Included Subpanel	Subpanel HxW	Drawing Link
1414N4PHSSC4	\$227.00	1414N4PHS16C4	\$279.00	6.31 x 4.31 x 4.20 [160 x 109 x 107]	14R0503	4.88 x 2.88 [124 x 73]	PDF
1414N4PHSSE	\$248.00	1414N4PHS16E	\$313.00	6.31 x 6.31 x 4.20 [160 x 160 x 107]	14R0505	4.88 x 4.88 [124 x 124]	PDF
1414N4PHSSG	\$278.00	1414N4PHS16G	\$347.00	8.31 x 6.31 x 3.70 [211 x 160 x 94]	14R0705	6.75 x 4.88 [171 x 124]	PDF
1414N4PHSSG4	\$282.00	1414N4PHS16G4	\$355.00	8.31 x 6.31 x 4.20 [211 x 160 x 107]	14R0705	6.75 x 4.88 [171 x 124]	PDF
1414N4PHSSI	\$340.00	1414N4PHS16I	\$430.00	10.31 x 8.31 x 4.20 [262 x 211 x 107]	14R0907	8.75 x 6.88 [222 x 175]	PDF
1414N4PHSSK	\$473.00	1414N4PHS16K	\$600.00	12.31 x 10.31 x 5.20 [313 x 262 x 132]	14R1109	10.75 x 8.88 [273 x 226]	PDF
1414N4PHSSK6	\$474.00	1414N4PHS16K6	\$602.00	12.31 x 10.31 x 6.20 [313 x 262 x 157]	14R1109	10.75 x 8.88 [273 x 226]	PDF
1414N4PHSSL6	\$523.00	1414N4PHS16L6	\$664.00	12.31 x 12.31 x 6.20 [313 x 313 x 157]	14R1111	10.75 x 10.88 [273 x 276]	PDF
1414N4PHSSM6	\$590.00	1414N4PHS16M6	\$729.00	14.31 x 12.31 x 6.20 [363 x 313 x 157]	14R1311	12.75 x 10.88 [324 x 276]	PDF
1414N4PHSSM8	\$617.00	1414N4PHS16M8	\$745.00	14.31 x 12.31 x 8.20 [363 x 313 x 208]	14R1311	12.75 x 10.88 [324 x 276]	PDF
1414N4PHSSO6	\$683.00	1414N4PHS16O6	\$867.00	16.31 x 14.31 x 6.20 [414 x 363 x 157]	14R1513	14.75 x 12.88 [375 x 327]	PDF
1414N4PHSSO10	\$770.00	1414N4PHS16O10	\$947.00	16.31 x 14.31 x 10.20 [414 x 363 x 259]	14R1513	14.75 x 12.88 [375 x 327]	PDF

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Dimensions

