


# NEMA 12 and 13 Single-Door Wall-Mount

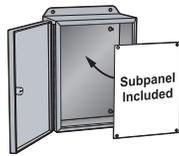

## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides some protection from falling dirt, dust, oil, and water.

## Construction

- Formed 14-gauge steel bodies and doors.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14-gauge welded mounting brackets
- Formed lip on door and enclosure exclude flowing liquids and contaminants.
- Continuously hinged door may be removed by pulling the hinge pin.
- Door is secured with easily operated stainless steel clamps.
- Provision for padlocking.
- Oil-resistant gaskets are permanently secured.
- A removable 12-gauge subpanel is included.
- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.
- A literature pocket is provided for the inside of the door.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating on the inside and outside.
- Removable subpanel is finished in white RAL9003 powder coating.

## Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 12 and 13
  - IEC 60529, IP54



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

NEMA 12 and 13 Single-Door Wall-Mount									
Part Number	Price	Enclosure Size HxWxD	Subpanels					Size HxW	Drawing Link
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless		
<a href="#">1418A6</a>	\$451.00	12.00 x 24.00 x 7.20 [305 x 610 x 183]	<a href="#">18P2109</a>	—	—	<a href="#">18G2109</a>	—	21.00 x 9.00 [533 x 229]	<a href="#">PDF</a>
<a href="#">1418A8</a>	\$472.00	12.00 x 24.00 x 9.20 [305 x 610 x 234]	<a href="#">18P2109</a>	—	—	<a href="#">18G2109</a>	—	21.00 x 9.00 [533 x 229]	<a href="#">PDF</a>
<a href="#">1418B6</a>	\$382.00	16.00 x 12.00 x 7.20 [406 x 305 x 183]	<a href="#">18P1309</a>	<a href="#">18P1309PP</a>	<a href="#">18A1309</a>	<a href="#">18G1309</a>	<a href="#">18P1309S16</a>	13.00 x 9.00 [330 x 229]	<a href="#">PDF</a>
<a href="#">1418B8</a>	\$400.00	16.00 x 12.00 x 9.20 [406 x 305 x 234]	<a href="#">18P1309</a>	<a href="#">18P1309PP</a>	<a href="#">18A1309</a>	<a href="#">18G1309</a>	<a href="#">18P1309S16</a>	13.00 x 9.00 [330 x 229]	<a href="#">PDF</a>
<a href="#">1418B10</a>	\$427.00	16.00 x 12.00 x 11.20 [406 x 305 x 284]	<a href="#">18P1309</a>	<a href="#">18P1309PP</a>	<a href="#">18A1309</a>	<a href="#">18G1309</a>	<a href="#">18P1309S16</a>	13.00 x 9.00 [330 x 229]	<a href="#">PDF</a>
<a href="#">1418G6</a>	\$416.00	16.00 x 16.00 x 7.20 [406 x 406 x 183]	<a href="#">18P1313</a>	<a href="#">18P1313PP</a>	<a href="#">18A1313</a>	<a href="#">18G1313</a>	<a href="#">18P1313S16</a>	13.00 x 13.00 [330 x 330]	<a href="#">PDF</a>
<a href="#">1418G8</a>	\$436.00	16.00 x 16.00 x 9.20 [406 x 406 x 234]	<a href="#">18P1313</a>	<a href="#">18P1313PP</a>	<a href="#">18A1313</a>	<a href="#">18G1313</a>	<a href="#">18P1313S16</a>	13.00 x 13.00 [330 x 330]	<a href="#">PDF</a>
<a href="#">1418CR6</a>	\$462.00	16.00 x 20.00 x 7.20 [406 x 508 x 183]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>
<a href="#">1418CR8</a>	\$485.00	16.00 x 20.00 x 9.20 [406 x 508 x 234]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>
<a href="#">1418CA6</a>	\$421.00	20.00 x 12.00 x 7.20 [508 x 305 x 183]	<a href="#">18P1709</a>	—	—	<a href="#">18G1709</a>	—	17.00 x 9.00 [432 x 229]	<a href="#">PDF</a>
<a href="#">1418CA8</a>	\$440.00	20.00 x 12.00 x 9.20 [508 x 305 x 234]	<a href="#">18P1709</a>	—	—	<a href="#">18G1709</a>	—	17.00 x 9.00 [432 x 229]	<a href="#">PDF</a>
<a href="#">1418C6</a>	\$451.00	20.00 x 16.00 x 7.20 [508 x 406 x 183]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>
<a href="#">1418C8</a>	\$472.00	20.00 x 16.00 x 9.20 [508 x 406 x 234]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>
<a href="#">1418C10</a>	\$494.00	20.00 x 16.00 x 11.20 [508 x 406 x 284]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Table continued from previous page

NEMA 12 and 13 Single-Door Wall-Mount									
Part Number	Price	Enclosure Size HxWxD	Subpanels					Size HxW	Drawing Link
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless		
<a href="#">1418C12</a>	\$528.00	20.00 x 16.00 x 13.20 [508 x 406 x 335]	<a href="#">18P1713</a>	<a href="#">18P1713PP</a>	—	<a href="#">18G1713</a>	<a href="#">18P1713S16</a>	17.00 x 13.00 [432 x 330]	<a href="#">PDF</a>
<a href="#">1418D6</a>	\$494.00	20.00 x 20.00 x 7.20 [508 x 508 x 183]	<a href="#">18P1717</a>	<a href="#">18P1717PP</a>	<a href="#">18A1717</a>	<a href="#">18G1717</a>	<a href="#">18P1717S16</a>	17.00 x 17.00 [432 x 432]	<a href="#">PDF</a>
<a href="#">1418D8</a>	\$517.00	20.00 x 20.00 x 9.20 [508 x 508 x 234]	<a href="#">18P1717</a>	<a href="#">18P1717PP</a>	<a href="#">18A1717</a>	<a href="#">18G1717</a>	<a href="#">18P1717S16</a>	17.00 x 17.00 [432 x 432]	<a href="#">PDF</a>
<a href="#">1418D10</a>	\$540.00	20.00 x 20.00 x 11.20 [508 x 508 x 284]	<a href="#">18P1717</a>	<a href="#">18P1717PP</a>	<a href="#">18A1717</a>	<a href="#">18G1717</a>	<a href="#">18P1717S16</a>	17.00 x 17.00 [432 x 432]	<a href="#">PDF</a>
<a href="#">1418ER6</a>	\$554.00	20.00 x 24.00 x 7.20 [508 x 610 x 183]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418ER8</a>	\$568.00	20.00 x 24.00 x 9.20 [508 x 610 x 234]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418AR6</a>	\$451.00	24.00 x 12.00 x 7.20 [610 x 305 x 183]	<a href="#">18P2109</a>	—	—	<a href="#">18G2109</a>	—	21.00 x 9.00 [533 x 229]	<a href="#">PDF</a>
<a href="#">1418AR8</a>	\$472.00	24.00 x 12.00 x 9.20 [610 x 305 x 234]	<a href="#">18P2109</a>	—	—	<a href="#">18G2109</a>	—	21.00 x 9.00 [533 x 229]	<a href="#">PDF</a>
<a href="#">1418AR10</a>	\$495.00	24.00 x 12.00 x 11.20 [610 x 305 x 284]	<a href="#">18P2109</a>	—	—	<a href="#">18G2109</a>	—	21.00 x 9.00 [533 x 229]	<a href="#">PDF</a>
<a href="#">1418H6</a>	\$499.00	24.00 x 16.00 x 7.20 [610 x 406 x 183]	<a href="#">18P2113</a>	—	—	<a href="#">18G2113</a>	<a href="#">18P2113S16</a>	21.00 x 13.00 [533 x 330]	<a href="#">PDF</a>
<a href="#">1418H8</a>	\$509.00	24.00 x 16.00 x 9.20 [610 x 406 x 234]	<a href="#">18P2113</a>	—	—	<a href="#">18G2113</a>	<a href="#">18P2113S16</a>	21.00 x 13.00 [533 x 330]	<a href="#">PDF</a>
<a href="#">1418E6</a>	\$540.00	24.00 x 20.00 x 7.20 [610 x 508 x 183]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418E8</a>	\$568.00	24.00 x 20.00 x 9.20 [610 x 508 x 234]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418E10</a>	\$594.00	24.00 x 20.00 x 11.20 [610 x 508 x 284]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418E12</a>	\$637.00	24.00 x 20.00 x 13.20 [610 x 508 x 335]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418E16</a>	\$692.00	24.00 x 20.00 x 17.20 [610 x 508 x 437]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">1418J6</a>	\$589.00	24.00 x 24.00 x 7.20 [610 x 610 x 183]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">1418J8</a>	\$618.00	24.00 x 24.00 x 9.20 [610 x 610 x 234]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">1418J10</a>	\$647.00	24.00 x 24.00 x 11.20 [610 x 610 x 284]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">1418J12</a>	\$676.00	24.00 x 24.00 x 13.20 [610 x 610 x 335]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">1418J16</a>	\$752.00	24.00 x 24.00 x 17.20 [610 x 610 x 437]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">1418KR8</a>	\$696.00	24.00 x 30.00 x 9.20 [610 x 762 x 234]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418KA8</a>	\$600.00	30.00 x 12.00 x 9.20 [762 x 305 x 234]	<a href="#">18P2709</a>	—	—	<a href="#">18G2709</a>	—	27.00 x 9.00 [686 x 229]	<a href="#">PDF</a>
<a href="#">1418FG6</a>	\$557.00	30.00 x 16.00 x 7.20 [762 x 406 x 183]	<a href="#">18P2713</a>	—	—	<a href="#">18G2713</a>	—	27.00 x 13.00 [686 x 330]	<a href="#">PDF</a>
<a href="#">1418KG8</a>	\$631.00	30.00 x 16.00 x 9.20 [762 x 406 x 234]	<a href="#">18P2713</a>	—	—	<a href="#">18G2713</a>	—	27.00 x 13.00 [686 x 330]	<a href="#">PDF</a>
<a href="#">1418F6</a>	\$620.00	30.00 x 20.00 x 7.20 [762 x 508 x 183]	<a href="#">18P2717</a>	—	—	<a href="#">18G2717</a>	<a href="#">18P2717S16</a>	27.00 x 17.00 [686 x 432]	<a href="#">PDF</a>
<a href="#">1418F8</a>	\$652.00	30.00 x 20.00 x 9.20 [762 x 508 x 234]	<a href="#">18P2717</a>	—	—	<a href="#">18G2717</a>	<a href="#">18P2717S16</a>	27.00 x 17.00 [686 x 432]	<a href="#">PDF</a>
<a href="#">1418F10</a>	\$682.00	30.00 x 20.00 x 11.20 [762 x 508 x 284]	<a href="#">18P2717</a>	—	—	<a href="#">18G2717</a>	<a href="#">18P2717S16</a>	27.00 x 17.00 [686 x 432]	<a href="#">PDF</a>
<a href="#">1418K6</a>	\$680.00	30.00 x 24.00 x 7.20 [762 x 610 x 183]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K8</a>	\$696.00	30.00 x 24.00 x 9.20 [762 x 610 x 234]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K10</a>	\$729.00	30.00 x 24.00 x 11.20 [762 x 610 x 284]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K12</a>	\$762.00	30.00 x 24.00 x 13.20 [762 x 610 x 335]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K16</a>	\$847.00	30.00 x 24.00 x 17.20 [762 x 610 x 437]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K20</a>	\$916.00	30.00 x 24.00 x 21.20 [762 x 610 x 538]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418K24</a>	\$985.00	30.00 x 24.00 x 25.20 [762 x 610 x 640]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">1418KK8</a>	\$808.00	30.00 x 30.00 x 9.20 [762 x 762 x 234]	<a href="#">18P2727</a>	<a href="#">18P2727PP</a>	—	<a href="#">18G2727</a>	<a href="#">18P2727S16</a>	27.00 x 27.00 [686 x 686]	<a href="#">PDF</a>
<a href="#">1418KK12</a>	\$882.00	30.00 x 30.00 x 13.20 [762 x 762 x 335]	<a href="#">18P2727</a>	<a href="#">18P2727PP</a>	—	<a href="#">18G2727</a>	<a href="#">18P2727S16</a>	27.00 x 27.00 [686 x 686]	<a href="#">PDF</a>
<a href="#">1418MR8</a>	\$919.00	30.00 x 36.00 x 9.20 [762 x 914 x 234]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418L6</a>	\$756.00	36.00 x 24.00 x 7.20 [914 x 610 x 183]	<a href="#">18P3321</a>	<a href="#">18P3327PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Table continued from previous page

NEMA 12 and 13 Single-Door Wall-Mount									
Part Number	Price	Enclosure Size HxWxD	Subpanels					Size HxW	Drawing Link
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless		
<a href="#">1418L8</a>	\$776.00	36.00 x 24.00 x 9.20 [914 x 610 x 234]	<a href="#">18P3321</a>	<a href="#">18P3321PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>
<a href="#">1418L10</a>	\$811.00	36.00 x 24.00 x 11.20 [914 x 610 x 284]	<a href="#">18P3321</a>	<a href="#">18P3321PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>
<a href="#">1418L12</a>	\$848.00	36.00 x 24.00 x 13.20 [914 x 610 x 335]	<a href="#">18P3321</a>	<a href="#">18P3321PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>
<a href="#">1418M6</a>	\$878.00	36.00 x 30.00 x 7.20 [914 x 762 x 183]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418M8</a>	\$898.00	36.00 x 30.00 x 9.20 [914 x 762 x 234]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418M10</a>	\$939.00	36.00 x 30.00 x 11.20 [914 x 762 x 284]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418M12</a>	\$979.00	36.00 x 30.00 x 13.20 [914 x 762 x 335]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418M16</a>	\$1,087.00	36.00 x 30.00 x 17.20 [914 x 762 x 437]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418M20</a>	\$1,169.00	36.00 x 30.00 x 21.20 [914 x 762 x 538]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">1418LL8</a>	\$1,008.00	36.00 x 36.00 x 9.20 [914 x 914 x 234]	<a href="#">18P3333</a>	<a href="#">18P3333PP</a>	—	<a href="#">18G3333</a>	<a href="#">18P3333S16</a>	33.00 x 33.00 [838 x 838]	<a href="#">PDF</a>
<a href="#">1418LL12</a>	\$1,098.00	36.00 x 36.00 x 13.20 [914 x 914 x 335]	<a href="#">18P3333</a>	<a href="#">18P3333PP</a>	—	<a href="#">18G3333</a>	<a href="#">18P3333S16</a>	33.00 x 33.00 [838 x 838]	<a href="#">PDF</a>
<a href="#">1418N8</a>	\$880.00	42.00 x 24.00 x 9.20 [1067 x 610 x 234]	<a href="#">18P3921</a>	—	—	<a href="#">18G3921</a>	—	39.00 x 21.00 [991 x 533]	<a href="#">PDF</a>
<a href="#">1418O8</a>	\$1,016.00	42.00 x 30.00 x 9.20 [1067 x 762 x 234]	<a href="#">18P3927</a>	—	—	<a href="#">18G3927</a>	<a href="#">18P3927S16</a>	39.00 x 27.00 [991 x 686]	<a href="#">PDF</a>
<a href="#">1418O10</a>	\$1,061.00	42.00 x 30.00 x 11.20 [1067 x 762 x 284]	<a href="#">18P3927</a>	—	—	<a href="#">18G3927</a>	<a href="#">18P3927S16</a>	39.00 x 27.00 [991 x 686]	<a href="#">PDF</a>
<a href="#">1418O12</a>	\$1,106.00	42.00 x 30.00 x 13.20 [1067 x 762 x 335]	<a href="#">18P3927</a>	—	—	<a href="#">18G3927</a>	<a href="#">18P3927S16</a>	39.00 x 27.00 [991 x 686]	<a href="#">PDF</a>
<a href="#">1418P8</a>	\$1,143.00	42.00 x 36.00 x 9.20 [1067 x 914 x 234]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	—	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">1418P10</a>	\$1,192.00	42.00 x 36.00 x 11.20 [1067 x 914 x 284]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	—	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">1418P12</a>	\$1,212.00	42.00 x 36.00 x 13.20 [1067 x 914 x 335]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	—	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">1418P16</a>	\$1,341.00	42.00 x 36.00 x 17.20 [1067 x 914 x 437]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	—	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">1418Q8</a>	\$964.00	48.00 x 24.00 x 9.20 [1219 x 610 x 234]	<a href="#">18P4521</a>	—	—	<a href="#">18G4521</a>	—	45.00 x 21.00 [1143 x 533]	<a href="#">PDF</a>
<a href="#">1418R8</a>	\$1,109.00	48.00 x 30.00 x 9.20 [1219 x 762 x 234]	<a href="#">18P4527</a>	—	—	<a href="#">18G4527</a>	—	45.00 x 27.00 [1143 x 686]	<a href="#">PDF</a>
<a href="#">1418R10</a>	\$1,161.00	48.00 x 30.00 x 11.20 [1219 x 762 x 284]	<a href="#">18P4527</a>	—	—	<a href="#">18G4527</a>	—	45.00 x 27.00 [1143 x 686]	<a href="#">PDF</a>
<a href="#">1418S8</a>	\$1,227.00	48.00 x 36.00 x 9.20 [1219 x 914 x 234]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418S10</a>	\$1,279.00	48.00 x 36.00 x 11.20 [1219 x 914 x 284]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418S12</a>	\$1,331.00	48.00 x 36.00 x 13.20 [1219 x 914 x 335]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418S16</a>	\$1,435.00	48.00 x 36.00 x 17.20 [1219 x 914 x 437]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418S20</a>	\$1,577.00	48.00 x 36.00 x 21.20 [1219 x 914 x 538]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418T8</a>	\$1,483.00	60.00 x 36.00 x 9.20 [1524 x 914 x 234]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">1418T10</a>	\$1,507.00	60.00 x 36.00 x 11.20 [1524 x 914 x 284]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">1418T12</a>	\$1,567.00	60.00 x 36.00 x 13.20 [1524 x 914 x 335]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">1418T16</a>	\$1,726.00	60.00 x 36.00 x 17.20 [1524 x 914 x 437]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">1418T20</a>	\$1,845.00	60.00 x 36.00 x 21.20 [1524 x 914 x 538]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">1418U12</a>	\$1,603.00	72.00 x 30.00 x 13.20 [1829 x 762 x 335]	<a href="#">18P6927</a>	—	—	<a href="#">18G6927</a>	—	69.00 x 27.00 [1753 x 686]	<a href="#">PDF</a>
<a href="#">1418U16</a>	\$1,729.00	72.00 x 30.00 x 17.20 [1829 x 762 x 437]	<a href="#">18P6927</a>	—	—	<a href="#">18G6927</a>	—	69.00 x 27.00 [1753 x 686]	<a href="#">PDF</a>
<a href="#">1418U20</a>	\$1,877.00	72.00 x 30.00 x 21.20 [1829 x 762 x 538]	<a href="#">18P6927</a>	—	—	<a href="#">18G6927</a>	—	69.00 x 27.00 [1753 x 686]	<a href="#">PDF</a>
<a href="#">1418U24</a>	\$1,982.00	72.00 x 30.00 x 25.20 [1829 x 762 x 640]	<a href="#">18P6927</a>	—	—	<a href="#">18G6927</a>	—	69.00 x 27.00 [1753 x 686]	<a href="#">PDF</a>
<a href="#">1418V12</a>	\$1,801.00	72.00 x 36.00 x 13.20 [1829 x 914 x 335]	<a href="#">18P6933</a>	—	—	<a href="#">18G6933</a>	—	69.00 x 33.00 [1753 x 838]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 12 and 13 Single-Door Wall-Mount



## Dimensions

