


NEMA 12 Hinged Screw Cover Wall-Mount

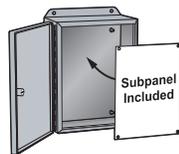

Applications

- Designed to house electrical, electronic, hydraulic, or pneumatic controls and instruments.
- Provides some protection from falling dirt, dust, oil, and water.

Construction

- Formed from 14-gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14-gauge welded mounting brackets
- Continuously hinged cover is secured with plated screws, threaded into sealed wells.
- Oil-resistant gaskets are permanently secured.
- A removable 12-gauge subpanel is included.
- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided on the enclosure.
- A literature pocket is provided for the inside of the door.

Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray recoatable powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 12 [UL File E65324]
- Complies with
 - NEMA Type 12
 - IEC 60529, IP54



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

NEMA 12 Hinged Screw Cover Wall-Mount										
Part Number	Price	Enclosure Size HxWxD	Subpanels					Size HxW	Drawing Link	
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless			
1418JB7	\$422.00	16.31 x 12.38 x 7.17 [414 x 314 x 182]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00 [330 x 229]	PDF	
1418JC7	\$442.00	20.31 x 16.38 x 7.17 [516 x 416 x 182]	18P1713	18P1713PP	—	18G1713	18P1713S16	17.00 x 13.00 [432 x 330]	PDF	
1418JC9	\$471.00	20.31 x 16.38 x 9.17 [516 x 416 x 233]	18P1713	18P1713PP	—	18G1713	18P1713S16	17.00 x 13.00 [432 x 330]	PDF	
1418JD7	\$494.00	20.31 x 20.38 x 7.17 [516 x 518 x 182]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00 [432 x 432]	PDF	
1418JD9	\$526.00	20.31 x 20.38 x 9.17 [516 x 518 x 233]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00 [432 x 432]	PDF	
1418JE7	\$554.00	24.31 x 20.38 x 7.17 [617 x 518 x 182]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00 [533 x 432]	PDF	
1418JE9	\$588.00	24.31 x 20.38 x 9.17 [617 x 518 x 233]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00 [533 x 432]	PDF	
1418JF7	\$632.00	30.31 x 20.38 x 7.17 [770 x 518 x 182]	18P2717	—	—	18G2717	18P2717S16	27.00 x 17.00 [686 x 432]	PDF	
1418JF9	\$671.00	30.31 x 20.38 x 9.17 [770 x 518 x 233]	18P2717	—	—	18G2717	18P2717S16	27.00 x 17.00 [686 x 432]	PDF	
1418JJ11	\$722.00	24.31 x 24.38 x 11.17 [617 x 619 x 284]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF	
1418JJ7	\$613.00	24.31 x 24.38 x 7.17 [617 x 619 x 182]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF	
1418JJ9	\$651.00	24.31 x 24.38 x 9.17 [617 x 619 x 233]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00 [533 x 533]	PDF	
1418JK13	\$832.00	30.31 x 24.38 x 13.17 [770 x 619 x 335]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF	
1418JK7	\$705.00	30.31 x 24.38 x 7.17 [770 x 619 x 182]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF	
1418JK9	\$747.00	30.31 x 24.38 x 9.17 [770 x 619 x 233]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00 [686 x 533]	PDF	
1418JL7	\$798.00	36.31 x 24.38 x 7.17 [922 x 619 x 182]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00 [838 x 533]	PDF	
1418JL9	\$845.00	36.31 x 24.38 x 9.17 [922 x 619 x 233]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00 [838 x 533]	PDF	
1418JL11	\$893.00	36.31 x 24.38 x 11.17 [922 x 619 x 284]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00 [838 x 533]	PDF	
1418JM13	\$1,096.00	36.31 x 30.38 x 13.17 [922 x 772 x 335]	18P3327	18P3327PP	18A3327	18G3327	—	33.00 x 27.00 [838 x 686]	PDF	
1418JM9	\$993.00	36.31 x 30.38 x 9.17 [922 x 772 x 233]	18P3327	18P3327PP	18A3327	18G3327	—	33.00 x 27.00 [838 x 686]	PDF	
1418JO9	\$1,136.00	42.31 x 30.38 x 9.17 [1075 x 772 x 233]	18P3927	—	—	18G3927	18P3927S16	39.00 x 27.00 [991 x 686]	PDF	
1418JP9	\$1,297.00	42.31 x 36.38 x 9.17 [1075 x 924 x 233]	18P3933	—	—	18G3933	—	39.00 x 33.00 [991 x 838]	PDF	
1418JS11	\$1,424.00	48.31 x 36.38 x 11.17 [1227 x 924 x 284]	18P4533	—	18A4533	18G4533	—	45.00 x 33.00 [1143 x 838]	PDF	

Note: Dimensions in inches [millimeters].

NEMA 12 Hinged Screw Cover Wall-Mount



Dimensions

