


NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

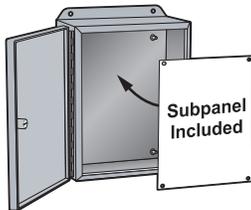

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

Construction

- Formed 14-gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Door stiffeners are provided in the larger enclosures for extra rigidity.
- Welded brackets provide for enclosure mounting.
- Formed lip on door and enclosure excludes flowing liquids and contaminants.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin.
- Door is secured with easily operated stainless steel clamps.
- Provision for padlocking.
- Seamless poured-in-place gasket.
- A removable 12-gauge subpanel is included.
- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.
- A literature pocket is provided for the inside of the door.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount							
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Included Subpanel	Subpanel HxW	Drawing Link
1418N4SSB6	\$840.00	1418N4S16B6	\$954.00	16.00 x 12.00 x 7.20 [406 x 305 x 183]	18P1309	13.00 x 9.00 [330 x 229]	PDF
1418N4SSB8	\$896.00	1418N4S16B8	\$1,084.00	16.00 x 12.00 x 9.20 [406 x 305 x 234]	18P1309	13.00 x 9.00 [330 x 229]	PDF
1418N4SSG6	\$933.00	1418N4S16G6	\$1,128.00	16.00 x 16.00 x 7.20 [406 x 406 x 183]	18P1713	17.00 x 13.00 [432 x 330]	PDF
1418N4SSCR6	\$1,030.00	1418N4S16CR6	\$1,243.00	16.00 x 20.00 x 7.20 [406 x 508 x 183]	18P1713	17.00 x 13.00 [432 x 330]	PDF
1418N4SSC6	\$1,030.00	1418N4S16C6	\$1,169.00	20.00 x 16.00 x 7.20 [508 x 406 x 183]	18P1713	17.00 x 13.00 [432 x 330]	PDF
1418N4SSC8	\$1,101.00	1418N4S16C8	\$1,249.00	20.00 x 16.00 x 9.20 [508 x 406 x 234]	18P1713	17.00 x 13.00 [432 x 330]	PDF
1418N4SSC10	\$1,172.00	1418N4S16C10	\$1,415.00	20.00 x 16.00 x 11.20 [508 x 406 x 284]	18P1713	17.00 x 13.00 [432 x 330]	PDF
1418N4SSD6	\$1,140.00	1418N4S16D6	\$1,374.00	20.00 x 20.00 x 7.20 [508 x 508 x 183]	18P1717	17.00 x 17.00 [432 x 432]	PDF
1418N4SSD8	\$1,256.00	1418N4S16D8	\$1,460.00	20.00 x 20.00 x 9.20 [508 x 508 x 234]	18P1717	17.00 x 17.00 [432 x 432]	PDF
1418N4SSER8	\$1,346.00	1418N4S16ER8	\$1,618.00	20.00 x 24.00 x 9.20 [508 x 610 x 234]	18P1717	17.00 x 17.00 [432 x 432]	PDF
1418N4SSH8	\$1,203.00	1418N4S16H8	\$1,451.00	24.00 x 16.00 x 9.20 [610 x 406 x 234]	18P2113	21.00 x 13.00 [533 x 330]	PDF
1418N4SSE10	\$1,435.00	1418N4S16E10	\$1,725.00	24.00 x 20.00 x 11.20 [610 x 508 x 284]	18P2117	21.00 x 17.00 [533 x 432]	PDF
1418N4SSE6	\$1,255.00	1418N4S16E6	\$1,515.00	24.00 x 20.00 x 7.20 [610 x 508 x 183]	18P2117	21.00 x 17.00 [533 x 432]	PDF
1418N4SSE8	\$1,346.00	1418N4S16E8	\$1,528.00	24.00 x 20.00 x 9.20 [610 x 508 x 234]	18P2117	21.00 x 17.00 [533 x 432]	PDF
1418N4SSJ6	\$1,440.00	1418N4S16J6	\$1,669.00	24.00 x 24.00 x 7.20 [610 x 610 x 183]	18P2121	21.00 x 21.00 [533 x 533]	PDF
1418N4SSJ8	\$1,483.00	1418N4S16J8	\$1,682.00	24.00 x 24.00 x 9.20 [610 x 610 x 234]	18P2121	21.00 x 21.00 [533 x 533]	PDF
1418N4SSJ12	\$1,675.00	1418N4S16J12	\$2,016.00	24.00 x 24.00 x 13.20 [610 x 610 x 335]	18P2121	21.00 x 21.00 [533 x 533]	PDF
1418N4SSKR8	\$1,691.00	1418N4S16KR8	\$2,032.00	24.00 x 30.00 x 9.20 [610 x 762 x 234]	18P2721	27.00 x 21.00 [686 x 533]	PDF
1418N4SSF8	\$1,528.00	1418N4S16F8	\$1,836.00	30.00 x 20.00 x 9.20 [762 x 508 x 234]	18P2717	27.00 x 17.00 [686 x 432]	PDF
1418N4SSK8	\$1,691.00	1418N4S16K8	\$1,915.00	30.00 x 24.00 x 9.20 [762 x 610 x 234]	18P2721	27.00 x 21.00 [686 x 533]	PDF
1418N4SSK10	\$1,850.00	1418N4S16K10	\$2,149.00	30.00 x 24.00 x 11.20 [762 x 610 x 284]	18P2721	27.00 x 21.00 [686 x 533]	PDF
1418N4SSK12	\$1,902.00	1418N4S16K12	\$2,156.00	30.00 x 24.00 x 13.20 [762 x 610 x 335]	18P2721	27.00 x 21.00 [686 x 533]	PDF
1418N4SSK16	\$2,116.00	1418N4S16K16	\$2,551.00	30.00 x 24.00 x 17.20 [762 x 610 x 437]	18P2721	27.00 x 21.00 [686 x 533]	PDF
1418N4SSKK8	\$1,950.00	1418N4S16KK8	\$2,341.00	30.00 x 30.00 x 9.20 [762 x 762 x 234]	18P2727	27.00 x 27.00 [686 x 686]	PDF
1418N4SSL8	\$1,897.00	1418N4S16L8	\$2,277.00	36.00 x 24.00 x 9.20 [914 x 610 x 234]	18P3321	33.00 x 21.00 [838 x 533]	PDF
1418N4SSL10	\$2,016.00	1418N4S16L10	\$2,423.00	36.00 x 24.00 x 11.20 [914 x 610 x 284]	18P3321	33.00 x 21.00 [838 x 533]	PDF
1418N4SSM8	\$2,194.00	1418N4S16M8	\$2,481.00	36.00 x 30.00 x 9.20 [914 x 762 x 234]	18P3327	33.00 x 27.00 [838 x 686]	PDF
1418N4SSM10	\$2,322.00	1418N4S16M10	\$2,788.00	36.00 x 30.00 x 11.20 [914 x 762 x 284]	18P3327	33.00 x 27.00 [838 x 686]	PDF
1418N4SSLL12	\$2,763.00	1418N4S16LL12	\$3,317.00	36.00 x 36.00 x 13.20 [914 x 914 x 335]	18P3327	33.00 x 27.00 [838 x 686]	PDF
1418N4SSM12	\$2,455.00	1418N4S16M12	\$2,948.00	36.00 x 30.00 x 13.20 [914 x 762 x 335]	18P3327	33.00 x 27.00 [838 x 686]	PDF
1418N4SSM16	\$2,714.00	1418N4S16M16	\$3,264.00	36.00 x 30.00 x 17.20 [914 x 762 x 437]	18P3327	33.00 x 27.00 [838 x 686]	PDF
1418N4SSO10	\$2,580.00	1418N4S16O10	\$3,096.00	42.00 x 30.00 x 11.20 [1067 x 762 x 284]	18P3927	39.00 x 27.00 [991 x 686]	PDF
1418N4SSP8	\$2,759.00	1418N4S16P8	\$3,284.00	42.00 x 36.00 x 9.20 [1067 x 914 x 234]	18P3933	39.00 x 33.00 [991 x 838]	PDF
1418N4SSS8	\$3,045.00	1418N4S16S8	\$3,650.00	48.00 x 36.00 x 9.20 [1219 x 914 x 234]	18P4533	45.00 x 33.00 [1143 x 838]	PDF
1418N4SSS10	\$3,366.00	1418N4S16S10	\$3,902.00	48.00 x 36.00 x 11.20 [1219 x 914 x 284]	18P4533	45.00 x 33.00 [1143 x 838]	PDF
1418N4SSS12	\$3,378.00	1418N4S16S12	\$4,053.00	48.00 x 36.00 x 13.20 [1219 x 914 x 335]	18P4533	45.00 x 33.00 [1143 x 838]	PDF
1418N4SSS16	\$3,708.00	1418N4S16S16	\$4,202.00	48.00 x 36.00 x 17.20 [1219 x 914 x 437]	18P4533	45.00 x 33.00 [1143 x 838]	PDF
1418N4SST12	\$3,996.00	1418N4S16T12	\$4,791.00	60.00 x 36.00 x 13.20 [1524 x 914 x 335]	18P5733	57.00 x 33.00 [1448 x 838]	PDF
1418N4SST16	\$4,570.00	1418N4S16T16	\$5,299.00	60.00 x 36.00 x 17.20 [1524 x 914 x 437]	18P5733	57.00 x 33.00 [1448 x 838]	PDF

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Dimensions

