



Quality Products. Service Excellence.


## Steel Instrument 1458 Series

### Key Features:



- Heavy duty, 18 gauge steel - top & bottom case in satin black or gulf blue powder coat.
- Available with either solid or vented tops and bottoms.
- Easy to machine 0.064" thick aluminum front and rear panels (one satin black and one contemporanea grey for each enclosure).
- Symmetrical design so either end panel can be used as a front or rear panel.
- 6-32 Philips nickel plated screws and self-adhesive rubber feet included.
- Replacement screws **1421J8** (Pkg. of 6, 6-32 Philips head screws).

Shown unassembled

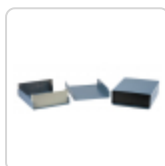

### Accessories

- Sheet Metal Screws

### Enclosures

Solid Top & Bottom		Vented Top & Bottom		Width	Depth	Height
Satin Black	Satin Blue	Satin Black	Satin Blue			
1458A3	1458A3B	1458VA3	1458VA3B	4.00	4.00	3.00
1458B4	1458B4B	1458VB4	1458VB4B	6.00	4.00	4.00
1458C3	1458C3B	1458VC3	1458VC3B	6.00	6.00	3.00
1458C4	1458C4B	1458VC4	1458VC4B	6.00	6.00	4.00
1458D3	1458D3B	1458VD3	1458VD3B	8.00	8.00	3.00
1458D4	1458D4B	1458VD4	1458VD4B	8.00	8.00	4.00
1458D5	1458D5B	1458VD5	1458VD5B	8.00	8.00	5.00
1458E3	1458E3B	1458VE3	1458VE3B	8.00	10.00	3.00
1458E4	1458E4B	1458VE4	1458VE4B	8.00	10.00	4.00
1458E5	1458E5B	1458VE5	1458VE5B	8.00	10.00	5.00
1458G3	1458G3B	1458VG3	1458VG3B	10.00	8.00	3.00
1458G4	1458G4B	1458VG4	1458VG4B	10.00	8.00	4.00
1458G5	1458G5B	1458VG5	1458VG5B	10.00	8.00	5.00

Tags: instrument enclosure, steel, instrument

Data subject to change without notice

