


NEMA 12 Lay-In Wireway

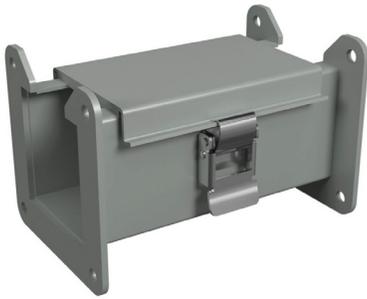

Features

- Designed to enclose and protect electrical wiring from dirt, dust, oil, and water.
- All sections and fittings are completely open on each side to allow wires and cables to be placed into the wireway without "pulling through".

Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

NEMA 12 Lay-In Wireway

Part Number	Price	Overall Size HxWxD	Drawing Link
1485B6	\$96.00	2.50 x 2.50 x 6.00 [64 x 64 x 152]	PDF
1485B12	\$113.00	2.50 x 2.50 x 12.00 [64 x 64 x 305]	PDF
1485B24	\$147.00	2.50 x 2.50 x 24.00 [64 x 64 x 610]	PDF
1485B36	\$178.00	2.50 x 2.50 x 36.00 [64 x 64 x 914]	PDF
1485B48	\$211.00	2.50 x 2.50 x 48.00 [64 x 64 x 1219]	PDF
1485B60	\$243.00	2.50 x 2.50 x 60.00 [64 x 64 x 1524]	PDF
1485B120	\$403.00	2.50 x 2.50 x 120.00 [64 x 64 x 3048]	PDF
1485C6	\$117.00	4.00 x 4.00 x 6.00 [102 x 102 x 152]	PDF
1485C12	\$135.00	4.00 x 4.00 x 12.00 [102 x 102 x 305]	PDF
1485C24	\$172.00	4.00 x 4.00 x 24.00 [102 x 102 x 610]	PDF
1485C36	\$209.00	4.00 x 4.00 x 36.00 [102 x 102 x 914]	PDF
1485C48	\$246.00	4.00 x 4.00 x 48.00 [102 x 102 x 1219]	PDF
1485C60	\$283.00	4.00 x 4.00 x 60.00 [102 x 102 x 1524]	PDF
1485C120	\$465.00	4.00 x 4.00 x 120.00 [102 x 102 x 3048]	PDF
1485D6	\$143.00	6.00 x 6.00 x 6.00 [152 x 152 x 152]	PDF
1485D12	\$172.00	6.00 x 6.00 x 12.00 [152 x 152 x 305]	PDF
1485D24	\$230.00	6.00 x 6.00 x 24.00 [152 x 152 x 610]	PDF
1485D36	\$288.00	6.00 x 6.00 x 36.00 [152 x 152 x 914]	PDF
1485D48	\$346.00	6.00 x 6.00 x 48.00 [152 x 152 x 1219]	PDF
1485D60	\$405.00	6.00 x 6.00 x 60.00 [152 x 152 x 1524]	PDF
1485D120	\$694.00	6.00 x 6.00 x 120.00 [152 x 152 x 3048]	PDF
1485E6	\$217.00	8.00 x 8.00 x 6.00 [203 x 203 x 152]	PDF
1485E12	\$254.00	8.00 x 8.00 x 12.00 [203 x 203 x 305]	PDF
1485E24	\$330.00	8.00 x 8.00 x 24.00 [203 x 203 x 610]	PDF
1485E36	\$405.00	8.00 x 8.00 x 36.00 [203 x 203 x 914]	PDF
1485E48	\$479.00	8.00 x 8.00 x 48.00 [203 x 203 x 1219]	PDF
1485E60	\$554.00	8.00 x 8.00 x 60.00 [203 x 203 x 1524]	PDF
1485E120	\$933.00	8.00 x 8.00 x 120.00 [203 x 203 x 3048]	PDF
1485F6	\$228.00	12.00 x 6.00 x 6.00 [305 x 152 x 152]	PDF
1485F12	\$286.00	12.00 x 6.00 x 12.00 [305 x 152 x 305]	PDF
1485F24	\$403.00	12.00 x 6.00 x 24.00 [305 x 152 x 610]	PDF
1485F36	\$521.00	12.00 x 6.00 x 36.00 [305 x 152 x 914]	PDF
1485F48	\$637.00	12.00 x 6.00 x 48.00 [305 x 152 x 1219]	PDF
1485F60	\$754.00	12.00 x 6.00 x 60.00 [305 x 152 x 1524]	PDF
1485F120	\$1,346.00	12.00 x 6.00 x 120.00 [305 x 152 x 3048]	PDF

Note: Dimensions in inches [millimeters].



Construction

- Bodies and covers are formed from 14-gauge steel with 10-gauge steel flanges.
- Top-open flanges allow cables to lay inside when doors open.
- 12 in [305 mm] x 6 in [152 mm] size has a 12-gauge steel body with a 14-gauge cover.
- Smooth, continuously welded seams.
- Interior surfaces are smooth to prevent wire damage during installation.
- Butt-hinged cover is secured with easily operated quick release clamps.
- Solid, oil-resistant gaskets are permanently secured between flanges when sections and fittings are bolted together.
- Sealing plate and one gasket kit, complete with hardware is provided with each straight section or fitting.
- Flange junctions are sealed with gasket sealing plates, which are put in place after wiring is completed.
 - One gasket is supplied with all straight sections and most fittings.
- Sections and components are finished in ANSI 61 gray powder coating.

Notes

- To join a wireway section or fitting to an enclosure, a box connector is required.
- To join two wireway sections, or to join a wireway section to a fitting, a flat sealing plate is required at each junction; necessary kits are supplied with each section and fitting. Extra kits may be ordered if necessary.
- To join a lay-in wireway section or fitting to a closure plate, a box connector, or cutoff fitting, an angle sealing plate is required at each junction.

Listings

- UL 870 Type 1 [File E186830]
- CSA Type 1 [File LL21312]
- Complies with:
 - NEMA Type 12
 - IEC 60529, IP54



NEMA 12 Lay-In Wireway Fittings



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	



Snap-on Flat Sealing Plates			
Part Number	Price	Size Size HxW	Drawing Link
1485BSM	\$16.00	2.50 x 2.50 [64 x 64]	PDF
1485CSM	\$18.75	4.00 x 4.00 [102 x 102]	PDF
1485DSM	\$24.00	6.00 x 6.00 [152 x 152]	PDF
1485ESM	\$31.50	8.00 x 8.00 [203 x 203]	PDF
1485FSM	\$39.00	12.00 x 6.00 [305 x 152]	PDF
Notes: Dimensions in inches [millimeters]. Maintains ratings on CSA and UL approved wireway.			



Angle Sealing Plate			
Part Number	Price	Size HxW	Drawing Link
1485BS9	\$20.00	2.50 x 2.50 [64 x 64]	PDF
1485CS9	\$23.00	4.00 x 4.00 [102 x 102]	PDF
1485DS9	\$28.50	6.00 x 6.00 [152 x 152]	PDF
1485ES9	\$37.00	8.00 x 8.00 [203 x 203]	PDF
1485FS9	\$46.50	12.00 x 6.00 [305 x 152]	PDF
Notes: Dimensions in inches [millimeters]. Maintains ratings on CSA and UL approved wireway.			

Features

- For connecting wireway to an enclosure
- One angle sealing plate included



Box Entry Swivel Nipples			
Part Number	Price	Size HxWxD	Drawing Link
1485BV1	\$132.00	2.50 x 2.50 x 2.25 [64 x 64 x 57]	PDF
1485CV1	\$165.00	4.00 x 4.00 x 2.25 [102 x 102 x 57]	PDF
1485DV1	\$206.00	6.00 x 6.00 x 2.25 [152 x 152 x 57]	PDF
1485EV1	\$297.00	8.00 x 8.00 x 2.25 [203 x 203 x 57]	PDF
Notes: Dimensions in inches [millimeters]. Maintains ratings on CSA and UL approved wireway.			

One angle sealing plate included.



Standard Swivel Nipples			
Part Number	Price	Size HxWxD	Drawing Link
1485BV2	\$132.00	2.50 x 2.50 x 2.25 [64 x 64 x 57]	PDF
1485CV2	\$165.00	4.00 x 4.00 x 2.25 [102 x 102 x 57]	PDF
1485DV2	\$206.00	6.00 x 6.00 x 2.25 [152 x 152 x 57]	PDF
1485EV2	\$297.00	8.00 x 8.00 x 2.25 [203 x 203 x 57]	PDF
Notes: Dimensions in inches [millimeters]. Maintains ratings on CSA and UL approved wireway.			

Two angle sealing plates included.

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

Features

- Allows for easy alignment of sections or fittings
- Carbon steel flanges
- Flexible "bellows" middle section



Flexible Fittings

Part Number	Price	Adjustment Size	Drawing Link
1485BFF	\$230.00	2.5 x 2.5 x 3 to 10 [64 x 64 x 76 to 254]	PDF
1485CFF	\$258.00	4 x 4 x 3 to 10 [102 x 102 x 76 to 254]	PDF
1485DFF	\$327.00	6 x 6 x 3 to 10 [152 x 152 x 76 to 254]	PDF
1485EFF	\$450.00	8 x 8 x 3 to 10 [203 x 203 x 76 to 254]	PDF

Note: Dimensions in inches [millimeters].

Features

- Allows length adjustment of 2 in to 7 in [50.8 to 177.8 mm]
- Special Sealing plate included
- Does not meet CSA or UL requirements



Adjustable Fittings

Part Number	Price	Adjustment Size	Drawing Link
1485BX	\$160.00	2.5 x 2.5 x 2 to 7 [64 x 64 x 51 to 178]	PDF
1485CX	\$196.00	4 x 4 x 2 to 7 [102 x 102 x 51 to 178]	PDF
1485DX	\$223.00	6 x 6 x 2 to 7 [152 x 152 x 51 to 178]	PDF
1485EX	\$320.00	8 x 8 x 2 to 7 [203 x 203 x 51 to 178]	PDF
1485FX	\$425.00	12 x 6 x 2 to 7 [305 x 152 x 51 to 178]	PDF

Note: Dimensions in inches [millimeters].



Cross Fittings

Part Number	Price	Size HxWxD	Drawing Link
1485BY	\$290.00	2.50 x 2.50 [64 x 64]	PDF
1485CY	\$368.00	4.00 x 4.00 [102 x 102]	PDF
1485DY	\$439.00	6.00 x 6.00 [152 x 152]	PDF
1485EY	\$567.00	8.00 x 8.00 [203 x 203]	PDF
1485FY	\$573.00	12.00 x 6.00 [305 x 152]	PDF

Note: Dimensions in inches [millimeters].

Three flat sealing plates included.

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Features

- Body comes in two pieces:
 - Cut off one piece, shorten cover, and weld together
- Includes angle sealing plate and flat sealing plate
- Does not meet CSA or UL requirements



Lay-in Cut-off Fittings			
Part Number	Price	Size HxWxD	Drawing Link
1485BW1	\$171.00	2.5 x 2.5 x 9 to 15 [64 x 64 x 229 to 381]	PDF
1485CW1	\$192.00	4 x 4 x 9 to 15 [102 x 102 x 229 to 381]	PDF
1485DW1	\$220.00	6 x 6 x 9 to 15 [152 x 152 x 229 to 381]	PDF
1485EW1	\$286.00	8 x 8 x 9 to 15 [203 x 203 x 229 to 381]	PDF
1485FW1	\$398.00	12 x 6 x 9 to 15 [305 x 152 x 229 to 381]	PDF

Note: Dimensions in inches [millimeters].

Features

- Cut-off body and weld-on flange
- One angle sealing plate included
- Does not meet CSA or UL requirements



Pull-Through Cut-Off Fittings			
Part Number	Price	Size HxWxD	Drawing Link
1485BW2	\$90.00	2.5 x 2.5 x up to 12 [64 x 64 x 0 to 305]	PDF
1485CW2	\$107.00	4 x 4 x up to 12 [102 x 102 x 0 to 305]	PDF
1485DW2	\$135.00	6 x 6 x up to 12 [152 x 152 x 0 to 305]	PDF
1485EW2	\$197.00	8 x 8 x up to 12 [203 x 203 x 0 to 305]	PDF
1485FW2	\$229.00	12 x 6 x up to 12 [305 x 152 x 0 to 305]	PDF

Note: Dimensions in inches [millimeters].

Features

- One flat sealing plate included
- Lay-in nipples come with a special sealing plate which cannot be used adjacent to swivel nipples (use 1487 series nipples)



Wireway Nipples				
Part Number	Price	Overall Size HxWxD	Nipple Size	Drawing Link
1485BM1	\$80.00	2.50 x 2.50 x 1.00 [64 x 64 x 25]	1 [25.4]	PDF
1485BM2	\$87.00	2.50 x 2.50 x 2.00 [64 x 64 x 51]	2 [50.8]	PDF
1485BM3	\$94.00	2.50 x 2.50 x 3.00 [64 x 64 x 76]	3 [76.2]	PDF
1485CM1	\$104.00	4.00 x 4.00 x 1.00 [102 x 102 x 25]	1 [25.4]	PDF
1485CM2	\$113.00	4.00 x 4.00 x 2.00 [102 x 102 x 51]	2 [50.8]	PDF
1485CM3	\$123.00	4.00 x 4.00 x 3.00 [102 x 102 x 76]	3 [76.2]	PDF
1485DM1	\$123.00	6.00 x 6.00 x 1.00 [152 x 152 x 25]	1 [25.4]	PDF
1485DM2	\$133.00	6.00 x 6.00 x 2.00 [152 x 152 x 51]	2 [50.8]	PDF
1485DM3	\$143.00	6.00 x 6.00 x 3.00 [152 x 152 x 76]	3 [76.2]	PDF

Note: Dimensions in inches [millimeters].

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	



Top Elbow Opening



Inside Elbow Opening



Outside Elbow Opening

45° Elbows				
Part Number	Price	Size HxW	Elbow Opening	Drawing Link
1485B4N	\$178.00	2.50 x 2.50 [64 x 64]	Top	PDF
1485B4P	\$178.00	2.50 x 2.50 [64 x 64]	Inside	PDF
1485B4Q	\$178.00	2.50 x 2.50 [64 x 64]	Outside	PDF
1485C4N	\$226.00	4.00 x 4.00 [102 x 102]	Top	PDF
1485C4P	\$226.00	4.00 x 4.00 [102 x 102]	Inside	PDF
1485C4Q	\$226.00	4.00 x 4.00 [102 x 102]	Outside	PDF
1485D4N	\$268.00	6.00 x 6.00 [152 x 152]	Top	PDF
1485D4P	\$268.00	6.00 x 6.00 [152 x 152]	Inside	PDF
1485D4Q	\$268.00	6.00 x 6.00 [152 x 152]	Outside	PDF
1485E4N	\$365.00	8.00 x 8.00 [203 x 203]	Top	PDF
1485E4P	\$365.00	8.00 x 8.00 [203 x 203]	Inside	PDF
1485E4Q	\$365.00	8.00 x 8.00 [203 x 203]	Outside	PDF
1485F4N	\$399.00	12.00 x 6.00 [305 x 152]	Top	PDF

Note: Dimensions in inches [millimeters].

90° Elbows				
Part Number	Price	Size HxW	Elbow Opening	Drawing Link
1485B9N	\$178.00	2.50 x 2.50 [64 x 64]	Top	PDF
1485B9P	\$178.00	2.50 x 2.50 [64 x 64]	Inside	PDF
1485B9Q	\$178.00	2.50 x 2.50 [64 x 64]	Outside	PDF
1485C9N	\$226.00	4.00 x 4.00 [102 x 102]	Top	PDF
1485C9P	\$226.00	4.00 x 4.00 [102 x 102]	Inside	PDF
1485C9Q	\$226.00	4.00 x 4.00 [102 x 102]	Outside	PDF
1485D9N	\$268.00	6.00 x 6.00 [152 x 152]	Top	PDF
1485D9P	\$268.00	6.00 x 6.00 [152 x 152]	Inside	PDF
1485D9Q	\$268.00	6.00 x 6.00 [152 x 152]	Outside	PDF
1485E9N	\$365.00	8.00 x 8.00 [203 x 203]	Top	PDF
1485E9P	\$365.00	8.00 x 8.00 [203 x 203]	Inside	PDF
1485E9Q	\$365.00	8.00 x 8.00 [203 x 203]	Outside	PDF
1485F9N	\$399.00	12.00 x 6.00 [305 x 152]	Top	PDF
1485F9P	\$399.00	12.00 x 6.00 [305 x 152]	Inside	PDF
1485F9Q	\$399.00	12.00 x 6.00 [305 x 152]	Outside	PDF

Note: Dimensions in inches [millimeters].

One flat sealing plate included.



Top Elbow Opening



Inside Elbow Opening



Outside Elbow Opening

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.



Top Opening



Outside and Top Opening



Tee Fitting, Top Opening				
Part Number	Price	Size	Opening	Drawing Link
1485BTN	\$212.00	2.50 x 2.50 [64 x 64]	Top	PDF
1485BTQ	\$243.00	2.50 x 2.50 [64 x 64]	Outside and Top	PDF
1485CTN	\$274.00	4.00 x 4.00 [102 x 102]	Top	PDF
1485CTQ	\$313.00	4.00 x 4.00 [102 x 102]	Outside and Top	PDF
1485DTN	\$327.00	6.00 x 6.00 [152 x 152]	Top	PDF
1485DTQ	\$375.00	6.00 x 6.00 [152 x 152]	Outside and Top	PDF
1485ETN	\$392.00	8.00 x 8.00 [203 x 203]	Top	PDF
1485ETQ	\$450.00	8.00 x 8.00 [203 x 203]	Outside and Top	PDF
1485FTN	\$440.00	12.00 x 6.00 [305 x 152]	Top	PDF

Note: Dimensions in inches [millimeters].

Two flat sealing plates included.

Reducers			
Part Number	Price	Reduces Size	Drawing Link
1485CRE	\$140.00	4.00 x 4.00.20 [102 x 102 x 5]	PDF
1485DRE	\$172.00	6.00 x 6.00 x 4.00 [152 x 152 x 102]	PDF
1485ERE	\$215.00	8.00 x 8.00 x 6.00 [203 x 203 x 152]	PDF
1485FRE	\$258.00	12.00 x 6.00 x 4.00 [305 x 152 x 102]	PDF
1485FRED	\$258.00	12.00 x 6.00 x 6.00 [305 x 152 x 152]	PDF

Note: Dimensions in inches [millimeters].

Box Connectors			
Part Number	Price	Size	Drawing Link
1485BK	\$37.00	2.50 x 2.50 [64 x 64]	PDF
1485CK	\$45.50	4.00 x 4.00 [102 x 102]	PDF
1485DK	\$55.00	6.00 x 6.00 [152 x 152]	PDF
1485EK	\$73.00	8.00 x 8.00 [203 x 203]	PDF
1485FK	\$148.00	12.00 x 6.00 [305 x 152]	PDF

Note: Dimensions in inches [millimeters].


One angle sealing plate included.

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

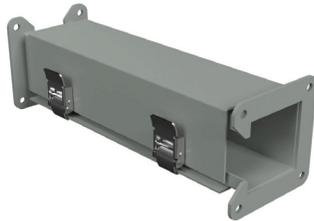

Clockwise Transposition			
Part Number	Price	Overall Size HxW	Drawing Link
1485BZ12	\$179.00	2.50 x 2.50 [64 x 64]	PDF
1485CZ12	\$228.00	4.00 x 4.00 [102 x 102]	PDF
1485DZ12	\$268.00	6.00 x 6.00 [152 x 152]	PDF
1485EZ12	\$468.00	8.00 x 8.00 [203 x 203]	PDF

Note: Dimensions in inches [millimeters].

One flat sealing plate included.



Counter-Clockwise Transposition			
Part Number	Price	Overall Size HxW	Drawing Link
1485BZC12	\$179.00	2.50 x 2.50 [64 x 64]	PDF
1485CZC12	\$228.00	4.00 x 4.00 [102 x 102]	PDF
1485DZC12	\$268.00	6.00 x 6.00 [152 x 152]	PDF
1485EZC12	\$468.00	8.00 x 8.00 [203 x 203]	PDF

Note: Dimensions in inches [millimeters].

One flat sealing plate included.



Junction Boxes				
Part Number	Price	Overall Size HxWxD	Size HxW	Drawing Link
1485BJ	\$265.00	12.00 x 10.25 x 2.50 [305 x 260 x 64]	12.00 x 10.25 [305 x 260]	PDF
1485CJ	\$309.00	14.00 x 13.87 x 4.00 [356 x 352 x 102]	14.00 x 13.87 [356 x 352]	PDF
1485DJ	\$374.00	16.00 x 17.87 x 6.00 [406 x 454 x 152]	16.00 x 17.87 [406 x 454]	PDF
1485EJ	\$456.00	18.00 x 21.87 x 8.00 [457 x 555 x 203]	18.00 x 21.87 [457 x 555]	PDF

Note: Dimensions in inches [millimeters].

Features

- Includes inner panel
- One flat sealing plate included



Cover Plates			
Part Number	Price	Wireway HxW	Drawing Link
1485BH	\$33.50	2.50 x 2.50 [64 x 64]	PDF
1485CH	\$41.50	4.00 x 4.00 [102 x 102]	PDF
1485DH	\$50.00	6.00 x 6.00 [152 x 152]	PDF
1485EH	\$66.00	8.00 x 8.00 [203 x 203]	PDF
1485FH	\$73.00	12.00 x 6.00 [305 x 152]	PDF

Note: Dimensions in inches [millimeters].

One flat sealing plate included.

NEMA 12 Lay-In Wireway Fittings



Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.



Drop Hangers

Part Number	Price	For Wireway HxW	Drawing Link
1485BL1	\$25.00	2.50 x 2.50 [64 x 64]	PDF
1485CL1	\$32.00	4.00 x 4.00 [102 x 102]	PDF
1485DL1	\$43.50	6.00 x 6.00 [152 x 152]	PDF
1485EL1	\$87.00	8.00 x 8.00 [203 x 203]	PDF

Note: Dimensions in inches [millimeters].

Does not meet CSA or UL requirements.



Bracket Hangers

Part Number	Price	For Wireway HxW	Drawing Link
1485BL2	\$17.25	2.50 x 2.50 [64 x 64]	PDF
1485CL2	\$22.00	4.00 x 4.00 [102 x 102]	PDF
1485DL2	\$30.50	6.00 x 6.00 [152 x 152]	PDF
1485EL2	\$79.00	8.00 x 8.00 [203 x 203]	PDF

Note: Dimensions in inches [millimeters].

Does not meet CSA or UL requirements.