


NEMA 12 Screw Cover Pushbutton

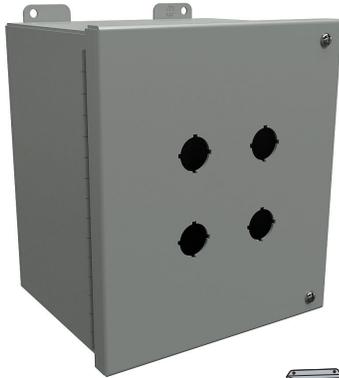

Applications

- Designed to accept standard heavy duty oil-tight pushbuttons, switches and pilot lights.
- Provides protection from dirt, dust, oil, and water.

Construction

- Formed 14-gauge steel.
- Smooth continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Continuously hinged cover is secured with captive, plated steel screws which fasten into threaded sealed wells.
- Oil-resistant gasket and adhesive.
- Weldnuts are provided for mounting subpanels.
- A removable 14-gauge subpanel is included.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure.

Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

Listings

- UL 508A Type 12 [UL File E65324]
- CSA Type 12 [CSA File LR21001]
- Complies with
 - NEMA Type 12
 - IEC 60529, IP54
- All appropriate components are required to maintain these standards.



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

NEMA 12 Screw Cover Pushbutton

22 mm	Price	30 mm	Price	Console Size HxWxD	Drawing Link	# Holes	Subpanel Dimensions
1489MP4	\$171.00	1489P4	\$174.00	8.56 x 7.56 x 6.17 [217 x 192 x 157]	PDF	4	6.25 x 5.25 [159 x 133]
1489MP6	\$196.00	1489P6	\$202.00	10.81 x 7.56 x 6.17 [275 x 192 x 157]	PDF	6	8.50 x 5.25 [216 x 133]
1489MP9	\$226.00	1489P9	\$234.00	10.81 x 9.81 x 6.17 [275 x 249 x 157]	PDF	9	8.50 x 7.50 [216 x 191]
1489MP12	\$257.00	1489P12	\$264.00	13.06 x 9.81 x 6.17 [332 x 249 x 157]	PDF	12	10.00 x 7.50 [254 x 191]
1489MP16	\$294.00	1489P16	\$302.00	13.06 x 12.06 x 6.17 [332 x 306 x 157]	PDF	16	10.75 x 9.75 [273 x 248]
1489MP20	\$328.00	1489P20	\$338.00	15.31 x 12.06 x 6.17 [389 x 306 x 157]	PDF	20	13.00 x 9.75 [330 x 248]
1489MP25	\$367.00	1489P25	\$380.00	15.31 x 14.31 x 6.17 [389 x 363 x 157]	PDF	25	13.00 x 12.00 [330 x 305]
1489MP30	\$409.00	1489P30	\$420.00	17.56 x 14.31 x 6.17 [446 x 363 x 157]	PDF	30	15.25 x 12.00 [387 x 305]
1489MP36	\$453.00	1489P36	\$467.00	17.56 x 16.56 x 6.17 [446 x 421 x 157]	PDF	36	15.25 x 14.25 [387 x 362]
1489MP42	\$495.00	1489P42	\$512.00	19.81 x 16.56 x 6.17 [503 x 421 x 157]	PDF	42	17.50 x 14.25 [455 x 362]

Note: Dimensions in inches [millimeters].

NEMA 12 Screw Cover Pushbutton



Dimensions

