




Quality Products. Service Excellence.

## Vertical Basic PDU 1585-6-7-8 Series

15A | 120V Single-Phase | 5-15R Outlets

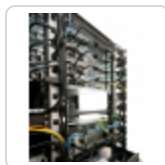

### Features

- Low-profile slim design constructed of rugged lightweight aluminum.
- It can also be used horizontally on your workbench.
- Each outlet strip includes a hardware mounting kit. Order P/N: **1585CLIP** for additional hardware kit.
- Receptacles are 1" square and are equally spaced over the length of the power strip.
- Available with a rocker switch or power indicator light and 15 Amp circuit breaker.

### Specifications

- Heavy duty 14 gauge wire cord - 14/3 SJT type for extreme temperature ranges and integral moulded plug.
- Plug types available are NEMA 5-15P straight blade or NEMA L5-15P locking type.
- Rated 15 amps, 120 volts.
- UL/cUL Listed Standard UL1363, CSA C22.2 No. 308-14 and CSA C22.2 No. 0.4-04
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America.

### Surge Specifications

- Max Energy (Joules) is 1080 J.
- 25000 Amp-rated MOV's for 75,000 Amps of single pulse transient current.
- Voltage Protection Rating (Vpr) of 500V in all three modes (L-N, L-G, N-G).
- Nominal Discharge Current (In) of 5kA.
- Voltage suppression at the outlet guards against transients from the equipment on the outlet strip.
- The green indicator light confirms surge module is active.
- Internal protection will disconnect the surge module at the end of its useful life (and extinguish the green light) but will maintain power to the load, now unprotected.
- cULus Listed to UL 1449 & C22.2 No. 269.3-17, for Surge Protective Devices – Type 3.
- cULus Listed to UL 1363 & C22.2 No. 308-18, for Relocatable Power Taps & Multi Outlet

### Plug Types



5-15P Straight Blade

L5-15P Locking Type

### Accessories

- Vertical Outlet Strip Mounting Clip Kit

Part No. On-Off Switch	Part No. Pilot Light	Strip Length	Number of Outlets	Cord Length (ft)	Color	NEMA Plug Type	Surge Protected
15851H6A1	15851T6A1	18.00	6	6	Natural	5-15P	No
15851H6B1	15851T6B1	18.00	6	15	Natural	5-15P	No
15852H8A1	15852T8A1	24.00	8	6	Natural	5-15P	No
15852H8B1	15852T8B1	24.00	8	15	Natural	5-15P	No
15853H12A1	15853T12A1	36.00	12	6	Natural	5-15P	No
15854H7A1	15854T7A1	42.00	7	6	Natural	5-15P	No
	15854T7B1	42.00	7	15	Natural	5-15P	No
1585T6A1		48.00	6	6	Natural	5-15P	No
1585H8A1	1585T8A1	48.00	8	6	Natural	5-15P	No
1585H8A1S		48.00	8	6	Natural	5-15P	Yes
1585H8B1	1585T8B1	48.00	8	15	Natural	5-15P	No
1585H8B1S	1585T8B1S	48.00	8	15	Natural	5-15P	Yes
1585H16A1	1585T16A1	48.00	16	6	Natural	5-15P	No
1585H16B1	1585T16B1	48.00	16	15	Natural	5-15P	No
	1585T16D1	48.00	16	15	Natural	L5-15P	No
1586H20A1	1586T20A1	60.00	20	6	Natural	5-15P	No
1587H24A1	1587T24A1	70.00	24	6	Natural	5-15P	No
1587H24B1	1587T24B1	70.00	24	15	Natural	5-15P	No
1588H12A1	1588T12A1	77.00	12	6	Natural	5-15P	No
1588H12A1S	1588T12A1S	77.00	12	6	Natural	5-15P	Yes
1588H12B1	1588T12B1	77.00	12	15	Natural	5-15P	No
1588H12B1S	1588T12B1S	77.00	12	15	Natural	5-15P	Yes

## Clearance Sizes (EOL Jan 7, 2026)

Part No. On-Off Switch	Part No. Pilot Light	Strip Length	Number of Outlets	Cord Length (ft)	Color	NEMA Plug Type	Surge Protected
15852H6A1	15852T6A1	24.00	6	6	Natural	5-15P	No
15852H6B1	15852T6B1	24.00	6	15	Natural	5-15P	No
	15852T6D1	24.00	6	15	Natural	L5-15P	No
15853H6A1	15853T6A1	36.00	6	6	Natural	5-15P	No
15853H6C1	15853T6C1	36.00	6	6	Natural	L5-15P	No
15853H6B1	15853T6B1	36.00	6	15	Natural	5-15P	No
15853H6D1		36.00	6	15	Natural	L5-15P	No
	15854T7C1	42.00	7	6	Natural	L5-15P	No
15854H7D1		42.00	7	15	Natural	L5-15P	No
1585H8A1BK	1585T8A1BK	48.00	8	6	Black	5-15P	No
1585H8B1BK	1585T8B1BK	48.00	8	15	Black	5-15P	No
1585H8D1		48.00	8	15	Natural	L5-15P	No
1585H10A1	1585T10A1	48.00	10	6	Natural	5-15P	No
1585H10A1S	1585T10A1S	48.00	10	6	Natural	5-15P	Yes
1585H10C1		48.00	10	6	Natural	L5-15P	No
1585H10B1	1585T10B1	48.00	10	15	Natural	5-15P	No
1585H10B1S	1585T10B1S	48.00	10	15	Natural	5-15P	Yes
1585H10D1		48.00	10	15	Natural	L5-15P	No
1585H11A1		48.00	11	6	Natural	5-15P	No
1585H15A1	1585T15A1	48.00	15	6	Natural	5-15P	No
1585H15A1S	1585T15A1S	48.00	15	6	Natural	5-15P	Yes
1585H15C1		48.00	15	6	Natural	L5-15P	No
1585H15B1	1585T15B1	48.00	15	15	Natural	5-15P	No
1585H15B1S		48.00	15	15	Natural	5-15P	Yes

Part No. On-Off Switch	Part No. Pilot Light	Strip Length	Number of Outlets	Cord Length (ft)	Color	NEMA Plug Type	Surge Protected
1585H15D1		48.00	15	15	Natural	L5-15P	No
1585H16C1		48.00	16	6	Natural	L5-15P	No
1586H10A1	1586T10A1	60.00	10	6	Natural	5-15P	No
1586H10C1		60.00	10	6	Natural	L5-15P	No
1586H10B1	1586T10B1	60.00	10	15	Natural	5-15P	No
1586H10D1		60.00	10	15	Natural	L5-15P	No
1586H12A1	1586T12A1	60.00	12	6	Natural	5-15P	No
1586H12A1BK	1586T12A1BK	60.00	12	6	Black	5-15P	No
1586H12C1	1586T12C1	60.00	12	6	Natural	L5-15P	No
1586H12B1	1586T12B1	60.00	12	15	Natural	5-15P	No
1586H12B1BK	1586T12B1BK	60.00	12	15	Black	5-15P	No
1587H10A1	1587T10A1	70.00	10	6	Natural	5-15P	No
1587H10A1BK	1587T10A1BK	70.00	10	6	Black	5-15P	No
1587H10C1		70.00	10	6	Natural	L5-15P	No
1587H10B1	1587T10B1	70.00	10	15	Natural	5-15P	No
1587H11A1	1587T11A1	70.00	11	6	Natural	5-15P	No
1587H11A1S	1587T11A1S	70.00	11	6	Natural	5-15P	Yes
1587H11C1		70.00	11	6	Natural	L5-15P	No
	1587T11B1	70.00	11	15	Natural	5-15P	No
1587H11B1S	1587T11B1S	70.00	11	15	Natural	5-15P	Yes
1587H12A1	1587T12A1	70.00	12	6	Natural	5-15P	No
1587H12B1	1587T12B1	70.00	12	15	Natural	5-15P	No
	1587T12D1	70.00	12	15	Natural	L5-15P	No
1587H19A1	1587T19A1	70.00	19	6	Natural	5-15P	No
1587H19A1S	1587T19A1S	70.00	19	6	Natural	5-15P	Yes
1587H19C1	1587T19C1	70.00	19	6	Natural	L5-15P	No
1587H19B1	1587T19B1	70.00	19	15	Natural	5-15P	No
1587H19B1S	1587T19B1S	70.00	19	15	Natural	5-15P	Yes
1587H24D1	1587T24D1	70.00	24	15	Natural	L5-15P	No
1588H12A1BK	1588T12A1BK	77.00	12	6	Black	5-15P	No
1588H12B1BK	1588T12B1BK	77.00	12	15	Black	5-15P	No
1588H12D1	1588T12D1	77.00	12	15	Natural	L5-15P	No
1588H12C1	1588T12C1	77.00	12	6	Natural	L5-15P	No

*Data subject to change without notice*

© 2026. Hammond Manufacturing Ltd. All rights reserved.