


# NEMA 4 and 4X Operator Consolets

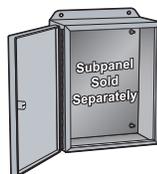

## Applications

- Serves as an economical housing for operator interface applications.
- Provides an ideal sloped surface for mounting keyboards, switches, indicator lights, and/or dials.
- Provides panel mounting capabilities for a variety of applications.
- Generally used as a stand alone enclosure. Possible to put side by side with base on a single plinth (for example, 36 in [914 mm] wide console with 24 in [610 mm] base with terminal all together on a 60 in [1524 mm] plinth.)
- Optional casters (require plinth) allow for a completely mobile, NEMA rated work station.
- Smooth lines and clean edges provide an attractive, contemporary appearance.

- Doors can be hinged from either side on 24 in [610 mm] and 36 in [914 mm] units.
- Door profiles provide increased strength and are pre-punched to provide mounting options.
- Formed lip on enclosure excludes flowing liquids and contaminants.
- Slotted 1/4-turn oil-tight latches secure the door and lid, with optional tamper resistant and locking latches available.
- Stainless steel models utilize stainless steel hardware.
- Oil-resistant gaskets are permanently secured.
- Features internal stud locations for mounting optional subpanel.
- A bonding screw is provided on the door, and a grounding stud is provided in the enclosure.

## Construction

- Formed 14-gauge steel bodies with 14-gauge steel door and lid.
- Also offered with formed 14-gauge 304 stainless steel bodies with 14-gauge 304 stainless steel door and lid.
- Smooth, continuously welded seams without knockouts or holes.
- Body stiffeners are provided where required for increased strength and rigidity.
- Offered in four widths 24 in [610 mm], 36 in [914 mm], 48 in [1219 mm] and 60 in [1524 mm].
- Has solid sides and back, solid door on front, 3-point adjustable lid on sloped (20°) top, and closed bottom with removable access panel.
- 24 in [610 mm] and 36 in [914 mm] widths have Single-Door on the front, whereas 48 in [1219 mm] and 60 in [1524 mm] widths have two outside hinged doors on the front.

## Finish

- Available in RAL7035 light gray textured powder coating and natural stainless steel with a smooth, brushed finish.
- Optional subpanel finished in RAL9003 white powder coat.

## Listings

- UL 508A Type 3R, 4, and 12 (Stainless Steel, add 4X)  
[UL File E65324]
- CSA Type 3R, 4, 12, and 13 (Stainless Steel, add 4X)  
[CSA File LR21001]
- EIA RS-310-D
- Complies with
  - NEMA Type 3R, 4, and 12 (Stainless Steel, add 4X)
  - IEC 60529, IP66



| Shipping Schedule |             |
|-------------------|-------------|
| Same day          | 1 - 15 days |

Color indicates shipping lead time in business days.

| NEMA 4 and 4X Operator Consolets |            |                          |            |  |                     |                         |          |                            |
|----------------------------------|------------|--------------------------|------------|--|---------------------|-------------------------|----------|----------------------------|
| Steel                            | Price      | Stainless                | Price      | Console Size HxWxD                       | Drawing Link        | Optional Subpanel       | Price    | Subpanel Size HxW          |
| <a href="#">2CLC2024</a>         | \$1,946.00 | <a href="#">2CSC2024</a> | \$2,681.00 | 38.81 x 24.00 x 21.03 [986 x 610 x 534]  | <a href="#">PDF</a> | <a href="#">2CWCP24</a> | \$162.00 | 30.50 x 20.50 [775 x 521]  |
| <a href="#">2CLC2036</a>         | \$2,264.00 | <a href="#">2CSC2036</a> | \$3,124.00 | 38.81 x 36.00 x 21.03 [986 x 914 x 534]  | <a href="#">PDF</a> | <a href="#">2CWCP36</a> | \$201.00 | 30.50 x 32.50 [775 x 826]  |
| <a href="#">2CLC2048</a>         | \$3,125.00 | <a href="#">2CSC2048</a> | \$4,310.00 | 38.81 x 48.00 x 21.03 [986 x 1219 x 534] | <a href="#">PDF</a> | <a href="#">2CWCP48</a> | \$249.00 | 30.50 x 44.50 [775 x 1130] |
| <a href="#">2CLC2060</a>         | \$3,658.00 | <a href="#">2CSC2060</a> | \$5,043.00 | 38.81 x 60.00 x 21.03 [986 x 1524 x 534] | <a href="#">PDF</a> | <a href="#">2CWCP60</a> | \$303.00 | 30.50 x 56.50 [775 x 1435] |



Note: Dimensions in inches [millimeters].

# NEMA 4 and 4X Operator Consolets



## Dimensions

Consolet

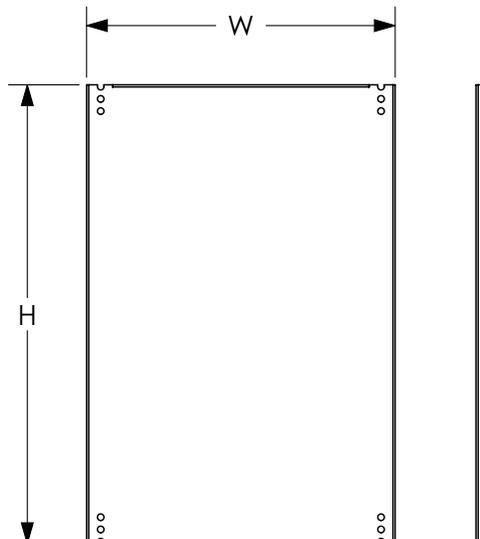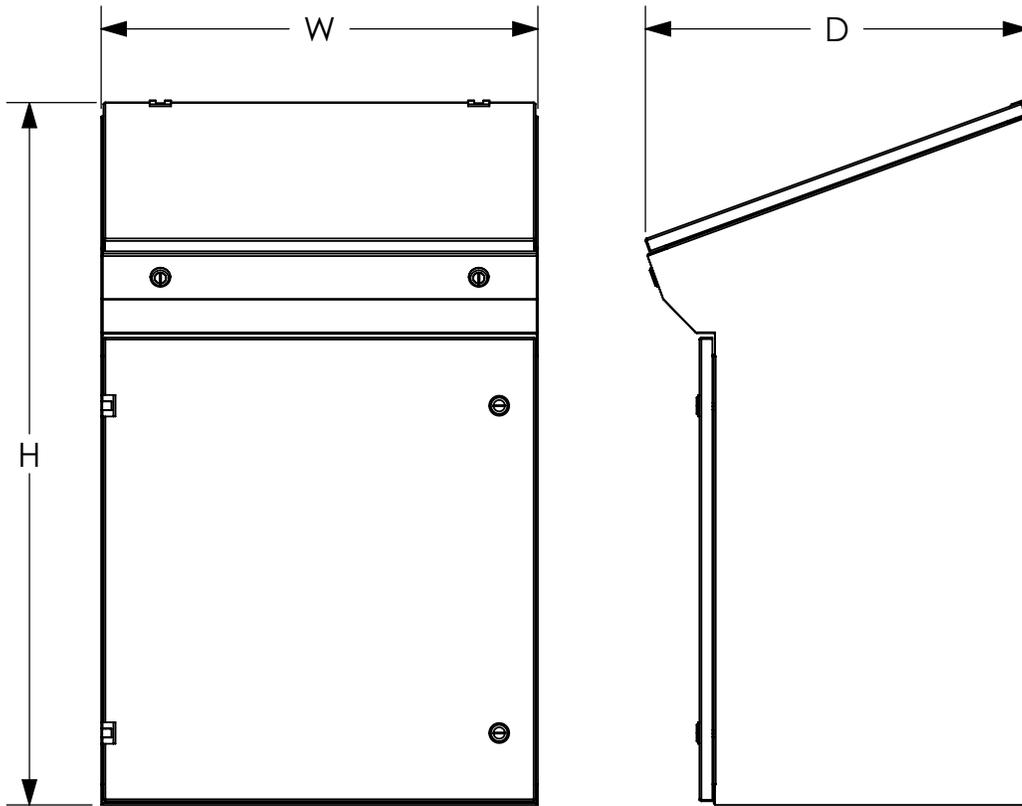

# NEMA 4 and 4X Operator Console Plinths



## Application

- Features removable front and rear panels for easy access to bottom for cabling or transport by forklift.
- For cable access, features 3 double knockouts on each end.
- Available in 4in and 8in heights.
- Available in 24in, 36in, 48in, and 60in widths.
- Maintains NEMA rating of system.
- Formed 14 gauge steel.
- Also offered with formed 14 gauge stainless steel.
- Available in light gray and stainless steel.



### Shipping Schedule

|          |             |
|----------|-------------|
| Same day | 1 - 15 days |
|----------|-------------|

Color indicates shipping lead time in business days.

## NEMA 4 and 4X Operator Console Plinths

| Carbon Steel              | Price      | Stainless Steel           | Price      | Size                                    | Fits Consoles |          | Drawink Link        |
|---------------------------|------------|---------------------------|------------|---|---------------|----------|---------------------|
| <a href="#">2CLP42418</a> | \$447.00   | <a href="#">2CSP42418</a> | \$662.00   | 4.00 x 24.00 x 18.00 [102 x 610 x 457]  | 2CLC2024      | 2CSC2024 | <a href="#">PDF</a> |
| <a href="#">2CLP43618</a> | \$485.00   | <a href="#">2CSP43618</a> | \$717.00   | 4.00 x 36.00 x 18.00 [102 x 914 x 457]  | 2CLC2036      | 2CSC2036 | <a href="#">PDF</a> |
| <a href="#">2CLP44818</a> | \$597.00   | <a href="#">2CSP44818</a> | \$882.00   | 4.00 x 48.00 x 18.00 [102 x 1219 x 457] | 2CLC2048      | 2CSC2048 | <a href="#">PDF</a> |
| <a href="#">2CLP46018</a> | \$709.00   | <a href="#">2CSP46018</a> | \$1,048.00 | 4.00 x 60.00 x 18.00 [102 x 1524 x 457] | 2CLC2060      | 2CSC2060 | <a href="#">PDF</a> |
| <a href="#">2CLP82418</a> | \$746.00   | <a href="#">2CSP82418</a> | \$1,103.00 | 8.00 x 24.00 x 18.00 [203 x 610 x 457]  | 2CLC2024      | 2CSC2024 | <a href="#">PDF</a> |
| <a href="#">2CLP83618</a> | \$858.00   | <a href="#">2CSP83618</a> | \$1,268.00 | 8.00 x 36.00 x 18.00 [203 x 914 x 457]  | 2CLC2036      | 2CSC2036 | <a href="#">PDF</a> |
| <a href="#">2CLP84818</a> | \$1,007.00 | <a href="#">2CSP84818</a> | \$1,489.00 | 8.00 x 48.00 x 18.00 [203 x 1219 x 457] | 2CLC2048      | 2CSC2048 | <a href="#">PDF</a> |
| <a href="#">2CLP86018</a> | \$1,156.00 | <a href="#">2CSP86018</a> | \$1,709.00 | 8.00 x 60.00 x 18.00 [203 x 1524 x 457] | 2CLC2060      | 2CSC2060 | <a href="#">PDF</a> |