




Quality Products. Service Excellence.

## Type 1 Lay In Screw Cover Wireway - w/o Knockouts CWSC NK Series

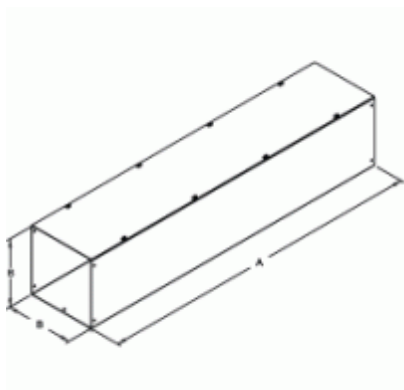

### Painted Steel

A=12"	A=18"	A=24"	A=36"	A=48"	Size
CWSC212NK	-	CWSC224NK	CWSC236NK	CWSC248NK	2.5 x 2.5
CWSC412NK	CWSC418NK	CWSC424NK	CWSC436NK	CWSC448NK	4 x 4
CWSC612NK	CWSC618NK	CWSC624NK	CWSC636NK	CWSC648NK	6 x 6
CWSC812NK	CWSC818NK	CWSC824NK	CWSC836NK	CWSC848NK	8 x 8
CWSC1012NK	-	CWSC1024NK	CWSC1036NK	CWSC1048NK	10 x 10
CWSC1212NK	-	CWSC1224NK	CWSC1236NK	CWSC1248NK	12 x 12

A=60"	A=72"	A=96"	A=120"	Size
CWSC260NK	-	-	CWSC2120NK	2.5 x 2.5
CWSC460NK	CWSC472NK	-	CWSC4120NK	4 x 4
CWSC660NK	CWSC672NK	-	CWSC6120NK	6 x 6
CWSC860NK	CWSC872NK	-	CWSC8120NK	8 x 8
CWSC1060NK	CWSC1072NK	CWSC1096NK	CWSC10120NK	10 x 10
CWSC1260NK	CWSC1272NK	CWSC1296NK	CWSC12120NK	12 x 12



Tags: straight section, CWSC, no knockouts, screw cover, wireway, CW *Data subject to change without notice*