



Quality Products. Service Excellence.

Variable-Depth Rack Shelf *DNRM Series*

Load rated to 300 lbs (136 kg)


Features

- Designed for use with our heavy-duty **DNRR** and **DRZ4** double-tapped two (2) post racks or any 2 post rack.
- Constructed of heavy-duty 16 gauge steel.
- Choice of 19" or 24" deep (19" deep shown).
- The vented version provides a sturdy shelf without obstructing upward heat movement.
- The front and rear lips are folded for extra strength & become equipment retainers.
- 300 lbs (136 kg) **load rating**.
- Finished in textured RAL9005 black powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS and REACH compliant.
- Manufactured in North America.



Accessories

- Hardware for Rack Mounting Solutions
- Rack Equipment Installation Tool
- Rack Rail Reducer Panel

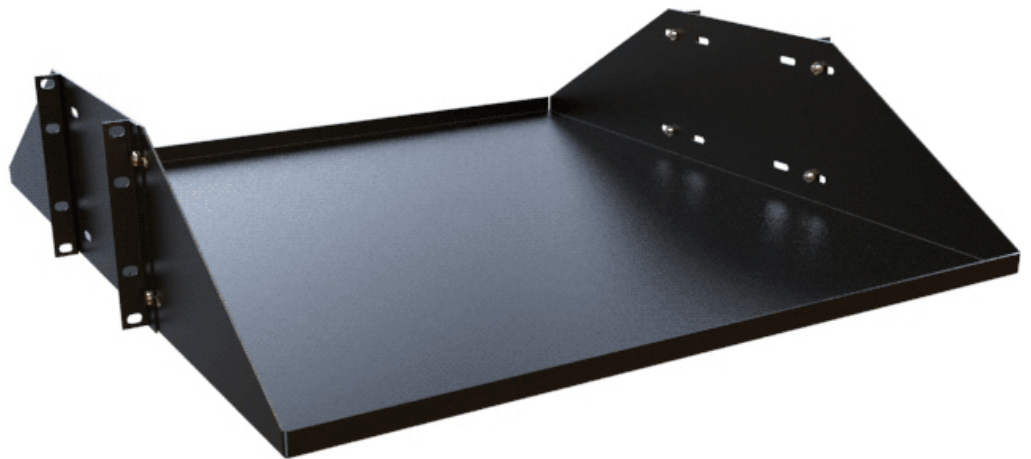

19 Inch Rack Mounting Shelf

Part No.	Part No.	Mounting Dimensions			
		Rack Units	Height	Width	Depth
Vented	Solid				
DNRMV19BK1	DNRMU19BK1	3U	5.25	19.00	19.00
DNRMV1924BK1	DNRMU1924BK1	3U	5.25	19.00	24.00

23 Inch Rack Mounting Shelf

Part No.	Part No.	Mounting Dimensions			
		Rack Units	Height	Width	Depth
Vented	Solid				
DNRMV23BK1	DNRMU23BK1	3U	5.25	23.00	19.00

Part No.	Part No.	Mounting Dimensions			
Vented	Solid	Rack Units	Height	Width	Depth
DNRMV2324BK1	DNRMU2324BK1	3U	5.25	23.00	24.00

Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.