



*Quality Products. Service Excellence.*

## 3000-5000 BTU/H Indoor Slimline Air Conditioner *DTS SL Series*

Type 12, Side Mounting



### Description

- Narrow design for side mounting on any enclosure surface where hot spot or low capacity cooling is required.
- Closed loop cooling ensures clean enclosure air is recirculated without ever mixing with contaminated ambient air.

### Standards

- Maintains NEMA 12 rating
- IP 54
- UL, cUL and CE




### Features


- R134a refrigerant.
- Thermostat control accessible from inside enclosure.
- Expansion valve increases efficiency with improved evaporator heat transfer and less frequent compressor operation.
- Built in condensor/evaporator
- Continuous air circulation from high capacity fans.
- EMI/RFI suppression meets CE.
- Self-diagnostics on startup.
- Fault indication via LED light.
- Door contact for power down when enclosure door is opened.
- Gasket, mounting kit and template for cutout and drilling are included.
- Condensate drain hose and clamp.

### Accessories

- Remote Door Switches
- Gasket Kits
- Condensate Bottle
- Filter Kits
- Water Condensate Evaporator

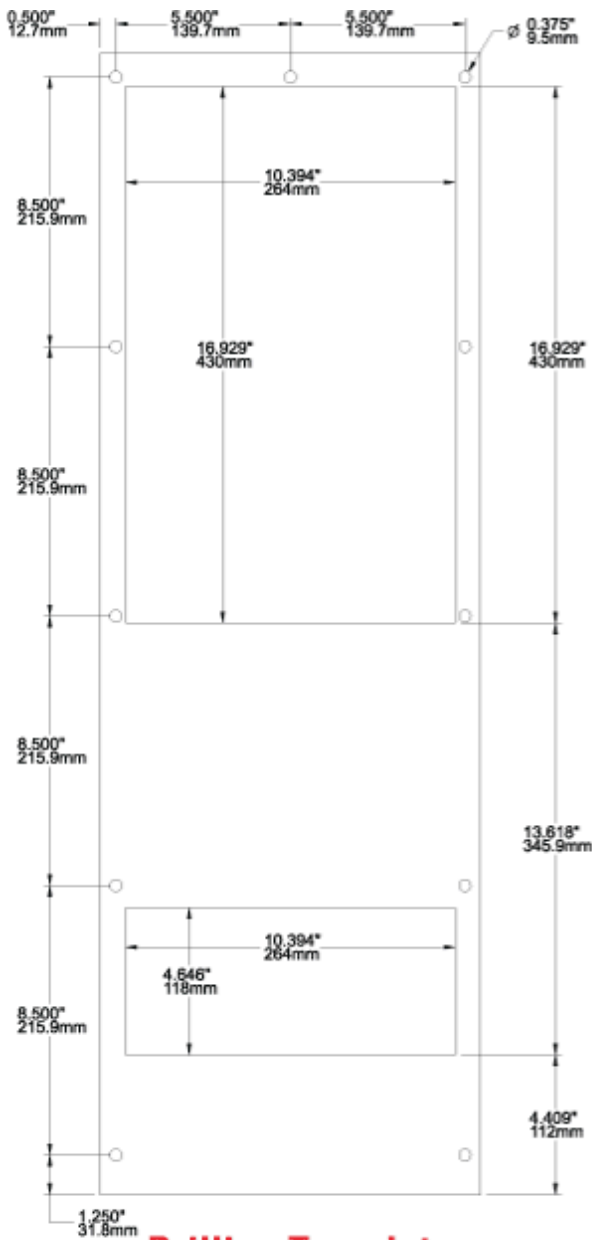

**Drilling Template**

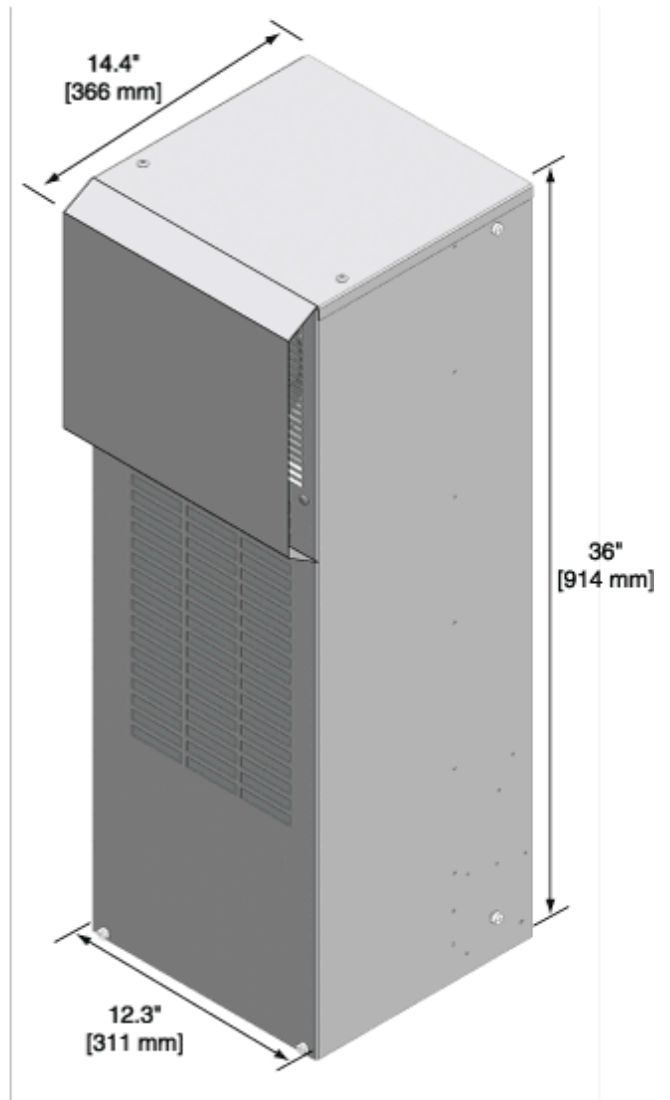

Part Number
DTS3141SLA115LG
DTS3141SLA230LG
DTS3141SLA460LG

\* For ANSI 61 Gray replace LG with GY

Electrical Data	DTS3141SLA115LG DTS3141SLA230LG DTS3141SLA460LG		
	Rated Voltage	115 V 60 Hz	230 V 50/60 Hz
Range of Operation	103 -127 V	198-253 V	360-506 V
Power Consumption	917 W	890 W	751 W
Running Amps	7.51 A	4.49 A	2.25 A
Starting Current	28 A	14.8 A	14.8 A
Line Cord	Terminal Block	Terminal Block	Terminal Block

Refrigeration Data	115V	230V	460V
Cooling Capacity BTU/h ( Watts) +95/+95F +35/+35C	5097 BTU/h (1493 Watts)	5648 BTU/h (1654 Watts)	5301 BTU/h (1552 Watts)
Type of Refrigerant	R134a		
Refrigerant Charge	700g		900g
Adjustable Control Range	+ 77...+ 113°F / + 25...+ 45°C Factory setting +95°F/+35°C		

Refrigeration Data	115V	230V	460V
Max Ambient Air Temp		+131°F (+55°C)	
Min Ambient Air Temp		+59°F (+15°C)	
Air Capacity (unrestricted)		Internal Circulation 350 CFM	
		External Circulation 350 CFM	
Condensate Discharge		Condensate Evaporator	
Filter Mat		Filterless	
Db Noise Level		<70 dB (A)	
Unit Weight		108 lbs (49 kg)	
Exterior Case		Galvanized Sheet Steel	
Finish LG		RAL7035 light gray finish	
Finish GY		ANSI 61 Gray	
Nema Rating		Enclosures IP 54/Nema 12	

Tags: **DTS, air conditioner, cooler, indoor, hot spot, low capacity, , slimline, 5000 BTU, side mounting,** *Data subject to change without notice*  
**NEMA 12, Type 12**

© 2026. Hammond Manufacturing Ltd. All rights reserved.