


Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window

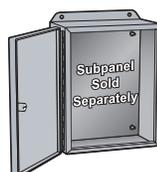

Applications

- Designed to enclose electrical and/or electronic equipment in wall-mount applications where viewing of component operation is necessary while maintaining protection ratings.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14-gauge (24 x 24 in [610 x 610 mm] and larger) or 16-gauge (24 x 20 in [508 mm] [610 x 508 mm] and smaller) stainless steel.
- Full view UV-resistant polycarbonate window allows maximum viewing area of subpanel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity – designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Doors may be easily removed for modifications and are interchangeable.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window

Part Number	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
			Painted	Galvanized	
EN4SD12126WSS	\$928.00	12.00 x 12.00 x 6.82 [305 x 305 x 173]	EP1212	EPG1212	PDF
EN4SD16126WSS	\$1,027.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]	EP1612	EPG1612	PDF
EN4SD161210WSS	\$1,246.00	16.00 x 12.00 x 10.82 [406 x 305 x 275]	EP1612	EPG1612	PDF
EN4SD20166WSS	\$1,249.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]	EP2016	EPG2016	PDF
EN4SD20168WSS	\$1,331.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]	EP2016	EPG2016	PDF
EN4SD20206WSS	\$1,365.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]	EP2020	EPG2020	PDF
EN4SD201610WSS	\$1,448.00	20.00 x 16.00 x 10.82 [508 x 406 x 275]	EP2016	EPG2016	PDF
EN4SD20208WSS	\$1,469.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]	EP2020	EPG2020	PDF
EN4SD202010WSS	\$1,567.00	20.00 x 20.00 x 10.82 [508 x 508 x 275]	EP2020	EPG2020	PDF
EN4SD24208WSS	\$1,617.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]	EP2420	EPG2420	PDF
EN4SD242010WSS	\$1,684.00	24.00 x 20.00 x 10.82 [610 x 508 x 275]	EP2420	EPG2420	PDF
EN4SD202012WSS	\$1,730.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]	EP2020	EPG2020	PDF
EN4SD24248WSS	\$1,767.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]	EP2424	EPG2424	PDF
EN4SD242410WSS	\$1,817.00	24.00 x 24.00 x 10.82 [610 x 610 x 275]	EP2424	EPG2424	PDF
EN4SD30248WSS	\$2,018.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]	EP3024	EPG3024	PDF
EN4SD302410WSS	\$2,020.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]	EP3024	EPG3024	PDF
EN4SD302412WSS	\$2,234.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]	EP3024	EPG3024	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Window



Dimensions

