

Enclosure Subpanels

Eclipse Series Enclosures



Construction

- Larger than standard NEMA panel used in same sized enclosure.
- 12-gauge steel construction.
- Larger sizes have 2 or 4 formed flanges for added strength.
- Slotted corner design for easier mounting.
- Finished in RAL9003 white powder coat or unpainted galvanized.


| Shipping Schedule | |
|--|-------------|
| Same day | 1 - 15 days |
| Color indicates shipping lead time in business days. | |

Subpanels for Eclipse Series Hammond Enclosures

| Painted | Price | Galvanized | Price | Dimensions HxW | Drawing Link |
|------------------------|----------|-------------------------|----------|-----------------------------|---------------------|
| EP1210 | \$17.25 | EPG1210 | \$17.75 | 10.17 x 8.17 [258 x 208] | PDF |
| EP1212 | \$17.25 | EPG1212 | \$13.25 | 10.17 x 10.17 [258 x 258] | PDF |
| EP1224 | \$54.00 | EPG1224 | \$54.00 | 10.17 x 22.17 [258 x 563] | PDF |
| EP1612 | \$22.50 | EPG1612 | \$17.00 | 14.17 x 10.17 [360 x 258] | PDF |
| EP1616 | \$43.00 | EPG1616 | \$43.00 | 14.17 x 14.17 [360 x 360] | PDF |
| EP1620 | \$49.50 | EPG1620 | \$49.50 | 14.17 x 18.17 [360 x 462] | PDF |
| EP2012 | \$40.00 | EPG2012 | \$49.50 | 18.17 x 10.17 [462 x 258] | PDF |
| EP2016 | \$49.50 | EPG2016 | \$49.50 | 18.17 x 14.17 [462 x 360] | PDF |
| EP2020 | \$59.00 | EPG2020 | \$59.00 | 18.17 x 18.17 [462 x 462] | PDF |
| EP2024 | \$76.00 | EPG2024 | \$76.00 | 18.17 x 22.17 [462 x 563] | PDF |
| EP2412 | \$54.00 | EPG2412 | \$54.00 | 22.17 x 10.17 [563 x 258] | PDF |
| EP2416 | \$59.00 | EPG2416 | \$59.00 | 22.17 x 14.17 [563 x 360] | PDF |
| EP2420 | \$76.00 | EPG2420 | \$76.00 | 22.17 x 18.17 [563 x 462] | PDF |
| EP2424 | \$88.00 | EPG2424 | \$88.00 | 22.17 x 22.17 [563 x 563] | PDF |
| EP2430 | \$110.00 | EPG2430 | \$110.00 | 22.17 x 28.17 [563 x 716] | PDF |
| EP2442 | \$150.00 | EPG2442 | \$150.00 | 22.17 x 40.17 [563 x 1020] | PDF |
| EP2448 | \$169.00 | EPG2448 | \$169.00 | 22.17 x 46.17 [563 x 1173] | PDF |
| EP3012 | \$67.00 | EPG3012 | \$67.00 | 28.17 x 10.17 [716 x 258] | PDF |
| EP3016 | \$81.00 | EPG3016 | \$81.00 | 28.17 x 14.17 [716 x 360] | PDF |
| EP3020 | \$95.00 | EPG3020 | \$95.00 | 28.17 x 18.17 [716 x 462] | PDF |
| EP3024 | \$110.00 | EPG3024 | \$110.00 | 28.17 x 22.17 [716 x 563] | PDF |
| EP3030 | \$144.00 | EPG3030 | \$144.00 | 28.17 x 28.17 [716 x 716] | PDF |
| EP3036 | \$167.00 | EPG3036 | \$167.00 | 28.17 x 34.17 [716 x 868] | PDF |
| EP3042 | \$195.00 | EPG3042 | \$195.00 | 28.17 x 40.17 [716 x 1020] | PDF |
| EP3048 | \$219.00 | EPG3048 | \$219.00 | 28.17 x 46.17 [716 x 1173] | PDF |
| EP3060 | \$265.00 | EPG3060 | \$265.00 | 28.17 x 58.17 [716 x 1478] | PDF |
| EP3624 | \$128.00 | EPG3624 | \$128.00 | 34.17 x 22.17 [868 x 563] | PDF |
| EP3630 | \$167.00 | EPG3630 | \$167.00 | 34.17 x 28.17 [868 x 716] | PDF |
| EP3636 | \$195.00 | EPG3636 | \$195.00 | 34.17 x 34.17 [868 x 868] | PDF |
| EP3642 | \$227.00 | EPG3642 | \$227.00 | 34.17 x 40.17 [868 x 1020] | PDF |
| EP3648 | \$250.00 | EPG3648 | \$250.00 | 34.17 x 46.17 [868 x 1173] | PDF |
| EP3660 | \$306.00 | EPG3660 | \$306.00 | 34.17 x 58.17 [868 x 1478] | PDF |
| EP4224 | \$148.00 | EPG4224 | \$147.00 | 40.17 x 22.17 [1020 x 563] | PDF |
| EP4230 | \$195.00 | EPG4230 | \$195.00 | 40.17 x 28.17 [1020 x 716] | PDF |
| EP4236 | \$227.00 | EPG4236 | \$227.00 | 40.17 x 34.17 [1020 x 868] | PDF |
| EP4824 | \$169.00 | EPG4824 | \$169.00 | 46.17 x 22.17 [1173 x 563] | PDF |
| EP4830 | \$212.00 | EPG4830 | \$212.00 | 46.17 x 28.17 [1173 x 716] | PDF |
| EP4836 | \$250.00 | EPG4836 | \$250.00 | 46.17 x 34.17 [1173 x 868] | PDF |
| EP4848 | \$302.00 | EPG4848 | \$302.00 | 46.17 x 46.17 [1173 x 1173] | PDF |
| EP6036 | \$306.00 | EPG6036 | \$306.00 | 58.17 x 34.17 [1478 x 868] | PDF |
| EP7230 | \$332.00 | EPG7230 | \$332.00 | 70.17 x 28.17 [1782 x 716] | PDF |
| EP7236 | \$366.00 | EPG7236 | \$368.00 | 70.17 x 34.17 [1782 x 868] | PDF |

Note: Dimensions in inches [millimeters].

Dimensions

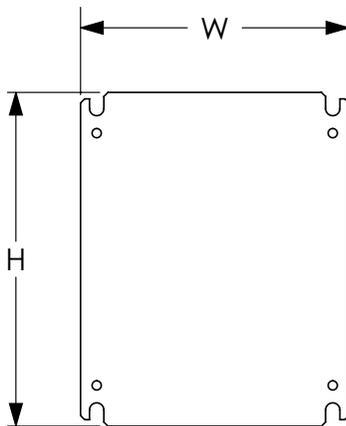

Eclipse Series Swing Panel Kits



Construction

- Hinged panel allows access to internally mounted equipment.
- 12-gauge steel panel included.
- Slotted 1/4-turn latches provide closure.
- Adding optional locking 1/4-turn latches (Part Number EQTRL) convert this to a dead front panel.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in RAL9003 white powder coat.




| Shipping Schedule | |
|--|-------------|
| Same day | 1 - 15 days |
| Color indicates shipping lead time in business days. | |

| Swing Panel Kits - Eclipse Series | | | | |
|-----------------------------------|----------|----------------------------|---------------------------------------|---------------------|
| Part Number | Price | Dimensions HxW | For Use With | Drawing Link |
| ESP1212 | \$143.00 | 9.75 x 9.79 [248 x 249] | 12x12 (HxW) EN4SD12126xx & ST12126LG | PDF |
| ESP1612 | \$148.00 | 13.75 x 9.79 [349 x 249] | 16x12 (HxW) EN4SD1612xxx & ST1612xxx | PDF |
| ESP1616 | \$156.00 | 13.75 x 13.79 [349 x 350] | 16x16 (HxW) EN4SD1616xxx & ST1616xxx | PDF |
| ESP1620 | \$165.00 | 13.75 x 17.79 [349 x 452] | 16x20 (HxW) EN4SD1620xxx | PDF |
| ESP2016 | \$165.00 | 17.75 x 13.79 [451 x 350] | 20x16 (HxW) EN4SD2016xxx & ST2016xxx | PDF |
| ESP2020 | \$173.00 | 17.75 x 17.79 [451 x 452] | 20x20 (HxW) EN4SD2020xxx & ST2020xxx | PDF |
| ESP2416 | \$172.00 | 21.75 x 13.79 [552 x 350] | 24x16 (HxW) EN4SD2416xxx | PDF |
| ESP2024 | \$184.00 | 17.75 x 21.79 [451 x 553] | 20x24 (HxW) EN4SD2024xxx | PDF |
| ESP2420 | \$184.00 | 21.75 x 17.79 [552 x 452] | 24x20 (HxW) EN4SD2420xxx & ST2420xxx | PDF |
| ESP2424 | \$196.00 | 21.75 x 21.79 [552 x 553] | 24x24 (HxW) EN4SD2424xxx & ST2424xxx | PDF |
| ESP3020 | \$198.00 | 27.75 x 17.79 [705 x 452] | 30x20 (HxW) EN4SD3020xxx | PDF |
| ESP3024 | \$212.00 | 27.75 x 21.79 [705 x 553] | 30x24 (HxW) EN4SD3024xxx & ST3024xxx | PDF |
| ESP3624 | \$232.00 | 33.75 x 21.79 [857 x 553] | 36x24 (HxW) EN4SD3624xxx | PDF |
| ESP3030 | \$235.00 | 27.75 x 27.79 [705 x 706] | 30x30 (HxW) EN4SD3030xxx & ST3030xxx | PDF |
| ESP4824 | \$250.00 | 45.75 x 21.79 [1162 x 553] | 48x24 (HxW) EN4SD4824xxx | PDF |
| ESP3630 | \$257.00 | 33.75 x 27.79 [857 x 706] | 36x30 (HxW) EN4SD3630xxx & ST3630xxx | PDF |
| ESP3636 | \$285.00 | 33.75 x 33.79 [857 x 858] | 36x36 (HxW) EN4SD3636xxx & ST363612xx | PDF |
| ESP4236 | \$313.00 | 39.75 x 33.79 [1010 x 858] | 42x36 (HxW) EN4SD4236xxx | PDF |
| ESP4836 | \$358.00 | 45.75 x 33.79 [1162 x 858] | 48x36 (HxW) EN4SD4836xxx & ST4836xxxx | PDF |
| ESP6036 | \$423.00 | 57.75 x 33.79 [1467 x 858] | 60x36 (HxW) EN4SD6036xxx & ST6036xxxx | PDF |

Note: Dimensions in inches [millimeters].

Dimensions

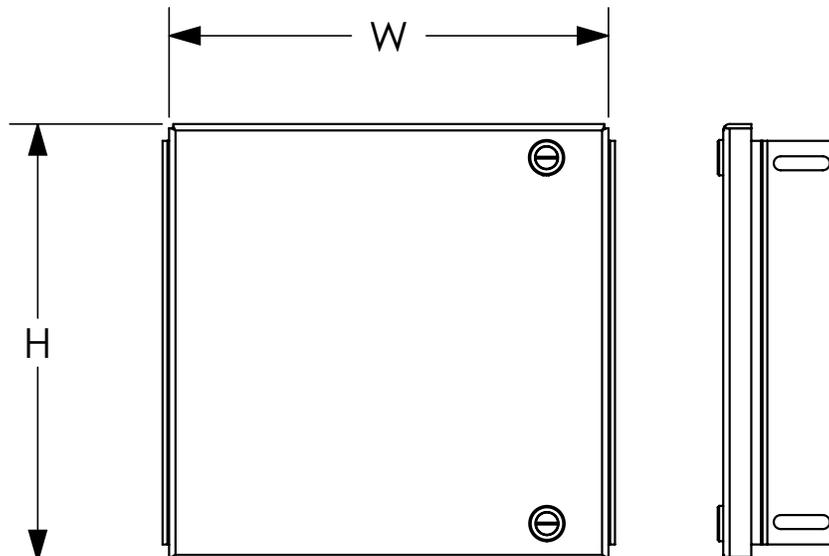

Eclipse Series Swing Frame



Construction

- Provides 19 in [483 mm] rack mounting with full EIA spacing (punched holes).
- Hinges allow easy equipment access.
- Slotted 1/4-turn latches provide closure.
- Optional locking 1/4-turn latch available by ordering Part No. EQTRL
- Adding optional locking 1/4-turn latches provides added security.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Mounting hardware sold separately.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in black powder coat.

| Shipping Schedule | |
|--|-------------|
| Same day | 1 - 15 days |
| Color indicates shipping lead time in business days. | |

| Eclipse Swing Frame | | | | | |
|-------------------------|----------|--------------|--------------------|------------|---------------------|
| Part Number | Price | For Use With | Rack Spacing Width | Rack Units | Drawing Link |
| ESF2424 | \$287.00 | 24x24in | 19.00in | 11U | PDF |
| ESF3024 | \$371.00 | 30x24in | 19.00in | 14U | PDF |
| ESF3624 | \$426.00 | 36x24in | 19.00in | 17U | PDF |

Dimensions

