

# NEMA 4 and 12 Single-Door Wall-Mount



## Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

## Construction

- Body formed from 16-gauge or 14-gauge steel. Covers are formed from 14-gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- 14-gauge welded mounting brackets
- Continuous hinged cover is secured with stainless steel clamps and screws.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin.
- Seamless poured-in-place gasket.
- Internal threaded weld studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

## Finish


- Cover and enclosure are phosphatized and finished in smooth ANSI 61 gray recoatable powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

## Listings

- UL 508A Type 3R, 4, 12, and 13 [UL File E65324]
- CSA Type 3R, 4, 12, and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 12, and 13
  - IEC 60529, IP66IEC 60529, IP66



## Dimensions

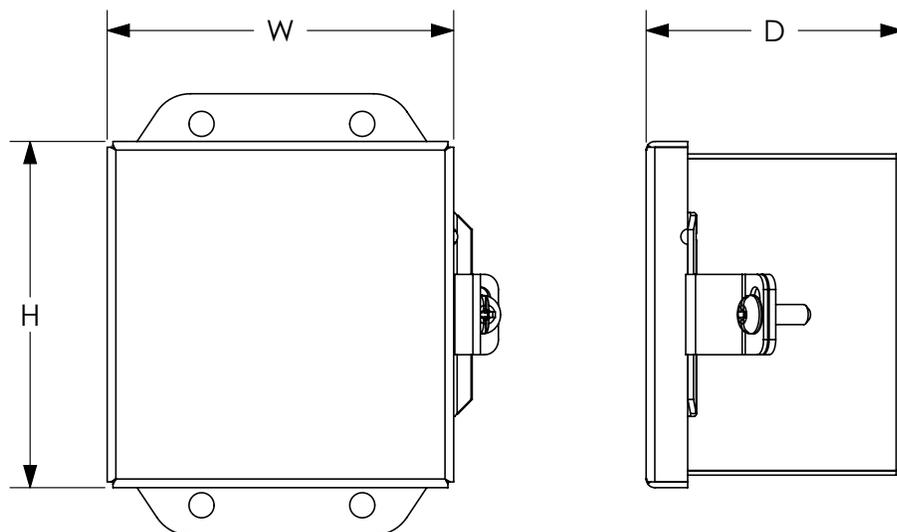

# NEMA 4 and 12 Single-Door Wall-Mount



## Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

## NEMA 4 and 12 Single-Door Wall-Mount

Part Number	Price	Enclosure Size HxWxD	Subpanels				Size HxW	Drawing Link
			Painted	Aluminum	Galvanized	Stainless		
<a href="#">HJ443HLP</a>	\$55.00	4.31 x 4.31 x 3.20 [109 x 109 x 81]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">HJ444HLP</a>	\$57.00	4.31 x 4.31 x 4.20 [109 x 109 x 107]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">HJ643HLP</a>	\$63.00	6.31 x 4.31 x 3.20 [160 x 109 x 81]	<a href="#">14R0503</a>	<a href="#">14A0503</a>	<a href="#">14G0503</a>	<a href="#">14R0503SS</a>	4.88 x 2.88 [124 x 73]	<a href="#">PDF</a>
<a href="#">HJ644HLP</a>	\$67.00	6.31 x 4.31 x 4.20 [160 x 109 x 107]	<a href="#">14R0503</a>	<a href="#">14A0503</a>	<a href="#">14G0503</a>	<a href="#">14R0503SS</a>	4.88 x 2.88 [124 x 73]	<a href="#">PDF</a>
<a href="#">HJ664HLP</a>	\$71.00	6.31 x 6.31 x 4.20 [160 x 160 x 107]	<a href="#">14R0505</a>	<a href="#">14A0505</a>	<a href="#">14G0505</a>	<a href="#">14R0505SS</a>	4.88 x 4.88 [124 x 124]	<a href="#">PDF</a>
<a href="#">HJ683HLP</a>	\$76.00	6.31 x 8.31 x 3.70 [160 x 211 x 94]	<a href="#">14R0705</a>	<a href="#">14A0705</a>	<a href="#">14G0705</a>	<a href="#">14R0705SS</a>	6.75 x 4.88 [171 x 124]	<a href="#">PDF</a>
<a href="#">HJ863HLP</a>	\$76.00	8.31 x 6.31 x 3.70 [211 x 160 x 94]	<a href="#">14R0705</a>	<a href="#">14A0705</a>	<a href="#">14G0705</a>	<a href="#">14R0705SS</a>	6.75 x 4.88 [171 x 124]	<a href="#">PDF</a>
<a href="#">HJ884HLP</a>	\$87.00	8.31 x 8.31 x 4.20 [211 x 211 x 107]	<a href="#">14R0707</a>	<a href="#">14A0707</a>	<a href="#">14G0707</a>	<a href="#">14R0707SS</a>	6.75 x 6.88 [171 x 175]	<a href="#">PDF</a>
<a href="#">HJ866HLP</a>	\$91.00	8.31 x 6.31 x 6.20 [211 x 160 x 157]	<a href="#">14R0705</a>	<a href="#">14A0705</a>	<a href="#">14G0705</a>	<a href="#">14R0705SS</a>	6.75 x 4.88 [171 x 124]	<a href="#">PDF</a>
<a href="#">HJ1084HLP</a>	\$96.00	10.31 x 8.31 x 4.20 [262 x 211 x 107]	<a href="#">14R0907</a>	<a href="#">14A0907</a>	<a href="#">14G0907</a>	<a href="#">14R0907SS</a>	8.75 x 6.88 [222 x 175]	<a href="#">PDF</a>
<a href="#">HJ1264HLP</a>	\$96.00	12.31 x 6.31 x 4.20 [313 x 160 x 107]	<a href="#">14R1105</a>	<a href="#">14A1105</a>	<a href="#">14G1105</a>	—	10.75 x 4.88 [273 x 124]	<a href="#">PDF</a>
<a href="#">HJ8104HLP</a>	\$95.00	8.31 x 10.31 x 4.20 [211 x 262 x 107]	<a href="#">14R0907</a>	<a href="#">14A0907</a>	<a href="#">14G0907</a>	<a href="#">14R0907SS</a>	8.75 x 6.88 [222 x 175]	<a href="#">PDF</a>
<a href="#">HJ1086HLP</a>	\$110.00	10.31 x 8.31 x 6.20 [262 x 211 x 157]	<a href="#">14R0907</a>	<a href="#">14A0907</a>	<a href="#">14G0907</a>	<a href="#">14R0907SS</a>	8.75 x 6.88 [222 x 175]	<a href="#">PDF</a>
<a href="#">HJ10106HLP</a>	\$119.00	10.31 x 10.31 x 6.20 [262 x 262 x 157]	<a href="#">14R0909</a>	<a href="#">14A0909</a>	<a href="#">14G0909</a>	<a href="#">14R0909SS</a>	8.75 x 8.88 [222 x 226]	<a href="#">PDF</a>
<a href="#">HJ10125HLP</a>	\$122.00	10.31 x 12.31 x 5.20 [262 x 313 x 132]	<a href="#">14R1109</a>	<a href="#">14A1109</a>	<a href="#">14G1109</a>	<a href="#">14R1109SS</a>	10.75 x 8.88 [273 x 226]	<a href="#">PDF</a>
<a href="#">HJ12105HLP</a>	\$123.00	12.31 x 10.31 x 5.20 [313 x 262 x 132]	<a href="#">14R1109</a>	<a href="#">14A1109</a>	<a href="#">14A1109</a>	<a href="#">14R1109SS</a>	10.75 x 8.88 [273 x 226]	<a href="#">PDF</a>
<a href="#">HJ1486HLP</a>	\$131.00	14.31 x 8.31 x 6.20 [363 x 211 x 157]	<a href="#">14R1307</a>	<a href="#">14A1307</a>	<a href="#">14G1307</a>	—	12.75 x 6.88 [324 x 175]	<a href="#">PDF</a>
<a href="#">HJ12126HLP</a>	\$143.00	12.31 x 12.31 x 6.20 [313 x 313 x 157]	<a href="#">14R1111</a>	<a href="#">14A1111</a>	<a href="#">14G1111</a>	<a href="#">14R1111SS</a>	10.75 x 10.88 [273 x 276]	<a href="#">PDF</a>
<a href="#">HJ12108HLP</a>	\$150.00	12.31 x 10.31 x 8.20 [313 x 262 x 208]	<a href="#">14R1109</a>	<a href="#">14A1109</a>	<a href="#">14G1109</a>	<a href="#">14R1109SS</a>	10.75 x 8.88 [273 x 226]	<a href="#">PDF</a>
<a href="#">HJ12146HLP</a>	\$153.00	12.31 x 14.31 x 6.20 [313 x 363 x 157]	<a href="#">14R1311</a>	<a href="#">14A1311</a>	<a href="#">14G1311</a>	<a href="#">14R1311SS</a>	12.75 x 10.88 [324 x 276]	<a href="#">PDF</a>
<a href="#">HJ14126HLP</a>	\$154.00	14.31 x 12.31 x 6.20 [363 x 313 x 157]	<a href="#">14R1311</a>	<a href="#">14A1311</a>	<a href="#">14G1311</a>	<a href="#">14R1311SS</a>	12.75 x 10.88 [324 x 276]	<a href="#">PDF</a>
<a href="#">HJ16106HLP</a>	\$156.00	16.31 x 10.31 x 6.20 [414 x 262 x 157]	<a href="#">14R1509</a>	<a href="#">14A1509</a>	<a href="#">14G1509</a>	—	14.75 x 8.88 [375 x 226]	<a href="#">PDF</a>
<a href="#">HJ14128HLP</a>	\$176.00	14.31 x 12.31 x 8.20 [363 x 313 x 208]	<a href="#">14R1311</a>	<a href="#">14A1311</a>	<a href="#">14G1311</a>	<a href="#">14R1311SS</a>	12.75 x 10.88 [324 x 276]	<a href="#">PDF</a>
<a href="#">HJ14166HLP</a>	\$180.00	14.31 x 16.31 x 6.20 [363 x 414 x 157]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>
<a href="#">HJ16146HLP</a>	\$182.00	16.31 x 14.31 x 6.20 [414 x 363 x 157]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>
<a href="#">HJ16148HLP</a>	\$201.00	16.31 x 14.31 x 8.20 [414 x 363 x 208]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>
<a href="#">HJ161410HLP</a>	\$227.00	16.31 x 14.31 x 10.20 [414 x 363 x 259]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].