


# NEMA 4 and 12 Lift-Off Cover Wall-Mount

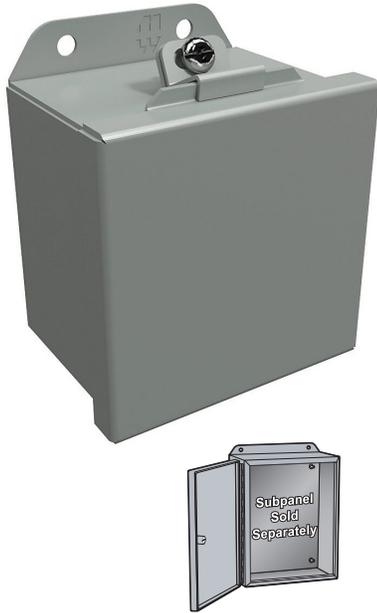

## Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes, or terminal wiring enclosures.
- Provides some protection from falling dirt, dust, oil, and water.

## Construction

- Body formed from 16-gauge or 14-gauge steel. Covers are formed from 14-gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- 14-gauge welded mounting brackets
- Lift-off cover is secured with stainless steel clamps and stainless steel screws and retained with a stainless steel chain when open.
- Seamless poured-in-place gasket.
- Internal threaded weld studs are provided for mounting subpanels.
- A bonding stud is provided on the door and a grounding stud is provided on the enclosure.

## Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray recoatable powder coating.

## Listings

- UL 508A Type 3R, 4, 12, and 13 [UL File E65324]
- CSA Type 3R, 4, 12, and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 12, and 13
  - IEC 60529, IP66



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 4 and 12 Lift-Off Cover Wall-Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels				Size HxW	Drawing Link
			Painted	Aluminum	Galvanized	Stainless		
<a href="#">HJ443LP</a>	\$56.00	4.31 x 4.31 x 3.20 [109 x 109 x 81]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">HJ444LP</a>	\$59.00	4.31 x 4.31 x 4.20 [109 x 109 x 107]	—	—	—	—	—	<a href="#">PDF</a>
<a href="#">HJ643LP</a>	\$63.00	6.31 x 4.31 x 3.20 [160 x 109 x 81]	<a href="#">14R0503</a>	<a href="#">14A0503</a>	<a href="#">14G0503</a>	<a href="#">14R0503SS</a>	4.88 x 2.88 [124 x 73]	<a href="#">PDF</a>
<a href="#">HJ644LP</a>	\$68.00	6.31 x 4.31 x 4.20 [160 x 109 x 107]	<a href="#">14R0503</a>	<a href="#">14A0503</a>	<a href="#">14G0503</a>	<a href="#">14R0503SS</a>	4.88 x 2.88 [124 x 73]	<a href="#">PDF</a>
<a href="#">HJ664LP</a>	\$73.00	6.31 x 6.31 x 4.20 [160 x 160 x 107]	<a href="#">14R0505</a>	<a href="#">14A0505</a>	<a href="#">14G0505</a>	<a href="#">14R0505SS</a>	4.88 x 4.88 [124 x 124]	<a href="#">PDF</a>
<a href="#">HJ863LP</a>	\$77.00	8.31 x 6.31 x 3.70 [211 x 160 x 94]	<a href="#">14R0705</a>	<a href="#">14A0705</a>	<a href="#">14G0705</a>	<a href="#">14R0705SS</a>	6.75 x 4.88 [171 x 124]	<a href="#">PDF</a>
<a href="#">HJ1084LP</a>	\$98.00	10.31 x 8.31 x 4.20 [262 x 211 x 107]	<a href="#">14R0907</a>	<a href="#">14A0907</a>	<a href="#">14G0907</a>	<a href="#">14R0907SS</a>	8.75 x 6.88 [222 x 175]	<a href="#">PDF</a>
<a href="#">HJ12105LP</a>	\$126.00	12.31 x 10.31 x 5.20 [313 x 262 x 132]	<a href="#">14R1109</a>	<a href="#">14A1109</a>	<a href="#">14G1109</a>	<a href="#">14R1109SS</a>	10.75 x 8.88 [273 x 226]	<a href="#">PDF</a>
<a href="#">HJ14126LP</a>	\$164.00	14.31 x 12.31 x 6.20 [363 x 313 x 157]	<a href="#">14R1311</a>	<a href="#">14A1311</a>	<a href="#">14G1311</a>	<a href="#">14R1311SS</a>	12.75 x 10.88 [324 x 276]	<a href="#">PDF</a>
<a href="#">HJ16146LP</a>	\$191.00	16.31 x 14.31 x 6.20 [414 x 363 x 157]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>
<a href="#">HJ14128LP</a>	\$194.00	14.31 x 12.31 x 8.20 [363 x 313 x 208]	<a href="#">14R1311</a>	<a href="#">14A1311</a>	<a href="#">14G1311</a>	<a href="#">14R1311SS</a>	12.75 x 10.88 [324 x 276]	<a href="#">PDF</a>
<a href="#">HJ161410LP</a>	\$233.00	16.31 x 14.31 x 10.20 [414 x 363 x 259]	<a href="#">14R1513</a>	<a href="#">14A1513</a>	<a href="#">14G1513</a>	<a href="#">14R1513SS</a>	14.75 x 12.88 [375 x 327]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 4 and 12 Lift-Off Cover Wall-Mount



## Dimensions

