


# NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle

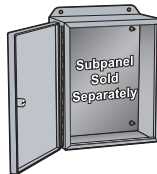

## Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.
- Ideal for processing plants, utility, outdoor municipal, or petro chemical locations where easy yet secure access is required.

## Construction

- Formed 14-gauge steel bodies and doors.
- Continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Powder coated black zinc diecast padlockable handle with 3-point roller latching system secures door.
- Door may be removed by pulling the stainless steel hinge pin
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Bonding stud provided on door and grounding stud installed in enclosure.

## Finish


- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating interior and exterior.

## Listings

- UL 508A Type 3R, 4, and 12 [UL File E63524]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 12, and 13
  - IEC 60529, IP66



## Dimensions

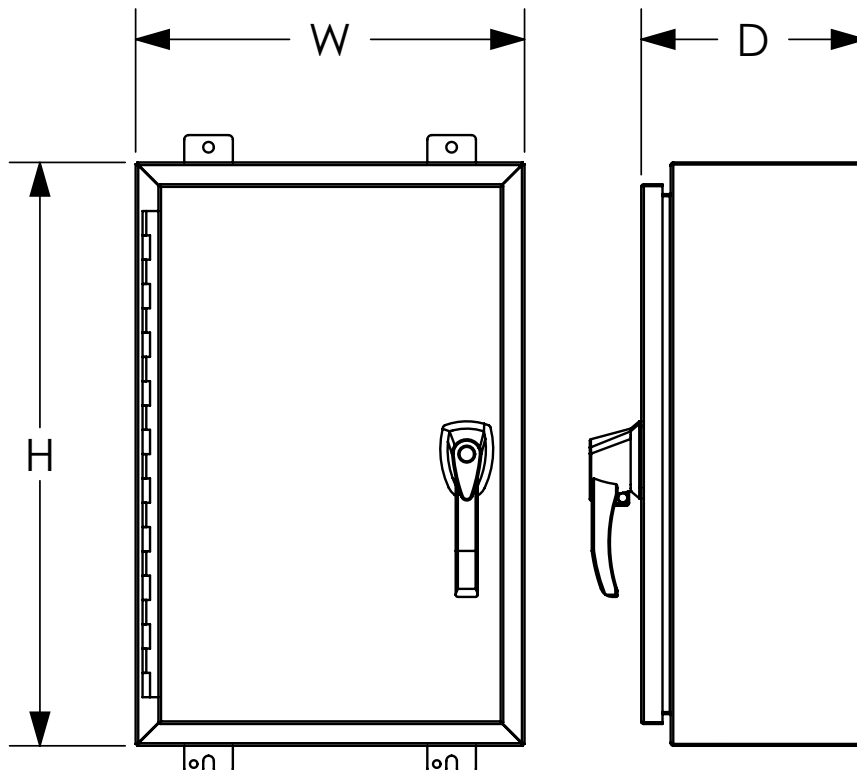

# NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, and 12 Single-Door Wall-Mount with 3-Point Handle									
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels					Size HxW	Drawing Link
			Painted	Perforated	Aluminum	Galvanized	Stainless		
<a href="#">HW24168GYHK</a>	\$549.00	24.00 x 16.00 x 9.21 [610 x 406 x 234]	<a href="#">18P2113</a>	—	—	<a href="#">18G2113</a>	<a href="#">18P2113S16</a>	21.00 x 13.00 [533 x 330]	<a href="#">PDF</a>
<a href="#">HW24206GYHK</a>	\$564.00	24.00 x 20.00 x 7.21 [610 x 508 x 183]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">HW24208GYHK</a>	\$592.00	24.00 x 20.00 x 9.21 [610 x 508 x 234]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">HW242010GYHK</a>	\$621.00	24.00 x 20.00 x 11.21 [610 x 508 x 285]	<a href="#">18P2117</a>	<a href="#">18P2117PP</a>	<a href="#">18A2117</a>	<a href="#">18G2117</a>	<a href="#">18P2117S16</a>	21.00 x 17.00 [533 x 432]	<a href="#">PDF</a>
<a href="#">HW24246GYHK</a>	\$609.00	24.00 x 24.00 x 7.21 [610 x 610 x 183]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">HW24248GYHK</a>	\$639.00	24.00 x 24.00 x 9.21 [610 x 610 x 234]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">HW242412GYHK</a>	\$701.00	24.00 x 24.00 x 13.21 [610 x 610 x 336]	<a href="#">18P2121</a>	<a href="#">18P2121PP</a>	<a href="#">18A2121</a>	<a href="#">18G2121</a>	<a href="#">18P2121S16</a>	21.00 x 21.00 [533 x 533]	<a href="#">PDF</a>
<a href="#">HW24308GYHK</a>	\$715.00	24.00 x 30.00 x 9.21 [610 x 762 x 234]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2121</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">HW30208GYHK</a>	\$678.00	30.00 x 20.00 x 9.21 [762 x 508 x 234]	<a href="#">18P2717</a>	—	—	<a href="#">18G2717</a>	<a href="#">18P2717S16</a>	27.00 x 17.00 [686 x 432]	<a href="#">PDF</a>
<a href="#">HW30248GYHK</a>	\$715.00	30.00 x 24.00 x 9.21 [762 x 610 x 234]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">HW302410GYHK</a>	\$750.00	30.00 x 24.00 x 11.21 [762 x 610 x 285]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">HW302412GYHK</a>	\$784.00	30.00 x 24.00 x 13.21 [762 x 610 x 336]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">HW302416GYHK</a>	\$875.00	30.00 x 24.00 x 17.21 [762 x 610 x 437]	<a href="#">18P2721</a>	<a href="#">18P2721PP</a>	<a href="#">18A2721</a>	<a href="#">18G2721</a>	<a href="#">18P2721S16</a>	27.00 x 21.00 [686 x 533]	<a href="#">PDF</a>
<a href="#">HW30308GYHK</a>	\$799.00	30.00 x 30.00 x 9.21 [762 x 762 x 234]	<a href="#">18P2727</a>	<a href="#">18P2727PP</a>	—	<a href="#">18G2727</a>	<a href="#">18P2727S16</a>	27.00 x 27.00 [686 x 686]	<a href="#">PDF</a>
<a href="#">HW36248GYHK</a>	\$786.00	36.00 x 24.00 x 9.21 [914 x 610 x 234]	<a href="#">18P3321</a>	<a href="#">18P3321PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>
<a href="#">HW362410GYHK</a>	\$824.00	36.00 x 24.00 x 11.21 [914 x 610 x 285]	<a href="#">18P3321</a>	<a href="#">18P3321PP</a>	<a href="#">18A3321</a>	<a href="#">18G3321</a>	<a href="#">18P3321S16</a>	33.00 x 21.00 [838 x 533]	<a href="#">PDF</a>
<a href="#">HW36308GYHK</a>	\$883.00	36.00 x 30.00 x 9.21 [914 x 762 x 234]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">HW363010GYHK</a>	\$926.00	36.00 x 30.00 x 11.21 [914 x 762 x 285]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">HW363012GYHK</a>	\$968.00	36.00 x 30.00 x 13.21 [914 x 762 x 336]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">HW363016GYHK</a>	\$1,083.00	36.00 x 30.00 x 17.21 [914 x 762 x 437]	<a href="#">18P3327</a>	<a href="#">18P3327PP</a>	<a href="#">18A3327</a>	<a href="#">18G3327</a>	<a href="#">18P3327S16</a>	33.00 x 27.00 [838 x 686]	<a href="#">PDF</a>
<a href="#">HW363612GYHK</a>	\$1,089.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]	<a href="#">18P3333</a>	<a href="#">18P3333PP</a>	—	<a href="#">18G3333</a>	<a href="#">18P3333S16</a>	33.00 x 33.00 [838 x 838]	<a href="#">PDF</a>
<a href="#">HW423010GYHK</a>	\$1,044.00	42.00 x 30.00 x 11.21 [1067 x 762 x 285]	<a href="#">18P3927</a>	—	—	<a href="#">18G3927</a>	<a href="#">18P3927S16</a>	39.00 x 27.00 [991 x 686]	<a href="#">PDF</a>
<a href="#">HW42368GYHK</a>	\$996.00	42.00 x 36.00 x 9.21 [1067 x 914 x 234]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	<a href="#">18P3933S16</a>	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">HW423612GYHK</a>	\$1,196.00	42.00 x 36.00 x 13.21 [1067 x 914 x 336]	<a href="#">18P3933</a>	—	—	<a href="#">18G3933</a>	<a href="#">18P3933S16</a>	39.00 x 33.00 [991 x 838]	<a href="#">PDF</a>
<a href="#">HW48368GYHK</a>	\$1,178.00	48.00 x 36.00 x 9.21 [1219 x 914 x 234]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">HW483610GYHK</a>	\$1,232.00	48.00 x 36.00 x 11.21 [1219 x 914 x 285]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">HW483612GYHK</a>	\$1,287.00	48.00 x 36.00 x 13.21 [1219 x 914 x 336]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">HW483616GYHK</a>	\$1,397.00	48.00 x 36.00 x 17.21 [1219 x 914 x 437]	<a href="#">18P4533</a>	—	<a href="#">18A4533</a>	<a href="#">18G4533</a>	<a href="#">18P4533S16</a>	45.00 x 33.00 [1143 x 838]	<a href="#">PDF</a>
<a href="#">HW603612GYHK</a>	\$1,517.00	60.00 x 36.00 x 13.21 [1524 x 914 x 336]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>
<a href="#">HW603616GYHK</a>	\$1,685.00	60.00 x 36.00 x 17.21 [1524 x 914 x 437]	<a href="#">18P5733</a>	—	<a href="#">18A5733</a>	<a href="#">18G5733</a>	<a href="#">18P5733S16</a>	57.00 x 33.00 [1448 x 838]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].