


IP69K Sanitary Screw Cover

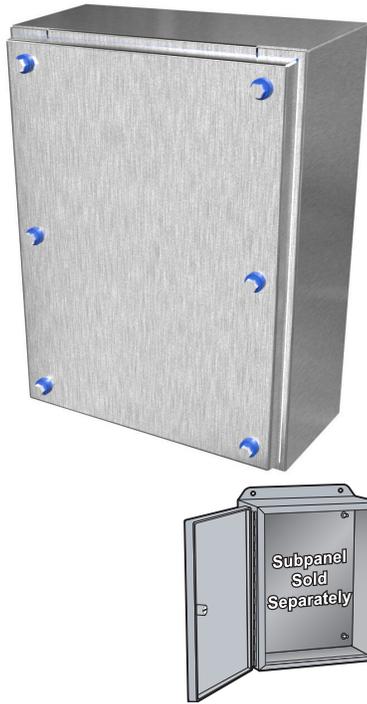

Features

- Designed to enclose electrical and/or electronic equipment and protect against harsh, sanitary environments for junction box and wall-mount applications.
- Sloped on four sides prevent water from pooling on top regardless of enclosure orientation.
- Hex head screws and door-edge mounted silicone gasket allow for easy cleaning in sanitary environments.

Construction

- Formed 304 stainless steel with a smooth, #4 dairy finish.
- Sloped 3° on all four sides.
- Continuously welded seams ground smooth.
- Hex head screw cover can be completely removed for modifications.
- Silicone gasket mounts around entire door edge allowing for efficient cleaning in sanitary environments.
- Gasket can be easily removed and reinstalled for cleaning or replacement. Additional silicone gaskets can be ordered separately
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts.
- Bonding stud provided on door and grounding stud installed in enclosure.
- No pre-drilled wall-mounting holes to allow for flexible mounting alternatives.
 - May be installed with standoffs (sold separately) to allow for cleaning of back of enclosure, or welded in place.

Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

IP69K Sanitary Screw Cover

| Part Number | Price | Enclosure Size HxWxD | Drawing Link |
|----------------------------|------------|--|---------------------|
| HYJ854SS | \$707.00 | 7.94 x 4.98 x 4.53 [202 x 126 x 115] | PDF |
| HYJ1074SS | \$783.00 | 9.94 x 6.98 x 4.53 [252 x 177 x 115] | PDF |
| HYJ1294SS | \$859.00 | 11.94 x 8.98 x 4.53 [303 x 228 x 115] | PDF |
| HYJ14116SS | \$1,028.00 | 14.15 x 11.19 x 6.53 [359 x 284 x 166] | PDF |
| HYJ16138SS | \$1,202.00 | 16.36 x 13.40 x 8.53 [416 x 340 x 217] | PDF |

Note: Dimensions in inches [millimeters].

Listings

- UL 508A Type 3R, 4, 4X, and 12 [File E65324]
- CSA Type 3R, 4, 4X, and 12 [File LR21001]
- NSF-ANSI 169 (not all accessories maintain NSF standards)
- Complies with:
 - NEMA Type 3R, 4, 4X, and 12
 - IEC 60529, IP69, IP69K



IP69K Sanitary Pushbutton



Applications

Designed to accept pushbuttons and indicators while protecting against harsh, sanitary environments.

Construction

- Formed 304 gauge steel.
- Sloped 3° on all four sides to prevent water from resting on top regardless of orientation.
- Smooth continuously welded seams.
- Hex head screw cover can be completely removed for modifications.
- Silicone gasket mounted around entire door edge and hex-head screws allow for efficient cleaning in sanitary environments.
- Gasket can be easily removed and re-installed for cleaning or replacement.
- Additional silicone gaskets can be ordered separately.
- Multiple pushbutton hole configurations with either 22 mm [0.87in] or 30 mm [1.18in] notched pushbutton holes.
- No pre-drilled wall mounting holes allow for flexible mounting alternatives.
- May be installed with standoffs (sold separately) to allow for cleaning of back of enclosure, or welded in place.
- Bonding stud provided on cover and grounding stud installed in enclosure.



- ## Finish
- Cover and enclosure are natural stainless steel with a smooth #4 dairy finish.

Listings

- UL 508A Type 3R, 12, 4, 4X [UL File E65324]
- CSA Type 3R, 12, 4, 4X [CSA File LR21001]
- Complies with:
 - NEMA Type 3R, 12, 4, 4X
 - IEC 60529, IP69, IP69K



Shipping Schedule

| | |
|----------|-------------|
| Same day | 1 - 15 days |
|----------|-------------|

Color indicates shipping lead time in business days.

IP69K Sanitary Pushbutton

| 22 mm | Price | 30 mm | Price | Dimensions HxWxD | Drawing Link | # Holes | Replacement Gasket | Price |
|---------------------------|------------|--------------------------|------------|---------------------------------------|---------------------|---------|------------------------|----------|
| HYMPB1SS | \$934.00 | HYPB1SS | \$934.00 | 7.94 x 4.98 x 4.53 [202 x 126 x 115] | PDF | 1 | HYG85 | \$130.00 |
| HYMPB2SS | \$982.00 | HYPB2SS | \$982.00 | 7.94 x 4.98 x 4.53 [202 x 126 x 115] | PDF | 2 | HYG85 | \$130.00 |
| HYMPB3SS | \$1,036.00 | HYPB3SS | \$1,036.00 | 9.94 x 4.98 x 4.53 [252 x 126 x 115] | PDF | 3 | HYG105 | \$125.00 |
| HYMPB4VSS | \$1,122.00 | HYPB4VSS | \$1,122.00 | 11.94 x 4.98 x 4.53 [303 x 126 x 115] | PDF | 4 | HYG125 | \$151.00 |
| HYMPB4SS | \$1,175.00 | HYPB4SS | \$1,175.00 | 9.94 x 6.98 x 4.53 [252 x 177 x 115] | PDF | 4 | HYG107 | \$133.00 |
| HYMPB6SS | \$1,368.00 | HYPB6SS | \$1,368.00 | 11.94 x 8.98 x 4.53 [303 x 228 x 115] | PDF | 6 | HYG129 | \$161.00 |

Note: Dimensions in inches [millimeters].

IP69K Sanitary Pushbutton



Dimensions

