


NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch

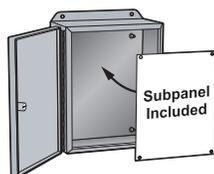

Applications

- Designed for indoor use to house controls, instruments and components not requiring oil-tight or dust-tight protection.

Construction

- Formed and spot welded from 16-gauge steel.
- Formed steel covers close by use of slotted 1/4-turn latch.
- Full swing door using butt hinges.
- Through holes in back for wall-mounting.
- Bonding stud is provided on the door and a grounding stud is provided on the box.
- Includes 14-gauge steel subpanel.

Finish

- Enclosure and cover are finished in ANSI 61 gray powder coating.
- Subpanel is finished in RAL9003 white powder coating

Listings

- UL-50 Type 1 [UL File E65324]
- CSA Type 1 [CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch

Part Number	Price	Enclosure Size HxWxD	Drawing Link	Included Subpanel	Subpanel Dimensions	Optional Subpanel Perforated
N1J664	\$61.00	6.38 x 6.30 x 4.12 [162 x 160 x 105]	PDF	N1JP66	4.25 x 4.25 [108 x 108]	N1JP66PP
N1J864	\$67.00	8.38 x 6.30 x 4.12 [213 x 160 x 105]	PDF	N1JP86	6.25 x 4.25 [159 x 108]	N1JP86PP
N1J884	\$74.00	8.38 x 8.30 x 4.12 [213 x 211 x 105]	PDF	N1JP88	6.25 x 6.25 [159 x 159]	N1JP88PP
N1J886	\$83.00	8.38 x 8.30 x 6.12 [213 x 211 x 155]	PDF	N1JP88	6.25 x 6.25 [159 x 159]	N1JP88PP
N1J1084	\$82.00	10.38 x 8.30 x 4.12 [264 x 211 x 105]	PDF	N1JP108	8.25 x 6.25 [210 x 159]	N1JP108PP
N1J1086	\$92.00	10.38 x 8.30 x 6.12 [264 x 211 x 155]	PDF	N1JP108	8.25 x 6.25 [210 x 159]	N1JP108PP
N1J10104	\$91.00	10.38 x 10.30 x 4.12 [264 x 262 x 105]	PDF	N1JP1010	8.25 x 8.25 [210 x 210]	N1JP1010PP
N1J10106	\$103.00	10.38 x 10.30 x 6.12 [264 x 262 x 155]	PDF	N1JP1010	8.25 x 8.25 [210 x 210]	N1JP1010PP
N1J12104	\$102.00	12.38 x 10.30 x 4.12 [314 x 262 x 105]	PDF	N1JP1210	10.25 x 8.25 [260 x 210]	N1JP1210PP
N1J12106	\$113.00	12.38 x 10.30 x 6.12 [314 x 262 x 155]	PDF	N1JP1210	10.25 x 8.25 [260 x 210]	N1JP1210PP
N1J12124	\$112.00	12.38 x 12.30 x 4.12 [314 x 312 x 105]	PDF	N1JP1212	10.25 x 10.25 [260 x 260]	N1JP1212PP
N1J12126	\$126.00	12.38 x 12.30 x 6.12 [314 x 312 x 155]	PDF	N1JP1212	10.25 x 10.25 [260 x 260]	N1JP1212PP
N1J12128	\$139.00	12.38 x 12.30 x 8.12 [314 x 312 x 206]	PDF	N1JP1212	10.25 x 10.25 [260 x 260]	N1JP1212PP
N1J14124	\$124.00	14.38 x 12.30 x 4.12 [365 x 312 x 105]	PDF	N1JP1412	12.25 x 10.25 [311 x 260]	N1JP1412PP
N1J14126	\$138.00	14.38 x 12.30 x 6.12 [365 x 312 x 155]	PDF	N1JP1412	12.25 x 10.25 [311 x 260]	N1JP1412PP
N1J14128	\$152.00	14.38 x 12.30 x 8.12 [365 x 312 x 206]	PDF	N1JP1412	12.25 x 10.25 [311 x 260]	N1JP1412PP
N1J16126	\$149.00	16.38 x 12.30 x 6.12 [416 x 312 x 155]	PDF	N1JP1612	14.25 x 10.25 [362 x 260]	N1JP1612PP
N1J20126	\$172.00	20.38 x 12.30 x 6.12 [518 x 312 x 155]	PDF	N1JP2012	18.25 x 10.25 [464 x 260]	N1JP2012PP

Note: Dimensions in inches [millimeters].

NEMA 1 Small Single-Door Wall-Mount with 1/4-Turn Latch



Dimensions

