

Rack-Mounted Instrument Enclosure



Applications

- Designed for use as instrument enclosures.
- Suitable for desk top or rack mountable applications.

Finish


- Textured black powder coat

Listings

- RoHS Compliant.

Construction

- Extruded aluminum side panels 0.25in [6.35mm]
- Extruded aluminum front and rear panels 0.25in [6.35mm]
- Flat aluminum top and bottom panels 0.064in [1.6mm]
- Knockdown design ships disassembled for easy handling and shipping protection.
- Can be used with or without included rack mounting brackets.
- Can be converted to a vented enclosure by replacing the top and bottom panels.

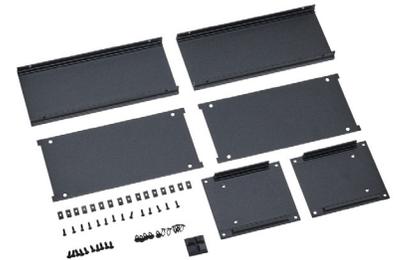

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Rack-Mounted Instrument Enclosure							
Part Number	Price	Enclosure Size HxWxD	Rack Units	Top/Bottom Panel Size	Vented Top/Bottom Panel	Price	Drawing Link
RM1U0804SBK	\$144.00	1.75 x 8.30 x 4.25 [44 x 211 x 108]	1U	8.30 x 4.25 [211 x 108]	RM0804BKVP	\$16.50	PDF
RM1U0808SBK	\$155.00	1.75 x 8.30 x 8.00 [44 x 211 x 203]	1U	8.30 x 8.00 [211 x 203]	RM0808BKVP	\$22.00	PDF
RM1U1908SBK	\$182.00	1.75 x 16.60 x 8.00 [44 x 422 x 203]	1U	16.60 x 8.00 [422 x 203]	RM1908BKVP	\$27.50	PDF
RM1U1913SBK	\$219.00	1.75 x 16.60 x 13.00 [44 x 422 x 330]	1U	16.60 x 13.00 [422 x 330]	RM1913BKVP	\$33.00	PDF
RM1U1918SBK	\$278.00	1.75 x 16.60 x 18.00 [44 x 422 x 457]	1U	16.60 x 18.00 [422 x 457]	RM1918BKVP	\$39.50	PDF
RM1U1922SBK	\$324.00	1.75 x 16.60 x 22.00 [44 x 422 x 559]	1U	16.60 x 22.00 [422 x 559]	RM1922BKVP	\$44.50	PDF
RM1U1928SBK	\$371.00	1.75 x 16.60 x 28.00 [44 x 422 x 711]	1U	16.60 x 28.00 [422 x 711]	RM1928BKVP	\$49.50	PDF
RM2U0804SBK	\$154.00	3.50 x 8.30 x 4.25 [89 x 211 x 108]	2U	8.30 x 4.25 [211 x 108]	RM0804BKVP	\$16.50	PDF
RM2U0808SBK	\$167.00	3.50 x 8.30 x 8.00 [89 x 211 x 203]	2U	8.30 x 8.00 [211 x 203]	RM0808BKVP	\$22.00	PDF
RM2U1908SBK	\$217.00	3.50 x 16.60 x 8.00 [89 x 422 x 203]	2U	16.60 x 8.00 [422 x 203]	RM1908BKVP	\$27.50	PDF
RM2U1913SBK	\$262.00	3.50 x 16.60 x 13.00 [89 x 422 x 330]	2U	16.60 x 13.00 [422 x 330]	RM1913BKVP	\$33.00	PDF
RM2U1918SBK	\$332.00	3.50 x 16.60 x 18.00 [89 x 422 x 457]	2U	16.60 x 18.00 [422 x 457]	RM1918BKVP	\$39.50	PDF
RM2U1922SBK	\$388.00	3.50 x 16.60 x 22.00 [89 x 422 x 559]	2U	16.60 x 22.00 [422 x 559]	RM1922BKVP	\$44.50	PDF
RM2U1928SBK	\$443.00	3.50 x 16.60 x 28.00 [89 x 422 x 711]	2U	16.60 x 28.00 [422 x 711]	RM1928BKVP	\$49.50	PDF
RM3U0804SBK	\$163.00	5.25 x 8.30 x 4.25 [133 x 211 x 108]	3U	8.30 x 4.25 [211 x 108]	RM0804BKVP	\$16.50	PDF
RM3U0808SBK	\$179.00	5.25 x 8.30 x 8.00 [133 x 211 x 203]	3U	8.30 x 8.00 [211 x 203]	RM0808BKVP	\$22.00	PDF
RM3U1908SBK	\$259.00	5.25 x 16.60 x 8.00 [133 x 422 x 203]	3U	16.60 x 8.00 [422 x 203]	RM1908BKVP	\$27.50	PDF
RM3U1913SBK	\$311.00	5.25 x 16.60 x 13.00 [133 x 422 x 330]	3U	16.60 x 13.00 [422 x 330]	RM1913BKVP	\$33.00	PDF
RM3U1918SBK	\$393.00	5.25 x 16.60 x 18.00 [133 x 422 x 457]	3U	16.60 x 18.00 [422 x 457]	RM1918BKVP	\$39.50	PDF
RM3U1922SBK	\$460.00	5.25 x 16.60 x 22.00 [133 x 422 x 559]	3U	16.60 x 22.00 [422 x 559]	RM1922BKVP	\$44.50	PDF
RM3U1928SBK	\$526.00	5.25 x 16.60 x 28.00 [133 x 422 x 711]	3U	16.60 x 28.00 [422 x 711]	RM1928BKVP	\$49.50	PDF
RM4U1908SBK	\$285.00	7.00 x 16.60 x 8.00 [178 x 422 x 203]	4U	16.60 x 8.00 [422 x 203]	RM1908BKVP	\$27.50	PDF
RM4U1913SBK	\$342.00	7.00 x 16.60 x 13.00 [178 x 422 x 330]	4U	16.60 x 13.00 [422 x 330]	RM1913BKVP	\$33.00	PDF
RM4U1918SBK	\$433.00	7.00 x 16.60 x 18.00 [178 x 422 x 457]	4U	16.60 x 18.00 [422 x 457]	RM1918BKVP	\$39.50	PDF
RM4U1922SBK	\$522.00	7.00 x 16.60 x 22.00 [178 x 422 x 559]	4U	16.60 x 22.00 [422 x 559]	RM1922BKVP	\$44.50	PDF
RM4U1928SBK	\$611.00	7.00 x 16.60 x 28.00 [178 x 422 x 711]	4U	16.60 x 28.00 [422 x 711]	RM1928BKVP	\$49.50	PDF

Note: Dimensions in inches [millimeters].

Vented Rack-Mounted Instrument Enclosure



Applications

- Designed for use as instrument enclosures.
- Suitable for desk top or rack mountable applications.

Finish


- Textured black powder-coat

Construction

- Extruded aluminum side panels 0.25in [6.35mm]
- Extruded aluminum front and rear panels 0.25in [6.35mm]
- Flat aluminum top and bottom panels 0.064in [1.6mm]
- Knockdown design ships un-assembled for easy handling and shipping protection.
- Can be used with or without included rack mounting brackets.
- Can be converted to a solid enclosure by replacing the top and bottom panels.

Listings

- RoHS Compliant

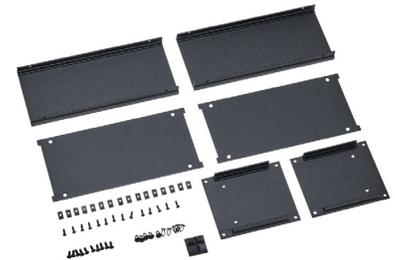

Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Vented Rack-Mounted Instrument Enclosure								
Part Number	Price	Enclosure Size HxWxD	Rack Units	Top/Bottom Panel Size	Solid Top/Bottom Panel	Price	Drawing Link	
RM1U0804VBK	\$148.00	1.75 x 8.30 x 4.25 [44 x 211 x 108]	1U	8.30 x 4.25 [211 x 108]	RM0804BKSP	\$10.00	PDF	
RM1U0808VBK	\$165.00	1.75 x 8.30 x 8.00 [44 x 211 x 203]	1U	8.30 x 8.00 [211 x 203]	RM0808BKSP	\$13.50	PDF	
RM1U1908VBK	\$191.00	1.75 x 16.60 x 8.00 [44 x 422 x 203]	1U	16.60 x 8.00 [422 x 203]	RM1908BKSP	\$22.50	PDF	
RM1U1913VBK	\$231.00	1.75 x 16.60 x 13.00 [44 x 422 x 330]	1U	16.60 x 13.00 [422 x 330]	RM1913BKSP	\$30.00	PDF	
RM1U1918VBK	\$294.00	1.75 x 16.60 x 18.00 [44 x 422 x 457]	1U	16.60 x 18.00 [422 x 457]	RM1918BKSP	\$34.00	PDF	
RM1U1922VBK	\$345.00	1.75 x 16.60 x 22.00 [44 x 422 x 559]	1U	16.60 x 22.00 [422 x 559]	RM1922BKSP	\$37.00	PDF	
RM1U1928VBK	\$396.00	1.75 x 16.60 x 28.00 [44 x 422 x 711]	1U	16.60 x 28.00 [422 x 711]	RM1928BKSP	\$40.50	PDF	
RM2U0804VBK	\$158.00	3.50 x 8.30 x 4.25 [89 x 211 x 108]	2U	8.30 x 4.25 [211 x 108]	RM0804BKSP	\$10.00	PDF	
RM2U0808VBK	\$177.00	3.50 x 8.30 x 8.00 [89 x 211 x 203]	2U	8.30 x 8.00 [211 x 203]	RM0808BKSP	\$13.50	PDF	
RM2U1908VBK	\$229.00	3.50 x 16.60 x 8.00 [89 x 422 x 203]	2U	16.60 x 8.00 [422 x 203]	RM1908BKSP	\$22.50	PDF	
RM2U1913VBK	\$279.00	3.50 x 16.60 x 13.00 [89 x 422 x 330]	2U	16.60 x 13.00 [422 x 330]	RM1913BKSP	\$30.00	PDF	
RM2U1918VBK	\$348.00	3.50 x 16.60 x 18.00 [89 x 422 x 457]	2U	16.60 x 18.00 [422 x 457]	RM1918BKSP	\$34.00	PDF	
RM2U1922VBK	\$404.00	3.50 x 16.60 x 22.00 [89 x 422 x 559]	2U	16.60 x 22.00 [422 x 559]	RM1922BKSP	\$37.00	PDF	
RM2U1928VBK	\$459.00	3.50 x 16.60 x 28.00 [89 x 422 x 711]	2U	16.60 x 28.00 [422 x 711]	RM1928BKSP	\$40.50	PDF	
RM3U0804VBK	\$167.00	5.25 x 8.30 x 4.25 [133 x 211 x 108]	3U	8.30 x 4.25 [211 x 108]	RM0804BKSP	\$10.00	PDF	
RM3U0808VBK	\$189.00	5.25 x 8.30 x 8.00 [133 x 211 x 203]	3U	8.30 x 8.00 [211 x 203]	RM0808BKSP	\$13.50	PDF	
RM3U1908VBK	\$271.00	5.25 x 16.60 x 8.00 [133 x 422 x 203]	3U	16.60 x 8.00 [422 x 203]	RM1908BKSP	\$22.50	PDF	
RM3U1913VBK	\$328.00	5.25 x 16.60 x 13.00 [133 x 422 x 330]	3U	16.60 x 13.00 [422 x 330]	RM1913BKSP	\$30.00	PDF	
RM3U1918VBK	\$413.00	5.25 x 16.60 x 18.00 [133 x 422 x 457]	3U	16.60 x 18.00 [422 x 457]	RM1918BKSP	\$34.00	PDF	
RM3U1922VBK	\$481.00	5.25 x 16.60 x 22.00 [133 x 422 x 559]	3U	16.60 x 22.00 [422 x 559]	RM1922BKSP	\$37.00	PDF	
RM3U1928VBK	\$549.00	5.25 x 16.60 x 28.00 [133 x 422 x 711]	3U	16.60 x 28.00 [422 x 711]	RM1928BKSP	\$40.50	PDF	
RM4U1908VBK	\$298.00	7.00 x 16.60 x 8.00 [178 x 422 x 203]	4U	16.60 x 8.00 [422 x 203]	RM1908BKSP	\$22.50	PDF	
RM4U1913VBK	\$361.00	7.00 x 16.60 x 13.00 [178 x 422 x 330]	4U	16.60 x 13.00 [422 x 330]	RM1913BKSP	\$30.00	PDF	
RM4U1918VBK	\$454.00	7.00 x 16.60 x 18.00 [178 x 422 x 457]	4U	16.60 x 18.00 [422 x 457]	RM1918BKSP	\$34.00	PDF	
RM4U1922VBK	\$547.00	7.00 x 16.60 x 22.00 [178 x 422 x 559]	4U	16.60 x 22.00 [422 x 559]	RM1922BKSP	\$37.00	PDF	
RM4U1928VBK	\$639.00	7.00 x 16.60 x 28.00 [178 x 422 x 711]	4U	16.60 x 28.00 [422 x 711]	RM1928BKSP	\$40.50	PDF	

Note: Dimensions in inches [millimeters].

Replacement Top/Bottom Panel for Instrument Enclosures



Application

Used to convert solid instrument enclosures to vented, or vice versa, or to replace damaged top or bottom panels.

Construction

- Flat aluminum 0.064in [1.6mm] with textured black powder-coat finish



[RM1918BKVP](#)



[RM1908BKSP](#)

Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

Replacement Top/Bottom Panel for Instrument Enclosures

Unvented	Price	Vented	Price	Dimensions HxW	Nominal Enclosure Size	Drawing Link
<u>RM0804BKSP</u>	\$10.00	<u>RM0804BKVP</u>	\$16.50	8.30 x 4.25 [211 x 108]	8.00 x 4.00 [203 x 102]	<u>PDF</u>
<u>RM0808BKSP</u>	\$13.50	<u>RM0808BKVP</u>	\$22.00	8.30 x 8.00 [211 x 203]	8.00 x 8.00 [203 x 203]	<u>PDF</u>
<u>RM1908BKSP</u>	\$22.50	<u>RM1908BKVP</u>	\$27.50	16.60 x 8.00 [422 x 203]	17.00 x 8.00 [432 x 203]	<u>PDF</u>
<u>RM1913BKSP</u>	\$30.00	<u>RM1913BKVP</u>	\$33.00	16.60 x 13.00 [422 x 330]	17.00 x 13.00 [432 x 330]	<u>PDF</u>
<u>RM1918BKSP</u>	\$34.00	<u>RM1918BKVP</u>	\$39.50	16.60 x 18.00 [422 x 457]	17.00 x 18.00 [432 x 457]	<u>PDF</u>
<u>RM1922BKSP</u>	\$37.00	<u>RM1922BKVP</u>	\$44.50	16.60 x 22.00 [422 x 559]	17.00 x 22.00 [432 x 559]	<u>PDF</u>
<u>RM1928BKSP</u>	\$40.50	<u>RM1928BKVP</u>	\$49.50	16.60 x 28.00 [422 x 711]	17.00 x 28.00 [432 x 711]	<u>PDF</u>

Note: Dimensions are in inches [millimeters]