

# 19-Inch Rack Cabinets



## Construction

- Cabinet frame, removable cover and doors constructed from 16-gauge steel.
- Square hole 19 in [483 mm] mounting rails are constructed from 12-gauge steel, include rack unit indicators, and are finished in smooth black powder coat.
- Suggested load ratings:
  - Wall-Mount (Rack-Mounted) up to 150 lb [68 kg].
  - Wall-Mount (Rails removed) up to 50 lb [22 kg].
  - Ceiling/ Under Desk Mount up to 150 lb [68 kg].
  - Freestanding (with or without casters) up to 800 lb [362 kg].
- Grounding studs provided on frame as well as on side panels and doors.
- Include punched square holes with 10-32 cage nuts and screws.

## Listings

- TAA compliant for GSA Schedule purchases.
- RoHS



Multi-use racks providing numerous options for equipment rack mounting. Ideal for securing rack mount equipment in spaces where room for a traditional rack or cabinet is limited or not available. The modular design includes a body with numerous accessory options to suit your unique application.

## Features

- 19 in [483 mm] mounting rail slots allow for adjustable depth rails and/or optional fan installation.
- Mounting rails are easily removed for non-rack mounting equipment.
- Starter pack of CAGKIT1032-10 screws and cage nuts included with 3U units or CAGKIT1032-50 screws and cage nuts included with 6U and 9U units.
- Removable cover panel for ease of equipment installation.
- Includes four cutouts perfect for mounting over an electrical receptacle and/or for cable entry.
- Interior cable management lances.
- Removable plastic handles for side mounting storage.
- Optional surface mounted doors with 1/4-turn lock and end cap available.

## Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

## 19-Inch Rack Cabinets

Part Number	Price	Rack Units	Overall Size HxWxD	Drawing Link
<a href="#">SDC243U17BK</a>	\$283.00	3U	6.25x24.00x17.50 [159 x 610 x 445]	<a href="#">PDF</a>
<a href="#">SDC243U24BK</a>	\$336.00	3U	6.25x24.00x24.50 [159 x 610 x 622]	<a href="#">PDF</a>
<a href="#">SDC243U31BK</a>	\$380.00	3U	6.25x24.00x31.50 [159 x 610 x 800]	<a href="#">PDF</a>
<a href="#">SDC243U36BK</a>	\$407.00	3U	6.25x24.00x36.00 [159 x 610 x 914]	<a href="#">PDF</a>
<a href="#">SDC246U17BK</a>	\$336.00	6U	11.50x24.00x17.50 [292 x 610 x 445]	<a href="#">PDF</a>
<a href="#">SDC246U24BK</a>	\$389.00	6U	11.50x24.00x24.50 [292 x 610 x 622]	<a href="#">PDF</a>
<a href="#">SDC246U31BK</a>	\$443.00	6U	11.50x24.00x31.50 [292 x 610 x 800]	<a href="#">PDF</a>
<a href="#">SDC246U36BK</a>	\$460.00	6U	11.50x24.00x36.00 [292 x 610 x 914]	<a href="#">PDF</a>
<a href="#">SDC249U17BK</a>	\$380.00	9U	16.75x24.00x17.50 [425 x 610 x 445]	<a href="#">PDF</a>
<a href="#">SDC249U24BK</a>	\$433.00	9U	16.75x24.00x24.50 [425 x 610 x 622]	<a href="#">PDF</a>
<a href="#">SDC249U31BK</a>	\$487.00	9U	16.75x24.00x31.50 [425 x 610 x 800]	<a href="#">PDF</a>
<a href="#">SDC249U36BK</a>	\$513.00	9U	16.75x24.00x36.00 [425 x 610 x 914]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# 19-Inch Rack Cabinets

## Accessories




Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	



Solid Cabinet Doors			
Part Number	Price	Rack Units	Drawing Link
<a href="#">SDC3USD</a>	\$71.00	3U	<a href="#">PDF</a>
<a href="#">SDC6USD</a>	\$92.00	6U	<a href="#">PDF</a>
<a href="#">SDC9USD</a>	\$101.00	9U	<a href="#">PDF</a>



Vented Cabinet Doors			
Part Number	Price	Rack Units	Drawing Link
<a href="#">SDC3UVD</a>	\$71.00	3U	<a href="#">PDF</a>
<a href="#">SDC6UVD</a>	\$95.00	6U	<a href="#">PDF</a>
<a href="#">SDC9UVD</a>	\$105.00	9U	<a href="#">PDF</a>

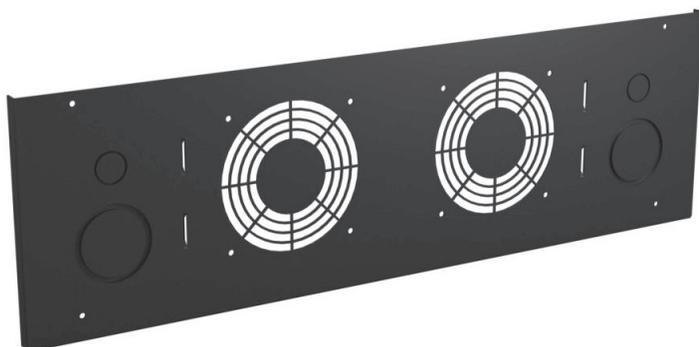

Fan Cover Panels			
Part Number	Price	Rack Units	Drawing Link
<a href="#">SDC3UCFP</a>	\$65.00	3U	<a href="#">PDF</a>
<a href="#">SDC6UCFP</a>	\$65.00	6U	<a href="#">PDF</a>
<a href="#">SDC9UCFP</a>	\$75.00	9U	<a href="#">PDF</a>

Compatible with fans [DNFK1AC120](#) and [DNFK2AC120](#)