

Flat and Dome Screw Cover Contoured Type 4, 10.25x4.00x2.75, Gray, Steel

CATALOG NUMBER

A1043DSC



An economical solution for a broad range of electrical and terminal wiring applications that don't require a back panel, this enclosure features aesthetic, rounded corners and is available in flat and dome cover models for mounting flexibility.

INDUSTRY STANDARDS

UL 508A Listed; Type 4, 6, 12, 13; File No. E61997

cUL Listed per CSA C22.2 No. 94; Type 4, 6, 12, 13; File No. E61997

NEMA Type 4, 6, 12, and 13

CSA, File No. 42186: Type 4, 12, and 13

IEC 60529, IP67

FEATURES

Drawn enclosure

No welded seams or sharp corners

Cover screws

Formed flanged cover

Oil-resistant gasket

External welded-on mounting brackets for easy installation

Bonding provision on cover

Grounding stud on body

PRODUCT ATTRIBUTES

Article Number: 57590

Height (H): 10.25in

Width (W): 4in

Depth (D): 2.75in

Material: Mild Steel

Finish: Powder Coated

Color: Gray

Color Code: ANSI 61

Thickness (T): 16ga

Cover Style: Flat

Interior Volume: 102.8in³


Mounting (G): 10.75in

Weight: 2.9lb

ADDITIONAL PRODUCT DETAILS

Domed-cover enclosure depth = V + 1 in. (25 mm)

DIAGRAMS

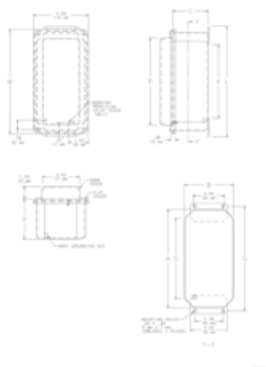

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE