

Screw Hinge Cover Quick-Release Latch Type 4X, 9.50x6.00x5.80, Gray, Fiberglass

CATALOG NUMBER

A1066JFGQRR



Able to withstand harsh environments, these small enclosures feature a simple, traditional non-metallic design that is suitable for a broad range of applications.

INDUSTRY STANDARDS

UL 508A Listed; Type 3, 3R, 4, 4X, 12, 13; File No. E61997
cUL Listed per CSA C22.2 No 94; Type 3, 3R, 4, 4X, 12, 13;
File No. E61997

Enclosure flammability evaluated per UL 508A

Window flammability evaluated per UL 508A

Window flammability evaluated per UL 508A

Mounting brackets required to meet UL/CSA external mounting requirements.

NEMA/EEMAC Type 3, 3R, 4, 4X, 12, 13

IEC 60529, IP66

Meets NEMA Type 3RX requirements

Meets NEMA Type 3RX requirements

CERTIFICATIONS



FEATURES

Compression-molded fiberglass material has excellent temperature and chemical resistance qualities and exhibits outstanding physical properties

Fiberglass material is easily punched, drilled, filed or sawed

Seamless foam-in-place gasket assures water-tight and dust-tight seal

Threaded internal bosses provided for mounting optional panels and terminal block kits

Scratch-resistant polycarbonate windows are permanently bonded in place

Screw-cover enclosures have easily removable covers attached to body with internal plated steel hinges

Cover securely fastens to the body with four captivated Type 316 stainless steel cover screws

Enclosures with quick-release latches have corrosion-resistant polyester hinges and polyester latches with a Type 316L stainless steel bail attached with Type 316 stainless steel screws

A Type 316L stainless steel padlock hasp is furnished with each enclosure

Sealing washers are furnished with enclosure

PRODUCT ATTRIBUTES

Article Number: 41240

Height (H): 10in

Width (W): 6in

Depth (D): 6in

Material: Fiberglass

Finish: Smooth Matte

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 0.12in

Cover Style: Solid

Latch Type: Quick Release

Latch Quantity: 2


Weight: 4.1lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately. Optional stainless steel, aluminum and composite material panels available for most sizes.

For CALIFORNIA residents only - WARNING: This product contains chemicals known to the State of California to cause cancer and birth defects or other reproductive harm. Please note that by posting this Proposition 65 warning, we are notifying you that one or more of the Proposition 65 listed chemicals may be present in this product. With HOFFMAN's products, the exposure to these chemicals may be of no significant risk to you, but out of caution and to ensure your well-being, we have elected to place this warning on our site to make sure our customers are informed. You can find more information at <http://www.oehha.ca.gov/proposition-65/about-proposition-65>.

DIAGRAMS

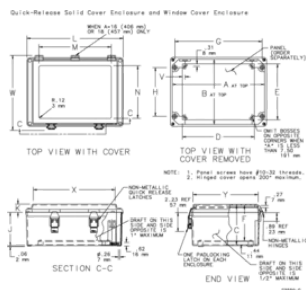

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE