


Hinged-Cover with Perforated Panel Type 1, 20.00x16.00x6.62, Gray, Steel

CATALOG NUMBER

A2016AT1PP

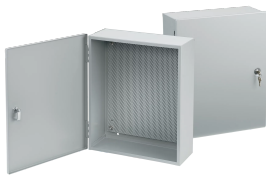

Hinged-Cover with Perforated Panel, Type 1, ships with pre-installed panel that accepts self-tapping screws and eliminates the need to measure, mark and drill when mounting components, which results in labor and time savings.

INDUSTRY STANDARDS

UL 50, 50E Listed; Type 1; File No. E27567

cUL Listed per CSA C22.2 No 40; Type 1; File No. E27567

NEMA/EEMAC Type 1

IEC 60529, IP30

FEATURES

Door has key lock quarter-turn latch; two keys included

Select models have concentric knockouts on four sides

Includes removable, 16-gauge, ANSI 61 gray, perforated panel

PRODUCT ATTRIBUTES

Article Number: 16086

Height: 20in

Width: 16in

Depth: 6.62in

Material: Mild Steel

Color: Gray

Color Code: ANSI 61

Thickness: 16ga

Mounting Holes: 17.88 x 11.00in

Knockout Pattern Along B Sides: B-C-D-E-F-G-H

Weight: 24.1lb

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE