


Fiberglass Disconnect Type 4X, 24.19x24.19x12.00, Lt Gray, Fiberglass

CATALOG NUMBER

A24HS2412GQRLP

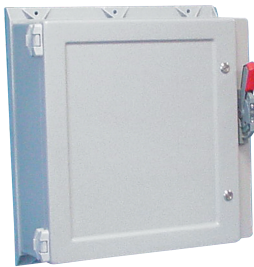

For effective and economical disconnect protection in the harshest corrosive environments, these enclosures provide secure door closure through the use of Type 304 stainless steel slotted quarter-turn latches. Each Fiberglass Disconnect, Type 4X is furnished with bracket affixed to door for attaching disconnect door catch (interlock) and instructions for installing disconnect handle (handle not included).

INDUSTRY STANDARDS

UL 508A Listed; Type 3, 3R, 4, 4X, 12, 13; File No. E61997
cUL Listed per CSA C22.2 No. 94; Type 3, 3R, 4, 4X, 12, 13;
File No. E61997

Enclosure flammability evaluated per UL 508A

NEMA/EEMAC Type 3, 3R, 4, 4X, 12, 13

IEC 60529, IP66

Meets NEMA Type 3RX requirements

CERTIFICATIONS



FEATURES

Fiberglass-reinforced material has excellent temperature and chemical resistance qualities and exhibits outstanding physical properties

Seams are sealed; no holes or knockouts

Seamless foam-in-place gasket assures water-tight and dust-tight seal

Fiberglass material is easily drilled, filed or sawed

Hinges are fiberglass reinforced polyester

Doors are secured with Type 304 stainless steel slotted quarter-turn latches

Data pocket is high-impact thermoplastic

Copper flashed steel collar studs for mounting optional panels and terminal block kits

Holes provided in body for mounting disconnect operating handle and operating mechanism; disconnect operating handle not included

Internal grounding provisions for quarter-turn latches

PRODUCT ATTRIBUTES

Article Number: 13236

Height: 24.19in

Width: 24.19in

Depth: 12in

Material: Fiberglass

Finish: Smooth Matte

Color: Light Gray

Color Code: RAL 7035

Thickness: 0.12in

Mounting: 25.81 x 18.00in

Latch Quantity: 2

Weight: 33.3lb

ADDITIONAL PRODUCT DETAILS

Purchase panels separately

Optional stainless steel, composite and aluminum panels available for most sizes. See General Accessories.

No additional "C" dimensions available

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE