

Free-Stand Type 1, 48.00x25.50x12.00, Gray, Steel

CATALOG NUMBER

A48N2512FSLP



Free-Stand Type 1 Enclosures are an economical way to protect equipment and employees in applications that do not require extensive environmental protection.

INDUSTRY STANDARDS

UL508A Listed; Type 1; File No. E61997

cUL Listed per CSA C22.2 No. 40; Type 1; File No. E61997

NEMA/EEMAC Type 1

IEC 60529 IP30

FEATURES

Enclosure back is 12 gauge for increased stiffness

4-in. high 10 gauge steel integral lifting base

Heights from 48 in. to 84 in. Usable height inside cabinet 4 in. less than nominal height.

Sturdy 7 gauge lifting tabs

Flush doors

3-point latch with heavy-duty handle

Padlock provision in handle

Predrilled holes in lifting base provide bolt-down capability

Easily reversible doors on single-door models

Overlapping doors with no center post on two-door models

Bonding provision on each door

Studs included for mounting optional panels on threaded bolts

Optional rack angles mount to top and bottom of front flanges

Removable back covers

PRODUCT ATTRIBUTES

Article Number: 13725

Height (H): 48in

Width (W): 25.5in

Depth (D): 12in

Material: Mild Steel

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 14ga

Panel Size (D): 37.16in


Panel Size (E): 21.5in

Weight: 173lb

ADDITIONAL PRODUCT DETAILS

Order panels separately.

DIAGRAMS

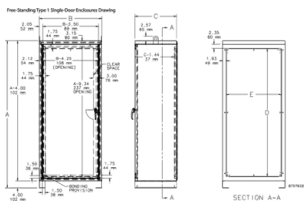

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE