

# Free-Stand Type 1, 60.00x36.00x18.00, Gray, Steel

## CATALOG NUMBER

**A60N3618FSLP**



Free-Stand Type 1 Enclosures are an economical way to protect equipment and employees in applications that do not require extensive environmental protection.

## INDUSTRY STANDARDS

UL508A Listed; Type 1; File No. E61997

cUL Listed per CSA C22.2 No. 40; Type 1; File No. E61997

NEMA/EEMAC Type 1

IEC 60529 IP30

## FEATURES

Enclosure back is 12 gauge for increased stiffness

4-in. high 10 gauge steel integral lifting base

Heights from 48 in. to 84 in. Usable height inside cabinet 4 in. less than nominal height.

Sturdy 7 gauge lifting tabs

Flush doors

3-point latch with heavy-duty handle

Padlock provision in handle

Predrilled holes in lifting base provide bolt-down capability

Easily reversible doors on single-door models

Overlapping doors with no center post on two-door models

Bonding provision on each door

Studs included for mounting optional panels on threaded bolts

Optional rack angles mount to top and bottom of front flanges

Removable back covers

## PRODUCT ATTRIBUTES

Article Number: 13733

Height (H): 60in

Width (W): 36in

Depth (D): 18in

Material: Mild Steel

Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 14ga

Panel Size (D): 49.16in


Panel Size (E): 32in

Weight: 288lb

## ADDITIONAL PRODUCT DETAILS

Order panels separately.

## DIAGRAMS

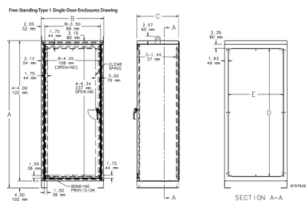

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**