

WeatherPro Outdoor Pad Mount Type 3R, 60.00x72.00x24.00, Lt Gray, Steel

CATALOG NUMBER

A60R7224FSLP



WeatherPro Outdoor Pad Mount Enclosures protect controls, drives, power distribution components or contactors in outdoor commercial or industrial power distribution and control applications. The overlapping two-door models with no center post allow full-width access to enclosure interior.

INDUSTRY STANDARDS

UL 508A Listed; Type 3R; File No. E61997

cUL/CSA C22.2 No. 94 Listed; Type 3R; File No. E61997

NEMA/EEMAC Type 3R

IEC 60529, IP32

FEATURES

3-point latching system with heavy duty handle

Padlock provision in handle

Open bottom with pre-punched mounting hole flange

Drip edge overhang on top

Louvered overhang with a closure plate

Studs included for mounting optional panels on threaded bolts

Welded body construction

Sturdy 7 gauge lifting tabs

Overlapping doors with no center post on two-door models

Bonding provision on each door

Bolted hinges on doors

Enclosures are finished with paint over plated surfaces

PRODUCT ATTRIBUTES

Article Number: 14418

Height (H): 60in

Width (W): 72in

Depth (D): 24in

Material: Mild Steel

Finish: Galvanized; Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 14ga


Mounting Dimensions (F x G): 7.90 x 30.90in

Weight: 475lb

ADDITIONAL PRODUCT DETAILS

Catalog weights and dimensions are careful estimates but not guaranteed.

DIAGRAMS

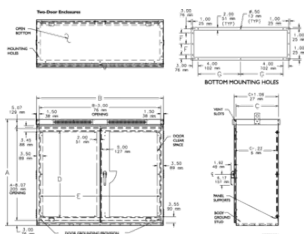

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE