



nve

We connect and protect

Low-Profile 3-Door Disconnect Type 12, 60.00x118.25x12.00, Gray, Steel

Catalog Number

A60X3E11912

A30X3E8310 Low Profile Three Door Disconnect Enclosure Type 12

- Available in one- to four-door wall-mount and one- to five-door free-stand models, the larger wall-mount sizes accommodate more components and are ideal for applications with limited floor space. Free-stand enclosures are 48- and 60-in. high to provide a clear line of site above the enclosure.

Industry Standards

- UL 508A Listed; Type 12; File No. E61997
- cUL Listed per CSA C22.2 No. 94; Type 12; File No. E61997
- NEMA/EEMAC Type 12
- IEC 60529, IP55

Features

- Seams continuously welded and ground smooth
- Body stiffeners in larger enclosures for extra rigidity
- Body flange trough excludes liquids and contaminants
- Heavy duty lifting eyes anchor into reinforced top on larger models
- Removable centerposts for easy panel installation
- Concealed, easy-to-remove hinges
- Heavy duty latch mechanism operated by zinc die-cast padlocking defeater handle on all doors; 2-point latch on enclosures up to 36 in. (914 mm); 3-point latch on enclosures 42 in. (1067 mm) and above
- Oil-resistant gasket
- Removable .127-in. thick steel panels mount on collar studs
- Master door is far right-hand door on all enclosures
- Defeater on primary door requires a screwdriver to open
- Preferred cutout on right flange provides mounting for most disconnect switches and circuit breakers
- Enclosures with three to five doors have three stiffeners on rear of body

PRODUCT ATTRIBUTES

- Article Number: 12744


- Height (H): 60in
- Width (W): 118.25in
- Depth (D): 12in
- Material: Mild Steel
- Finish: Powder Coated
- Color: Gray
- Color Code: ANSI 61
- Thickness (T): 0.098in
- Body Stiffener: 3
- Panel Quantity: 1; 1
- Lifting Eye Quantity: 2
- Weight: 555lb

Additional Product Details

Purchase panels separately.

Diagrams

Three-Door Enclosure

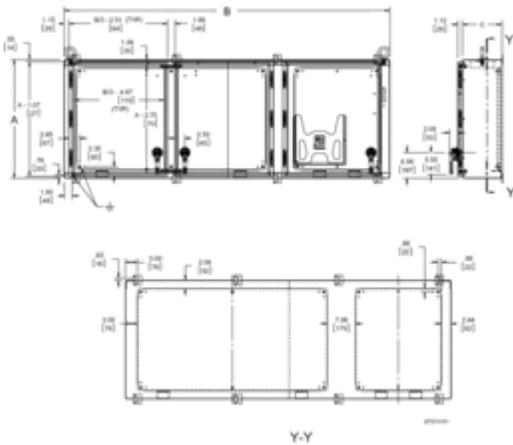

Warning

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

nVent-logo

Our powerful portfolio of brands:

- Caddy
- Erico
- Hoffman

- IlSCO
- Schroff
- Trachte

©2026 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

This document is system-generated.

nVent.com/HOFFMAN |